

Pneumatic Wheels for Dynastraight® and Dynisher Tools




DynaWheel Pneumatic Wheels

For light grinding and deburring

- Each wheel includes Low Flow Air Chuck (98130)
- Controlled inflation for hard-to-reach valve assemblies. 1/4" female NPT



	Part No.	Arbor	Max. RPM	Belt Size
5" x 1" (127 mm x 25 mm)	92922	5/8"-11 Thread	4,500	1" x 15-1/2" (25 x 394 mm)
	92924	1/2", 5/8" or 3/4" Bore		

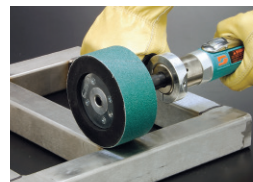

IMPORTANT

Speed of tool must not exceed maximum operating speed of accessory.


Dynacushion® Pneumatic Wheels

For polishing and blending

- Each wheel includes Low Flow Air Chuck (98130)
- Controlled inflation for hard-to-reach valve assemblies. 1/4" female NPT



	Part No.	Arbor	Max. RPM	Belt Size
3-1/4" x 3" (83 mm x 76 mm)	94507	5/8" Bore	7,000	3" x 10-11/16" (76 x 271 mm)
	94508	5/8"-11 Thread		
5" x 3-1/2" (127 mm x 89 mm)	92938	1/2", 5/8" or 3/4" Bore	3,500	3-1/2" x 15-1/2" (89 x 394 mm)
	94472	5/8"-11 Thread		

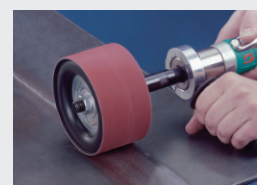

IMPORTANT

Speed of tool must not exceed maximum operating speed of accessory.