

DynaCut – Zirconia Alumina (Z/A)

Versatile, high-performance mineral that is sharp, hard and tough. For metalworking finishing on many types of metal including; stainless steel, nickel alloy, forged steel and aluminum.




	Width	60 Grit	80 Grit	120 Grit
24" Long	1/8"	79049	79054	79055
	1/4"	79057	79058	79059
	1/2"	79061	79062	79063
18" Long	1/4"	79027	79028	79029
	1/2"	79031	79032	79033
	3/4"	79035	79036	79037
	1"	79039	79040	79041
30" Long	1"	92186	92187	92188
	2"	92191	92192	92193

DynaBrite® – Non-Woven Nylon

Tough reinforced non-woven nylon impregnated with abrasive grain and resin. Ideal for surface conditioning, decorative finishing, light/heavy cleaning, blending and polishing.



	Width	Medium	Fine
24" Long	1/4"	78046	78047
	1/2"	78050	78051
18" Long	1/4"	78016	78017
	1/2"	78020	78021
	3/4"	78025	78026
	1"	78030	78031
30" Long	1"	78067	78068
	2"	78070	78071

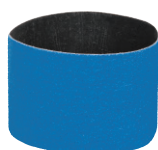

	Width	60 Grit	80 Grit	120 Grit
15-1/2"	1"	90195	90126	90127
10-11/16"	3"	92101	92102	92103
15-1/2"	3.5"	90272	90273	90275



	Width	Medium	Fine
15-1/2"	1"	78079	78094
10-11/16"	3"	90238	90237
15-1/2"	3.5"	90282	90281

