

Closed End Rivets

Exclusive rivet design featuring a cup shaped end configuration ideal for applications that need to be water tight or when stem retention is paramount.



Key features and benefits

- Seals out moisture, air and other contaminants
- Higher tensile and shear strength than the equivalent open end rivet
- 100% stem retention



Blindside set view

Specifications

Sizes:

1/8" – 1/4"

(3.2 mm – 6.4 mm)


Materials:

Aluminum, Steel,
Stainless Steel

Head Styles:

Dome, Countersunk

Typical placing sequence

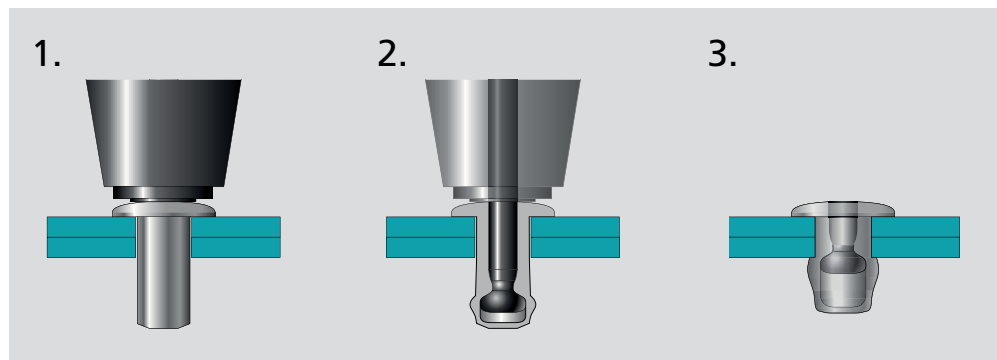

Please visit our website for fastener placing animations and technical data.

Assembly applications

- White goods
- Electronic enclosure
- Signs
- Outdoor cases
- Scoreboards
- LED signs
- Recreational vehicles

White goods



Lawn and garden



School bus



Electronic enclosure



Electronic switch




Sunroof





English	Français	Deutsch	Italiano	Español
Dome head	Tête plate	Flachrundkopf	Testa Tonda	Cabeza alomada
Body: Stainless steel* Natural	Corps: Inox* Brut	Hülse: Edelstahl* Unbehandelt	Corpo: Acciaio inox* Nessuna finitura	Cuerpo: Acero inoxidable* Natural
Stem: Stainless steel Natural	Tige: Inox Brut	Dorn: Edelstahl Unbehandelt	Gambo: Acciaio inox Nessuna finitura	Vástago: Acero inoxidable Natural

*: 300 Series

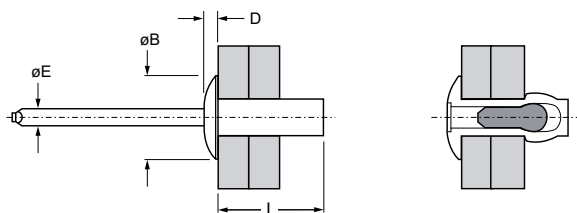

Ø					L	ØE	ØB	D			Part No.
nom.	min.	max.	min.	max.	ref.	ref.	max.	max.	lbf (kN) ¹⁾	lbf (kN) ¹⁾	
1/8" (3.2)	.0 (0)	.063 (1.6)	.130 (3.3)	.134 (3.4)	.260 (6.6)	.078 (2.0)	.262 (6.7)	.039 (1.0)	472 (2.10)	499 (2.22)	SSD 41 SSH
	.063 (1.6)	.125 (3.2)			.315 (8.0)						SSD 42 SSH
	.125 (3.2)	.190 (4.8)			.382 (9.7)						SSD 43 SSH
	.188 (4.8)	.252 (6.4)			.445 (11.3)						SSD 44 SSH
	.250 (6.4)	.311 (7.9)			.508 (12.9)						SSD 45 SSH
5/32" (4.0)	.0 (0)	.125 (3.2)	.161 (4.09)	.165 (4.19)	.339 (8.6)	.093 (2.4)	.338 (8.6)	.042 (1.1)	742 (3.30)	899 (4.00)	SSD 52 SSH
	.125 (3.2)	.190 (4.8)			.402 (10.2)						SSD 53 SSH
	.188 (4.8)	.252 (6.4)			.465 (11.8)						SSD 54 SSH
	.250 (6.4)	.311 (7.9)			.528 (13.4)						SSD 55 SSH
3/16" (4.8)	.0 (0)	.125 (3.2)	.193 (4.9)	.197 (5.0)	.362 (9.2)	.117 (3.0)	.393 (10.0)	.049 (1.25)	966 (4.30)	990 (4.40)	SSD 62 SSH
	.125 (3.2)	.189 (4.8)			.425 (10.8)						SSD 63 SSH
	.188 (4.8)	.252 (6.4)			.492 (12.5)						SSD 64 SSH
	.250 (6.4)	.374 (9.5)			.610 (15.5)						SSD 66 SSH
	.371 (9.5)	.500 (12.7)			.728 (18.5)						SSD 68 SSH

dimensions in inches and (mm) / en pouces et (millimètre) / alle Maße in Zoll und (mm) / in pollici e (millimetri) / en pulgadas y (milímetros)
 1) typical values / valeurs moyennes / typische Werte / Valori tipici / valores típicos