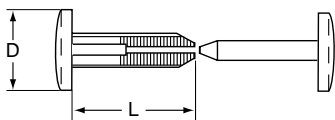




RATCHET FASTENERS

SRR/BR Series
Ratchet Fasteners

Specifications:

 
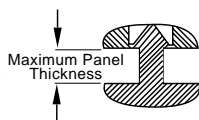
- Material: Nylon 6/6
- Color: Natural & Black

Features:

- Quick to install
- Interlocking teeth provide strong locking capability

Item No.		D (ref)	L (ref)	Hole Dia	Grip Range	Pack Qty.
Natural	Black					
SRR0100A	SRR0100B	0.375	0.500	0.250	0.500 - 0.812	1000
SRR0200A	SRR0200B	0.375	0.750	0.250	0.780 - 1.375	1000
SRR0300A	SRR0300B	0.625	0.500	0.250	0.500 - 0.812	1000
SRR0400A	SRR0400B	0.625	0.750	0.250	0.780 - 1.375	1000
SRR0500A	SRR0500B	0.375	0.218	0.250	0.235 - 0.297	1000
SRR0600A	SRR0600B	0.375	0.343	0.250	0.346 - 0.500	1000
SRR0700A	SRR0700B	0.625	0.218	0.250	0.235 - 0.297	1000
SRR0800A	SRR0800B	0.625	0.343	0.250	0.346 - 0.500	1000

Item No.		D (ref)	L (ref)	Hole Dia	Grip Range	Pack Qty.
Natural	Black					
BR2-226-01	BR2-226-01BK	0.406	0.226	0.281	.235-.297	1000
BR2-344-01	BR2-344-01BK	0.406	0.343	0.281	.346-.500	1000
BR2-488-01	BR2-488-01BK	0.406	0.500	0.281	.500-.812	1000
BR2-768-01	BR2-768-01BK	0.406	0.750	0.281	.781-1.375	1000
BR1-226-01	BR1-226-01BK	0.750	0.226	0.281	.235-.297	1000
BR1-344-01	BR1-344-01BK	0.750	0.344	0.281	.346-.500	1000
BR1-488-01	BR1-488-01BK	0.750	0.488	0.281	.500-.812	1000
BR1-768-01	BR1-768-01BK	0.750	0.768	0.281	.781-1.375	1000

RM/MBRR - MBRP Series
Mini Rivets

Male Mini Rivet



Female Mini Rivet

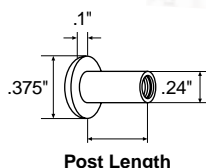
Specifications:

- Material: Nylon 6/6
- Color: Natural and Black

 
Features:

- Quick to install by simply pressing together
- Male and female parts sold separately
- Ideal for outdoor environments
- Resistant to corrosion, oil, abrasion and most chemicals

Item No.		Material	Material UL Rating	Hole Dia		Max Panel Thickness		Head Dia		Head thickness		Mating Part	Pack Qty.
Natural	Black			in	mm	in	mm	in	mm	in	mm		
Male													
RM110A	RM110B	Nylon 6/6	UL94 V-2	0.094	2.4	0.02	0.51	0.375	9.5	0.075	1.9	RM100A or RM100B	1000
RM120A	RM120B	Nylon 6/6	UL94 V-2	0.094	2.4	0.032	0.81	0.375	9.5	0.075	1.9	RM100A or RM100B	1000
RM130A	RM130B	Nylon 6/6	UL94 V-2	0.094	2.4	0.045	1.14	0.375	9.5	0.075	1.9	RM100A or RM100B	1000
RM140A	RM140B	Nylon 6/6	UL94 V-2	0.094	2.4	0.062	1.57	0.375	9.5	0.075	1.9	RM100A or RM100B	1000
RM150A	RM150B	Nylon 6/6	UL94 V-2	0.094	2.4	0.075	1.57	0.375	9.5	0.075	1.9	RM100A or RM100B	1000
RM160A	RM160B	Nylon 6/6	UL94 V-2	0.094	2.4	0.090	1.57	0.375	9.5	0.075	1.9	RM100A or RM100B	1000
RM170A	RM170B	Nylon 6/6	UL94 V-2	0.094	2.4	0.125	3.18	0.375	9.5	0.075	1.9	RM100A or RM100B	1000
RM180A	RM180B	Nylon 6/6	UL94 V-2	0.094	2.4	0.312	3.18	0.375	9.5	0.075	1.9	RM100A or RM100B	1000
Female													
RM100A	RM100B	Nylon 6/6	UL94 V-2	—	—	—	—	0.375	9.5	0.075	1.9	RM1XXA or RM1XXB	1000
Male													
MBRP1-030-01	MBRP1-030-01BK	Nylon 6/6	UL94 V-2	0.125	3.2	0.03	0.8	0.4	10.2	0.09	2.3	MBRR1-01 or MBRR1-01BK	1000
RM220A	RM220B	Nylon 6/6	UL94 V-2	0.125	3.2	0.045	1.1	0.5	12.7	0.10	2.5	RM200A or RM200B	1000
MBRP1-062-01	MBRP1-062-01BK	Nylon 6/6	UL94 V-2	0.125	3.2	0.062	1.6	0.4	10.2	0.09	2.3	MBRR1-01 or MBRR1-01BK	1000
MBRP1-100-01	MBRP1-100-01BK	Nylon 6/6	UL94 V-2	0.125	3.2	0.100	2.5	0.4	10.2	0.09	2.3	MBRR1-01 or MBRR1-01BK	1000
MBRP1-125-01	MBRP1-125-01BK	Nylon 6/6	UL94 V-2	0.125	3.2	0.125	3.2	0.4	10.2	0.09	2.3	MBRR1-01 or MBRR1-01BK	1000
RM260A	RM260B	Nylon 6/6	UL94 V-2	0.125	3.2	0.143	3.6	0.5	12.7	0.10	2.5	RM200A or RM200B	1000
MBRP1-187-01	MBRP1-187-01BK	Nylon 6/6	UL94 V-2	0.125	3.2	0.187	4.8	0.4	10.2	0.09	2.3	MBRR1-01 or MBRR1-01BK	1000
MBRP1-250-01	MBRP1-250-01BK	Nylon 6/6	UL94 V-2	0.125	3.2	0.250	6.4	0.4	10.2	0.09	2.3	MBRR1-01 or MBRR1-01BK	1000
RM280A	RM280B	Nylon 6/6	UL94 V-2	0.125	3.2	0.325	8.3	0.5	12.7	0.10	2.5	RM200A or RM200B	1000
Female													
MBRR1-01	MBRR1-01BK	Nylon 6/6	UL94 V-2	—	—	—	—	0.4	10.2	0.10	2.5	MBRP1-XXX or RM	1000
RM200A	RM200B	Nylon 6/6	UL94 V-2	—	—	—	—	0.5	12.7	0.10	2.5	RM2XXA or RM2XXB	1000

BS Series
Book Screws

Post Length



Screw Length

Specifications:

- Material: Nylon 6/6 & Post – HDPE
- Color: White and Black

Features:

- Supplied in sets of posts and screws
- Head diameter of 3/8

Item No.		Post Length	Screw Length	Pack Qty.
White	Black	In	In	
BS0187A	BS0187B	0.187	0.187	1000
BS0250A	BS0250B	0.250	0.250	1000
BS0375A	BS0375B	0.375	0.375	1000
BS0500A	BS0500B	0.500	0.500	1000
BS0750A	BS0750B	0.750	0.750	1000
BS0875A	BS0875B	0.875	0.690	1000

Item No.		Post Length	Screw Length	Pack Qty.
White	Black	In	In	
BS1000A	BS1000B	1.000	0.690	1000
BS1250A	BS1250B	1.250	0.690	1000
BS1375A	BS1375B	1.375	0.690	1000
BS1500A	BS1500B	1.500	0.690	1000
BS1750A	BS1750B	1.750	0.690	1000
BS2000A	BS2000B	2.000	.0690	1000