



PLASTIC SCREWS

Specifications:

 
- Material: Nylon 6/6
- Color: Natural

Features:

- Threaded nylon bolts and screws are the ideal fastener for mechanically securing materials
- Ideal for outdoor environments
- Lightweight compared to metal screws and bolts
- Resistant to corrosion, oil, abrasion and most chemicals

SPX/NSP Series

Pan Phillips Head Screws





Item No.	Thread	L in	L mm	T in	T mm	D in	D mm	Pack Qty.
SPX1010A	#2-56	0.188	4.775	0.058	1.473	0.168	4.267	1000
SPX1020A	#2-56	0.250	6.350	0.058	1.473	0.168	4.267	1000
SPX1060A	#2-56	0.500	12.700	0.058	1.473	0.168	4.267	1000
SPX1090A	#2-56	0.750	19.050	0.058	1.473	0.168	4.267	1000
SPX1100A	#2-56	1.000	25.400	0.058	1.473	0.168	4.267	1000
NSP-4-2-01	#4-40	0.125	3.175	0.080	2.032	0.210	5.334	1000
NSP-4-3-01	#4-40	0.188	4.775	0.080	2.032	0.210	5.334	1000
NSP-4-4-01	#4-40	0.250	6.350	0.080	2.032	0.210	5.334	1000
NSP-4-5-01	#4-40	0.313	7.950	0.080	2.032	0.210	5.334	1000
NSP-4-6-01	#4-40	0.375	9.525	0.080	2.032	0.210	5.334	1000
NSP-4-7-01	#4-40	0.438	11.125	0.080	2.032	0.210	5.334	1000
NSP-4-8-01	#4-40	0.500	12.700	0.080	2.032	0.210	5.334	1000
NSP-4-10-01	#4-40	0.625	15.875	0.080	2.032	0.210	5.334	1000
NSP-4-12-01	#4-40	0.750	19.050	0.080	2.032	0.210	5.334	1000
NSP-4-14-01	#4-40	0.875	22.225	0.080	2.032	0.210	5.334	1000
NSP-4-16-01	#4-40	1.000	25.400	0.080	2.032	0.210	5.334	1000
NSP-6-2-01	#6-32	0.125	3.175	0.090	2.286	0.260	6.604	1000
NSP-6-3-01	#6-32	0.188	4.775	0.090	2.286	0.260	6.604	1000
NSP-6-4-01	#6-32	0.250	6.350	0.090	2.286	0.260	6.604	1000
NSP-6-5-01	#6-32	0.313	7.950	0.090	2.286	0.260	6.604	1000
NSP-6-6-01	#6-32	0.375	9.525	0.090	2.286	0.260	6.604	1000
NSP-6-7-01	#6-32	0.438	11.125	0.090	2.286	0.260	6.604	1000

Item No.	Thread	L in	L mm	T in	T mm	D in	D mm	Pack Qty.
NSP-6-8-01	#6-32	0.500	12.700	0.090	2.286	0.260	6.604	1000
NSP-6-10-01	#6-32	0.625	15.875	0.090	2.286	0.260	6.604	1000
NSP-6-12-01	#6-32	0.750	19.050	0.090	2.286	0.260	6.604	1000
NSP-6-14-01	#6-32	0.875	22.225	0.090	2.286	0.260	6.604	1000
NSP-6-16-01	#6-32	1.000	25.400	0.090	2.286	0.260	6.604	1000
SPX1380A	#6-32	1.500	38.100	0.077	1.956	0.256	6.502	1000
NSP-8-2-01	#8-32	0.125	3.175	0.110	2.794	0.320	8.128	1000
NSP-8-3-01	#8-32	0.188	4.775	0.110	2.794	0.320	8.128	1000
NSP-8-4-01	#8-32	0.250	6.350	0.110	2.794	0.320	8.128	1000
NSP-8-5-01	#8-32	0.313	7.950	0.110	2.794	0.320	8.128	1000
NSP-8-6-01	#8-32	0.375	9.525	0.110	2.794	0.320	8.128	1000
NSP-8-7-01	#8-32	0.438	11.125	0.110	2.794	0.320	8.128	1000
NSP-8-8-01	#8-32	0.500	12.700	0.110	2.794	0.320	8.128	1000
NSP-8-10-01	#8-32	0.625	15.875	0.110	2.794	0.320	8.128	1000
NSP-8-12-01	#8-32	0.750	19.050	0.110	2.794	0.320	8.128	1000
NSP-8-14-01	#8-32	0.875	22.225	0.110	2.794	0.320	8.128	1000
NSP-8-16-01	#8-32	1.000	25.400	0.110	2.794	0.320	8.128	1000
SPX1520A	#8-32	1.500	38.100	0.120	3.048	0.314	7.976	1000
SPX1600A	#10-32	0.625	15.875	0.127	3.226	0.365	9.271	1000
SPX1650A	#10-32	1.000	25.400	0.127	3.226	0.365	9.271	1000
SPX1720A	1/4-20	0.500	12.700	0.171	4.343	0.483	12.268	1000
SPX1740A	1/4-20	1.000	25.400	0.171	4.343	0.483	12.268	1000

SPS/NSS Series

 Pan Slotted Head Screws

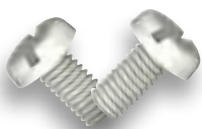


Item No.	Thread	L in	L mm	T in	T mm	D in	D mm	Pack Qty.
SPS1010A	#2-56	0.188	4.775	0.058	1.473	0.168	4.267	1000
SPS1020A	#2-56	0.250	6.350	0.058	1.473	0.168	4.267	1000
SPS1040A	#2-56	0.375	9.525	0.058	1.473	0.168	4.267	1000
SPS1060A	#2-56	0.500	12.700	0.058	1.473	0.168	4.267	1000
SPS1100A	#2-56	1.000	25.400	0.058	1.473	0.168	4.267	1000
NSS-4-2-01	#4-40	0.125	3.175	0.080	2.032	0.210	5.334	1000
NSS-4-3-01	#4-40	0.188	4.775	0.080	2.032	0.210	5.334	1000
NSS-4-4-01	#4-40	0.250	6.350	0.080	2.032	0.210	5.334	1000
NSS-4-5-01	#4-40	0.313	7.950	0.080	2.032	0.210	5.334	1000
NSS-4-6-01	#4-40	0.375	9.525	0.080	2.032	0.210	5.334	1000
NSS-4-7-01	#4-40	0.438	11.125	0.080	2.032	0.210	5.334	1000
NSS-4-8-01	#4-40	0.500	12.700	0.080	2.032	0.210	5.334	1000
SPS1180A	#4-40	0.563	14.300	0.065	1.651	0.212	5.385	1000
NSS-4-10-01	#4-40	0.625	15.875	0.080	2.032	0.210	5.334	1000
NSS-4-12-01	#4-40	0.750	19.050	0.080	2.032	0.210	5.334	1000
NSS-4-14-01	#4-40	0.875	22.225	0.080	2.032	0.210	5.334	1000
NSS-4-16-01	#4-40	1.000	25.400	0.080	2.032	0.210	5.334	1000
NSS-6-2-01	#6-32	0.125	3.175	0.090	2.286	0.260	6.604	1000
NSS-6-3-01	#6-32	0.188	4.775	0.090	2.286	0.260	6.604	1000
NSS-6-4-01	#6-32	0.250	6.350	0.090	2.286	0.260	6.604	1000
NSS-6-5-01	#6-32	0.313	7.950	0.090	2.286	0.260	6.604	1000
NSS-6-6-01	#6-32	0.375	9.525	0.090	2.286	0.260	6.604	1000
NSS-6-7-01	#6-32	0.438	11.125	0.090	2.286	0.260	6.604	1000
NSS-6-8-01	#6-32	0.500	12.700	0.090	2.286	0.260	6.604	1000
NSS-6-10-01	#6-32	0.625	15.875	0.090	2.286	0.260	6.604	1000
NSS-6-12-01	#6-32	0.750	19.050	0.090	2.286	0.260	6.604	1000
NSS-6-14-01	#6-32	0.875	22.225	0.090	2.286	0.260	6.604	1000
NSS-6-16-01	#6-32	1.000	25.400	0.090	2.286	0.260	6.604	1000
NSS-8-2-01	#8-32	0.125	3.175	0.110	2.794	0.320	8.128	1000

Item No.	Thread	L in	L mm	T in	T mm	D in	D mm	Pack Qty.
NSS-8-3-01	#8-32	0.188	4.775	0.110	2.794	0.320	8.128	1000
NSS-8-4-01	#8-32	0.250	6.350	0.110	2.794	0.320	8.128	1000
NSS-8-5-01	#8-32	0.313	7.950	0.110	2.794	0.320	8.128	1000
NSS-8-6-01	#8-32	0.375	9.525	0.110	2.794	0.320	8.128	1000
NSS-8-7-01	#8-32	0.438	11.125	0.110	2.794	0.320	8.128	1000
NSS-8-8-01	#8-32	0.500	12.700	0.110	2.794	0.320	8.128	1000
NSS-8-10-01	#8-32	0.625	15.875	0.110	2.794	0.320	8.128	1000
NSS-8-12-01	#8-32	0.750	19.050	0.110	2.794	0.320	8.128	1000
NSS-8-14-01	#8-32	0.875	22.225	0.110	2.794	0.320	8.128	1000
NSS-8-16-01	#8-32	1.000	25.400	0.110	2.794	0.320	8.128	1000
SPS1570A	#8-32	2.000	50.800	0.120	3.048	0.314	7.976	1000
SPS1640A	#10-32	0.500	12.700	0.127	3.226	0.365	9.271	1000
SPS1690A	#10-32	1.000	25.400	0.127	3.226	0.365	9.271	1000
SPS1740A	#10-32	2.000	50.800	0.171	4.343	0.483	12.268	1000
SPS1750A	1/4-20	0.250	6.350	0.171	4.343	0.483	12.268	1000
SPS1770A	1/4-20	0.500	12.700	0.171	4.343	0.483	12.268	1000
SPS1780A	1/4-20	0.750	19.050	0.171	4.343	0.483	12.268	1000
SPS1790A	1/4-20	1.000	25.400	0.171	4.343	0.483	12.268	1000
SPS1810A	1/4-20	1.500	38.100	0.171	4.343	0.483	12.268	1000
SPS1820A	1/4-20	1.750	44.450	0.171	4.343	0.483	12.268	1000
SPS1830A	1/4-20	2.000	50.800	0.171	4.343	0.483	12.268	1000
SPS1850A	5/16-18	0.500	12.700	0.221	5.613	0.605	15.367	1000
SPS1870A	5/16-18	1.000	25.400	0.221	5.613	0.605	15.367	1000
SPS1910A	5/16-18	2.000	50.800	0.221	5.613	0.605	15.367	1000
SPS1920A	3/8-16	0.250	6.350	0.280	7.112	0.728	18.491	500
SPS1930A	3/8-16	0.500	12.700	0.280	7.112	0.728	18.491	500
SPS1950A	3/8-16	1.000	25.400	0.280	7.112	0.728	18.491	500
SPS1990A	3/8-16	2.000	50.800	0.280	7.112	0.728	18.491	500

SPXM/NMS Series

 Metric Pan Phillips Head Screws



Item No.	Thread	L in	L mm	T in	T mm	D in	D mm	Pack Qty.
SPXM3L6A	M3	0.236	6.000	0.091	2.300	0.213	5.400	1000
NMS-306	M3	0.252	6.400	0.098	2.500	0.224	5.700	1000
NMS-308	M3	0.315	8.000	0.098	2.500	0.224	5.700	1000
SPXM3L10A	M3	0.394	10.000	0.091	2.300	0.213	5.400	1000
NMS-312	M3	0.476	12.100	0.098	2.500	0.224	5.700	1000
SPXM3L16A	M3	0.630	16.000	0.091	2.300	0.213	5.400	1000
SPXM3L25A	M3	0.984	25.000	0.091	2.300	0.213	5.400	1000
SPXM4L6A	M4	0.236	6.000	0.114	2.900	0.315	8.000	1000
NMS-408	M4	0.315	8.000	0.110	2.800	0.291	7.400	1000
SPXM4L10A	M4	0.394	10.000	0.114	2.900	0.315	8.000	1000
SPXM4L16A	M4	0.630	16.000	0.114	2.900	0.315	8.000	1000
SPXM4L25A	M4	0.984	25.000	0.114	2.900	0.315	8.000	1000
SPXM5L6A	M5	0.236	6.000	0.138	3.500	0.366	9.300	1000