




LOCKING CIRCUIT BOARD SUPPORTS

LCBSA-3 Locking Circuit Board Support

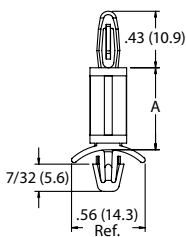

Top Hole:
Snap-lock: .156 (4)
Panel Thickness:
.093 (2.4)


Bottom Hole:
Snap-lock: .187 (4.75)
Panel Thickness:
.031 - .078 (0.79 - 1.98)

- Both ends lock by hand, no tools required
- Strong, dependable grip
- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

| Item No. | A Standoff Height | Bulk Pack Qty. |
|---------------|----------------------|----------------|
| LCBSA-3-3-01 | 3/16 (4.8) | 1000 |
| LCBSA-3-4-01 | 1/4 (6.4) | 1000 |
| LCBSA-3-5-01 | 5/16 (7.9) | 1000 |
| LCBSA-3-6-01 | 3/8 (9.5) | 1000 |
| LCBSA-3-7-01 | 7/16 (11.1) | 1000 |
| LCBSA-3-8-01 | 1/2 (12.7) | 1000 |
| LCBSA-3-10-01 | 5/8 (15.9) | 1000 |

| Item No. | A Standoff Height | Bulk Pack Qty. |
|---------------|----------------------|----------------|
| LCBSA-3-12-01 | 3/4 (19.1) | 1000 |
| LCBSA-3-14-01 | 7/8 (22.2) | 1000 |
| LCBSA-3-16-01 | 1 (25.4) | 1000 |
| LCBSA-3-18-01 | 1-1/8 (28.6) | 1000 |
| LCBSA-3-20-01 | 1-1/4 (31.7) | 1000 |
| LCBSA-3-22-01 | 1-3/8 (34.9) | 1000 |

LCBS-5 Locking Circuit Board Support

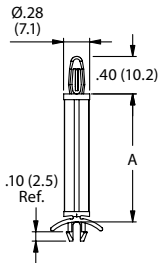

Top Hole:
Snap-lock: .156 (4)
Panel Thickness:
.062 (1.57)


Bottom Hole:
Snap-lock: .187 (4.75)
Panel Thickness:
.031 - .078 (0.79 - 1.98)

- Maximum temperature of 392°F (200°C)
- Extremely high strength
- Strong, dependable grip
- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

| Item No. | A Standoff Height | Bulk Pack Qty. |
|--------------|----------------------|----------------|
| LCBS-5-3-01 | 3/16 (4.8) | 1000 |
| LCBS-5-4-01 | 1/4 (6.4) | 1000 |
| LCBS-5-5-01 | 5/16 (7.9) | 1000 |
| LCBS-5-6-01 | 3/8 (9.5) | 1000 |
| LCBS-5-7-01 | 7/16 (11.1) | 1000 |
| LCBS-5-8-01 | 1/2 (12.7) | 1000 |
| LCBS-5-10-01 | 5/8 (15.9) | 1000 |

| Item No. | A Standoff Height | Bulk Pack Qty. |
|--------------|----------------------|----------------|
| LCBS-5-12-01 | 3/4 (19.1) | 1000 |
| LCBS-5-14-01 | 7/8 (22.2) | 1000 |
| LCBS-5-16-01 | 1 (25.4) | 1000 |
| LCBS-5-18-01 | 1-1/8 (28.6) | 1000 |
| LCBS-5-20-01 | 1-1/4 (31.8) | 1000 |
| LCBS-5-22-01 | 1-3/8 (34.9) | 1000 |

LCBS-HT Locking Circuit Board Support High Temperature

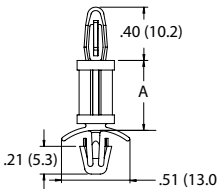

Top Hole:
Snap-lock: .156 (4.0)
Panel Thickness:
.062 (1.57)

Bottom Hole:
Snap-lock: .187 (4.8)
Panel Thickness:
.031 - .078 (0.8 - 2.0)

Specifications:

- Material: PEI
- Color: Black
- Flame Class: UL94 V-0


Features:

- Temperature rating up to 392°F (200°C)

| Item No. | In | mm | Bulk Pack Qty. |
|------------|-------|------|----------------|
| LCBS-3-HT | 0.188 | 4.8 | 1000 |
| LCBS-4-HT | 0.250 | 6.4 | 1000 |
| LCBS-5-HT | 0.313 | 7.9 | 1000 |
| LCBS-6-HT | 0.375 | 9.5 | 1000 |
| LCBS-7-HT | 0.438 | 11.1 | 1000 |
| LCBS-8-HT | 0.500 | 12.7 | 1000 |
| LCBS-10-HT | 0.625 | 15.9 | 1000 |

| Item No. | In | mm | Bulk Pack Qty. |
|------------|-------|------|----------------|
| LCBS-12-HT | 0.750 | 19.1 | 1000 |
| LCBS-14-HT | 0.875 | 22.2 | 1000 |
| LCBS-16-HT | 1.000 | 25.4 | 1000 |
| LCBS-18-HT | 1.125 | 28.6 | 1000 |
| LCBS-20-HT | 1.250 | 31.8 | 1000 |
| LCBS-22-HT | 1.375 | 34.9 | 1000 |

CBLS Series Locking Support

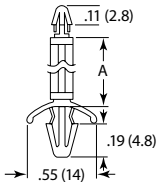

To Lock in Hole:
.137 (3.5)
Panel Thickness:
.047-.067 (1.2-1.7)


To Lock in Hole:
.187 (4.8)
Panel Thickness:
.031-.086 (0.8-2.2)

| Item No. | In | mm | Bulk Pack Qty. |
|----------|-------|------|----------------|
| CBLS105A | 0.125 | 3.2 | 1000 |
| CBLS110A | 0.197 | 5.0 | 1000 |
| CBLS115A | 0.248 | 6.3 | 1000 |
| CBLS120A | 0.315 | 8.0 | 1000 |
| CBLS125A | 0.394 | 10.0 | 1000 |

| Item No. | In | mm | Bulk Pack Qty. |
|----------|-------|------|----------------|
| CBLS130A | 0.472 | 12.0 | 1000 |
| CBLS135A | 0.551 | 14.0 | 1000 |
| CBLS140A | 0.630 | 16.0 | 1000 |
| CBLS145A | 0.709 | 18.0 | 1000 |
| CBLS150A | 0.984 | 25.0 | 1000 |

Specifications:

- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

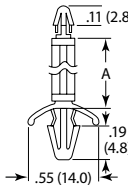


To Lock in Hole:
.118 (3.0)
Panel Thickness:
.047-.067 (1.2-1.7)

To Lock in Hole:
.187 (4.8)
Panel Thickness:
.031-.086 (0.8-2.2)

| Item No. | In | mm | Bulk Pack Qty. |
|----------|-------|------|----------------|
| CBLS205A | 0.125 | 3.2 | 1000 |
| CBLS210A | 0.187 | 4.8 | 1000 |
| CBLS215A | 0.248 | 6.3 | 1000 |
| CBLS220A | 0.315 | 8.0 | 1000 |
| CBLS225A | 0.394 | 10.0 | 1000 |

| Item No. | In | mm | Bulk Pack Qty. |
|----------|-------|------|----------------|
| CBLS230A | 0.472 | 12.0 | 1000 |
| CBLS235A | 0.551 | 14.0 | 1000 |
| CBLS240A | 0.630 | 16.0 | 1000 |
| CBLS245A | 0.709 | 18.0 | 1000 |
| CBLS250A | 0.984 | 25.0 | 1000 |

DLCBS Series Double Locking Support

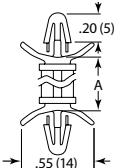

To Lock in Hole:
.156 (4.0)
Panel Thickness:
.031-.078 (0.8-2.0)

To Lock in Hole:
.156 (4.0)
Panel Thickness:
.031-.078 (0.8-2.0)



Specifications:

- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

| Item No. | UL94 V-2 | UL94 V-0 | In | mm | Bulk Pack Qty. |
|------------|------------|----------|------|------|----------------|
| DLCBS-3-01 | DLCBS-3-19 | 0.187 | 4.8 | 1000 | |
| DLCBS-4-01 | DLCBS-4-19 | 0.250 | 6.4 | 1000 | |
| DLCBS-6-01 | DLCBS-6-19 | 0.375 | 9.5 | 1000 | |
| DLCBS-8-01 | DLCBS-8-19 | 0.500 | 12.7 | 1000 | |

| Item No. | UL94 V-2 | UL94 V-0 | In | mm | Bulk Pack Qty. |
|-------------|-------------|----------|------|------|----------------|
| DLCBS-10-01 | DLCBS-10-19 | 0.625 | 15.9 | 1000 | |
| DLCBS-12-01 | DLCBS-12-19 | 0.750 | 19.1 | 1000 | |
| DLCBS-14-01 | DLCBS-14-19 | 0.875 | 22.2 | 1000 | |