




# LOCKING CIRCUIT BOARD SUPPORTS

## MDLSP2 Metric Mini Dual Locking Support Post

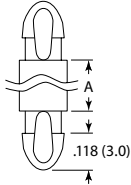

To Lock Hole:  
.137 (3.5)  
Panel Thickness:  
.062 (1.6)

To Lock Hole:  
.137 (3.5)  
Panel Thickness:  
.062 (1.6)


### Specifications:

- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

| Item No.      | A     |     | Bulk Pack Qty. |
|---------------|-------|-----|----------------|
|               | In    | mm  |                |
| MDLSP2-02M-01 | 0.078 | 2.0 | 1000           |
| MDLSP2-03M-01 | 0.118 | 3.0 | 1000           |
| MDLSP2-04M-01 | 0.156 | 4.0 | 1000           |
| MDLSP2-05M-01 | 0.197 | 5.0 | 1000           |
| MDLSP2-06M-01 | 0.236 | 6.0 | 1000           |
| MDLSP2-07M-01 | 0.276 | 7.0 | 1000           |
| MDLSP2-08M-01 | 0.314 | 8.0 | 1000           |

| Item No.      | A     |      | Bulk Pack Qty. |
|---------------|-------|------|----------------|
|               | In    | mm   |                |
| MDLSP2-10M-01 | 0.394 | 10.0 | 1000           |
| MDLSP2-12M-01 | 0.472 | 12.0 | 1000           |
| MDLSP2-14M-01 | 0.551 | 14.0 | 1000           |
| MDLSP2-16M-01 | 0.630 | 16.0 | 1000           |
| MDLSP2-18M-01 | 0.709 | 18.0 | 1000           |
| MDLSP2-20M-01 | 0.787 | 20.0 | 1000           |
| MDLSP2-22M-01 | 0.866 | 22.0 | 1000           |

## LCBSM Locking Support - Mini

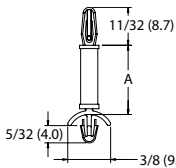

Top Hole:  
Snap-Lock: .125  
Panel Thickness:  
.062 (1.57)

Bottom Hole:  
Snap-Lock: .125  
Panel Thickness:  
.031 - .078 (0.8 - 2.0)


### Specifications:

 - Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

| Item No.   | A     |     | Bulk Pack Qty. |
|------------|-------|-----|----------------|
|            | In    | mm  |                |
| LCBSM-2-01 | 0.125 | 3.2 | 1000           |
| LCBSM-3-01 | 0.188 | 4.8 | 1000           |
| LCBSM-4-01 | 0.250 | 6.4 | 1000           |
| LCBSM-5-01 | 0.313 | 7.9 | 1000           |
| LCBSM-6-01 | 0.375 | 9.5 | 1000           |

| Item No.    | A     |      | Bulk Pack Qty. |
|-------------|-------|------|----------------|
|             | In    | mm   |                |
| LCBSM-7-01  | 0.438 | 11.1 | 1000           |
| LCBSM-8-01  | 0.500 | 12.7 | 1000           |
| LCBSM-9-01  | 0.563 | 14.3 | 1000           |
| LCBSM-10-01 | 0.625 | 15.9 | 1000           |

## LMSP Locking Support



Top Hole:  
Snap-lock: .125 (3.2)  
Panel Thickness: .062 (1.57)

Bottom Hole:  
Snap-lock: .125 (3.2)  
Panel Thickness: .062 (1.6)

- Both ends lock by hand, no tools required
- Strong, dependable grip


### Specifications:

- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

| Item No.  | A     |      | Bulk Pack Qty. |
|-----------|-------|------|----------------|
|           | In    | mm   |                |
| LMSP-2-01 | 0.125 | 3.2  | 1000           |
| LMSP-3-01 | 0.188 | 4.8  | 1000           |
| LMSP-4-01 | 0.250 | 6.4  | 1000           |
| LMSP-5-01 | 0.313 | 7.9  | 1000           |
| LMSP-6-01 | 0.375 | 9.5  | 1000           |
| LMSP-7-01 | 0.438 | 11.1 | 1000           |

| Item No.   | A     |      | Bulk Pack Qty. |
|------------|-------|------|----------------|
|            | In    | mm   |                |
| LMSP-8-01  | 0.500 | 12.7 | 1000           |
| LMSP-9-01  | 0.563 | 14.3 | 1000           |
| LMSP-10-01 | 0.625 | 15.9 | 1000           |
| LMSP-12-01 | 0.750 | 19.1 | 1000           |
| LMSP-14-01 | 0.875 | 22.2 | 1000           |

## DLCBSM Double Locking Support

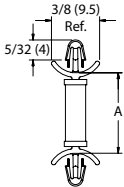

Top Hole:  
Snap-Lock: .125  
Panel Thickness:  
.031 - .078 (0.8 - 2.0)

Bottom Hole:  
Snap-Lock: .125  
Panel Thickness:  
.031 - .078 (0.8 - 2.0)



### Specifications:

- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

| Item No.    | A     |     | Bulk Pack Qty. |
|-------------|-------|-----|----------------|
|             | In    | mm  |                |
| DLCBSM-3-01 | 0.188 | 4.8 | 1000           |
| DLCBSM-4-01 | 0.250 | 6.4 | 1000           |
| DLCBSM-5-01 | 0.313 | 7.9 | 1000           |
| DLCBSM-6-01 | 0.375 | 9.5 | 1000           |

| Item No.     | A     |      | Bulk Pack Qty. |
|--------------|-------|------|----------------|
|              | In    | mm   |                |
| DLCBSM-7-01  | 0.438 | 11.1 | 1000           |
| DLCBSM-8-01  | 0.500 | 12.7 | 1000           |
| DLCBSM-9-01  | 0.563 | 14.3 | 1000           |
| DLCBSM-10-01 | 0.625 | 15.9 | 1000           |

## DLMSPM Stud Fitting Support

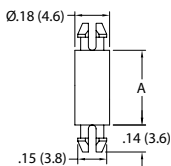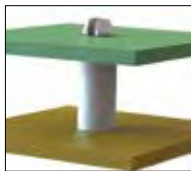

Snap-Lock:  
.125 (3.2)  
Panel Thickness:  
.062 (1.6)

Snap-Lock:  
.125 (3.2)  
Panel Thickness:  
.062 (1.6)


### Specifications:

- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

| Item No.     | A     |      | Bulk Pack Qty. |
|--------------|-------|------|----------------|
|              | In    | mm   |                |
| DLMSPM-2-01  | 0.125 | 3.2  | 1000           |
| DLMSPM-3-01  | 0.188 | 4.8  | 1000           |
| DLMSPM-4-01  | 0.250 | 6.4  | 1000           |
| DLMSPM-5-01  | 0.313 | 7.9  | 1000           |
| DLMSPM-6-01  | 0.375 | 9.5  | 1000           |
| DLMSPM-7-01  | 0.438 | 11.1 | 1000           |
| DLMSPM-8-01  | 0.500 | 12.7 | 1000           |
| DLMSPM-9-01  | 0.563 | 14.3 | 1000           |
| DLMSPM-10-01 | 0.625 | 15.9 | 1000           |

| Item No.     | A     |      | Bulk Pack Qty. |
|--------------|-------|------|----------------|
|              | In    | mm   |                |
| DLMSPM-12-01 | 0.750 | 19.1 | 1000           |
| DLMSPM-13-01 | 0.813 | 20.6 | 1000           |
| DLMSPM-14-01 | 0.875 | 22.2 | 1000           |
| DLMSPM-16-01 | 1.000 | 25.4 | 1000           |
| DLMSPM-18-01 | 1.125 | 28.6 | 1000           |
| DLMSPM-20-01 | 1.250 | 31.8 | 1000           |
| DLMSPM-22-01 | 1.375 | 34.9 | 1000           |
| DLMSPM-24-01 | 1.500 | 38.1 | 1000           |

## CLCBST Cupped Locking Circuit Board Support

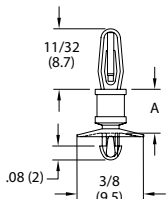

Top Hole:  
Snap-lock: .125 (3.18)  
Panel Thickness:  
.062 (1.57)

Bottom Hole:  
Snap-lock: .100 (2.54)  
Panel Thickness:  
.062 (1.57)

### Specifications:

- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

- Cupped base covers hole completely
- Low profile

| Item No.    | A          |      | Bulk Pack Qty. |
|-------------|------------|------|----------------|
|             | In         | mm   |                |
| CLCBST-2-01 | 1/8 (3.2)  | 1000 |                |
| CLCBST-3-01 | 3/16 (4.8) | 1000 |                |
| CLCBST-4-01 | 1/4 (6.4)  | 1000 |                |
| CLCBST-5-01 | 5/16 (7.9) | 1000 |                |
| CLCBST-6-01 | 3/8 (9.5)  | 1000 |                |

| Item No.     | A           |      | Bulk Pack Qty. |
|--------------|-------------|------|----------------|
|              | In          | mm   |                |
| CLCBST-7-01  | 7/16 (11.1) | 1000 |                |
| CLCBST-8-01  | 1/2 (12.7)  | 1000 |                |
| CLCBST-9-01  | 9/16 (14.3) | 1000 |                |
| CLCBST-10-01 | 5/8 (15.9)  | 1000 |                |