




REVERSE MOUNT CIRCUIT BOARD SUPPORTS

CRLCBSRE
Reverse Locking Domed Support

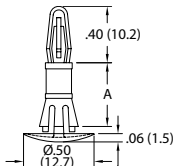


Snap Lock:
.157 (4.0)
Panel Thickness:
.063 (1.6)

Snap Lock:
.213 (5.4)
Panel Thickness:
.047-.079 (1.2-2.0)

- Specifications:
- Material: Nylon 6/6
 - Color: Natural
 - Flame Class: UL94 V-2

Item No.	A		Bulk Pack Qty.
	In	mm	
CRLCBSRE-4-01	0.250	6.4	1000
CRLCBSRE-6-01	0.375	9.5	1000
CRLCBSRE-8-01	0.500	12.7	1000
CRLCBSRE-10-01	0.625	15.9	1000

CRLCBSK-2
Metric Cupped Reverse Locking Circuit Board Support

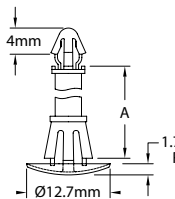

Top Hole:
Snap-lock: 4mm
Panel Thickness:
1.6mm

Bottom Hole:
Snap-lock: 5.4mm
Panel Thickness:
1mm - 1.6mm


- Cupped head provides tight holding in chassis
- Inserts into both holes from chassis underside
- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

Item No.	A		Bulk Pack Qty.
	In	mm	
CRLCBSK-2-8-01	8	1000	
CRLCBSK-2-10-01	10	1000	
CRLCBSK-2-12-01	12	1000	
CRLCBSK-2-14-01	14	1000	

CBRLDS Series
Reverse Locking Domed Support



- Specifications:
- Material: Nylon 6/6
 - Color: Natural
 - Flame Class: UL94 V-2

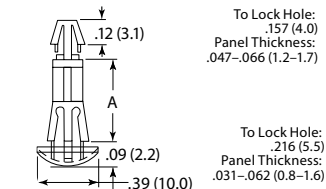


To Lock Hole:
.157 (4.0)
Panel Thickness:
.047-.066 (1.2-1.7)

To Lock Hole:
.216 (5.5)
Panel Thickness:
.031-.062 (0.8-1.6)

Item No.	A		Bulk Pack Qty.
	In	mm	
CBRLDS005A	0.138	3.5	1000
CBRLDS010A	0.197	5.0	1000
CBRLDS015A	0.250	6.4	1000
CBRLDS020A	0.276	7.0	1000
CBRLDS025A	0.315	8.0	1000
CBRLDS030A	0.335	8.5	1000
CBRLDS035A	0.394	10.0	1000
CBRLDS040A	0.472	12.0	1000
CBRLDS045A	0.500	12.7	1000
CBRLDS050A	0.531	13.5	1000

Item No.	A		Bulk Pack Qty.
	In	mm	
CBRLDS055A	0.551	14.0	1000
CBRLDS060A	0.598	15.2	1000
CBRLDS065A	0.625	15.9	1000
CBRLDS070A	0.709	18.0	1000
CBRLDS075A	0.748	19.0	1000
CBRLDS080A	1.787	20.0	1000
CBRLDS085A	1.854	21.7	500
CBRLDS090A	1.945	24.0	500
CBRLDS095A	1.000	25.4	500
CBRLDS100A	1.181	30.0	500

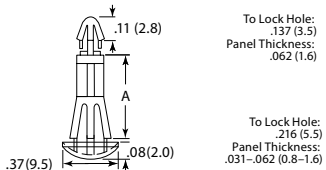


To Lock Hole:
.137 (3.5)
Panel Thickness:
.062 (1.6)

To Lock Hole:
.216 (5.5)
Panel Thickness:
.031-.062 (0.8-1.6)

Item No.	A		Bulk Pack Qty.
	In	mm	
CBRLDS205A	0.138	3.5	1000
CBRLDS210A	0.187	4.8	1000
CBRLDS215A	0.250	6.4	1000
CBRLDS220A	0.276	7.0	1000
CBRLDS225A	0.315	8.0	1000

Item No.	A		Bulk Pack Qty.
	In	mm	
CBRLDS230A	0.394	10.0	1000
CBRLDS235A	0.433	11.0	1000
CBRLDS240A	0.500	12.7	1000
CBRLDS245A	0.625	15.9	1000

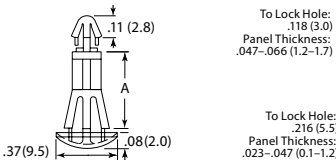


To Lock Hole:
.118 (3.0)
Panel Thickness:
.047-.066 (1.2-1.7)

To Lock Hole:
.216 (5.5)
Panel Thickness:
.023-.047 (0.1-1.2)

Item No.	A		Bulk Pack Qty.
	In	mm	
CBRLDS305A	0.138	3.5	1000
CBRLDS310A	0.188	4.8	1000
CBRLDS315A	0.250	6.4	1000
CBRLDS320A	0.276	7.0	1000
CBRLDS325A	0.315	8.0	1000

Item No.	A		Bulk Pack Qty.
	In	mm	
CBRLDS330A	0.394	10.0	1000
CBRLDS335A	0.433	11.0	1000
CBRLDS340A	0.500	12.7	1000
CBRLDS345A	0.625	15.9	1000

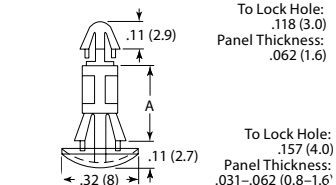

To Lock Hole:
.118 (3.0)
Panel Thickness:
.062 (1.6)

To Lock Hole:
.157 (4.0)
Panel Thickness:
.031-.062 (0.8-1.6)

Item No.	A		Bulk Pack Qty.
	In	mm	
CBRLDS405A	0.098	2.5	2000
CBRLDS410A	0.125	3.2	2000
CBRLDS415A	0.157	4.0	2000
CBRLDS420A	0.197	5.0	2000
CBRLDS425A	0.236	6.0	2000
CBRLDS430A	0.276	7.0	1000

Item No.	A		Bulk Pack Qty.
	In	mm	
CBRLDS435A	0.315	8.0	1000
CBRLDS440A	0.354	9.0	1000
CBRLDS445A	0.394	10.0	1000
CBRLDS450A	0.472	12.0	1000
CBRLDS455A	0.551	14.0	1000
CBRLDS460A	0.630	16.0	1000