




FEMALE / FEMALE THREADED STANDOFFS


PEEK Hex Female/Female Spacer

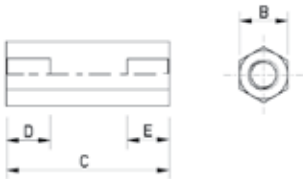

- Material: PEEK
- Color: Light Brown
- Heat Resistant up to 356° F
- Flame Rating: UL94 V-0
- Excellent mechanical strength and stiffness
- Excellent Resistance to alternating tensile and bending loads

Item No.	Thread	C	B	D & E	Bulk Pack Qty
186301070409	M3	10.0 mm	6.0 mm	5.0 mm	10
186301270409	M3	12.0 mm	6.0 mm	6.0 mm	10
186301570409	M3	15.0 mm	6.0 mm	7.5 mm	10
186301870409	M3	18.0 mm	6.0 mm	9.0 mm	10
186302070409	M3	20.0 mm	6.0 mm	10.0 mm	10
186302570409	M3	25.0 mm	6.0 mm	10.0 mm	10
186303070409	M3	30.0 mm	6.0 mm	10.0 mm	10
186304070409	M3	4.0 mm	6.0 mm	2.0 mm	10
186305070409	M3	5.0 mm	6.0 mm	2.5 mm	10
186306070409	M3	6.0 mm	6.0 mm	3.0 mm	10
186308070409	M3	8.0 mm	6.0 mm	4.0 mm	10
186401070409	M4	10.0 mm	7.0 mm	5.0 mm	10
186401270409	M4	12.0 mm	7.0 mm	6.0 mm	10
186401570409	M4	15.0 mm	7.0 mm	7.5 mm	10
186401870409	M4	18.0 mm	7.0 mm	9.0 mm	10
186402070409	M4	20.0 mm	7.0 mm	10.0 mm	10
186402570409	M4	25.0 mm	7.0 mm	10.0 mm	10
186403070409	M4	30.0 mm	7.0 mm	10.0 mm	10
186403570409	M4	35.0 mm	7.0 mm	10.0 mm	10
186405070409	M4	5.0 mm	7.0 mm	2.5 mm	10
186406070409	M4	6.0 mm	7.0 mm	3.0 mm	10
186408070409	M4	8.0 mm	7.0 mm	4.0 mm	10
186501070409	M4	10.0 mm	7.0 mm	5.0 mm	10
186501270409	M4	12.0 mm	7.0 mm	6.0 mm	10
186501570409	M5	15.0 mm	8.0 mm	7.5 mm	10
186501870409	M5	18.0 mm	8.0 mm	9.0 mm	10
186502070409	M5	20.0 mm	8.0 mm	10.0 mm	10
186502570409	M5	25.0 mm	8.0 mm	10.0 mm	10
186503070409	M5	30.0 mm	8.0 mm	10.0 mm	10
186503570409	M5	35.0 mm	8.0 mm	10.0 mm	10
186504070409	M5	40.0 mm	8.0 mm	10.0 mm	10
186506070409	M5	6.0 mm	8.0 mm	3.0 mm	10
186508070409	M5	8.0 mm	8.0 mm	4.0 mm	10

HTS/CBTS Series Threaded Standoff

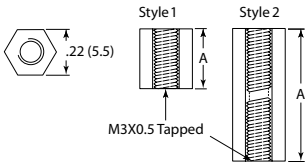

CBTS Series (Threaded Standoffs) can be used with the following screws:

Threads: 4-40, 6-32

SCREWS:

SPS Series - Page: 122    SPX Series - Page: 122



Threads: M3 & M4

SCREWS:

SXHM Series - Page: 120    SCSM Series - Page: 123    SPXM Series - Page: 122



Specifications:

- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

Size	C
#4	0.250
#6	0.250
M3	0.217

Item No.			A		Bulk Pack Qty.
#4	#6	#8	M3	In mm	
—	—	—	CBTS005A	0.157 4.0	1000
—	—	—	CBTS010A	0.197 5.0	1000
—	—	—	CBTS015A	0.236 6.0	1000
HTS4-4-48	HTS6-4-48	—	MTS-6	0.250 6.4	1000
—	—	—	CBTS020A	0.276 7.0	1000
HTS4-5-48	—	—	—	0.313 7.9	1000
—	—	—	MTS-8	0.315 8.0	1000
—	—	—	CBTS030A	0.354 9.0	1000
HTS4-6-48	HTS6-6-48	—	CBTS035A	0.375 9.5	1000
—	—	—	MTS-10S	0.394 10.0	1000
—	—	—	MTS-10	0.413 10.5	1000
—	—	—	MTS-11	0.433 11.0	1000
HTS4-7-48	HTS6-7-48	—	—	0.437 11.1	1000
—	—	—	MTS-12	0.472 12.0	1000
HTS4-8-48	HTS6-8-48	—	CBTS060A	0.500 12.7	1000
—	—	—	MTS-13	0.504 12.8	1000
—	—	—	CBTS065A	0.531 13.5	1000
—	—	—	MTS-14	0.551 14.0	1000
—	HTS6-9-48	—	—	0.563 14.3	1000
—	—	—	CBTS075A	0.591 15.0	1000
HTS4-10-48	HTS6-10-48	HTS8-10-48	—	0.625 15.9	1000

Item No.			A		Bulk Pack Qty.
#4	#6	#8	M3	In mm	
—	—	—	MTS-16	0.630 16.0	1000
—	—	—	CBTS085A	0.669 17.0	1000
—	—	—	CBTS090A	0.709 18.0	1000
—	—	—	MTS-18	0.717 18.2	1000
—	—	—	CBTS095A	0.748 19.0	1000
—	—	—	CBTS100A	0.787 20.0	1000
—	—	—	MTS-20	0.791 20.1	1000
—	—	—	CBTS105A	0.866 22.0	1000
—	—	—	CBTS110A	0.945 24.0	1000
—	—	—	CBTS115A	0.984 25.0	1000
—	HTS6-16-48	—	—	1.000 25.4	1000
—	—	—	CBTS120A	1.063 27.0	1000
—	—	—	MTS-30	1.181 30.0	1000
—	—	—	CBTS130A	1.260 32.0	1000
—	—	—	CBTS135A	1.496 38.0	1000
—	—	—	CBTS140A	1.575 40.0	1000
—	—	—	CBTS145A	1.654 42.0	1000
—	—	—	CBTS150A	1.772 45.0	1000
—	—	—	CBTS155A	1.929 49.0	1000
—	—	—	CBTS160A	2.047 52.0	1000