




LED SPACERS

LEDS2M
LED Spacer

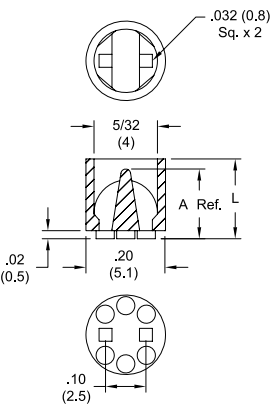


- Fits standard T-1 3/4 LEDs
- Internal tapered dividers guide the lead wires and prevent leads from shorting
- Bottom bosses serve to dissipate heat and ease post-solder cleanup
- Material: UL94 V-2 Nylon 6/6
- Color: Natural

Item No.	L	A Ref.	LED Type	Bulk Pack Qty.
LEDS2M-120-01	.12 (3.1)	.08 (2)	T-1 3/4 (5mm)	1000
LEDS2M-140-01	.14 (3.6)	.08 (2)	T-1 3/4 (5mm)	1000
LEDS2M-160-01	.16 (4.1)	.08 (2)	T-1 3/4 (5mm)	1000
LEDS2M-180-01	.18 (4.5)	.08 (2)	T-1 3/4 (5mm)	1000
LEDS2M-200-01	.20 (5.1)	.08 (2)	T-1 3/4 (5mm)	1000
LEDS2M-220-01	.22 (5.6)	.08 (2)	T-1 3/4 (5mm)	1000
LEDS2M-240-01	.24 (6.1)	.08 (2)	T-1 3/4 (5mm)	1000
LEDS2M-250-01	.25 (6.4)	.20 (5.1)	T-1 3/4 (5mm)	1000
LEDS2M-260-01	.26 (6.6)	.20 (5.1)	T-1 3/4 (5mm)	1000
LEDS2M-280-01	.28 (7.1)	.20 (5.1)	T-1 3/4 (5mm)	1000
LEDS2M-300-01	.30 (7.8)	.20 (5.1)	T-1 3/4 (5mm)	1000
LEDS2M-320-01	.32 (8.1)	.20 (5.1)	T-1 3/4 (5mm)	1000
LEDS2M-340-01	.34 (8.6)	.20 (5.1)	T-1 3/4 (5mm)	1000
LEDS2M-360-01	.36 (9.1)	.20 (5.1)	T-1 3/4 (5mm)	1000

Item No.	L	A Ref.	LED Type	Bulk Pack Qty.
LEDS2M-380-01	.38 (9.7)	.33 (8.4)	T-1 3/4 (5mm)	1000
LEDS2M-400-01	.40 (10.2)	.33 (8.4)	T-1 3/4 (5mm)	1000
LEDS2M-420-01	.42 (10.7)	.33 (8.4)	T-1 3/4 (5mm)	1000
LEDS2M-440-01	.44 (11.2)	.33 (8.4)	T-1 3/4 (5mm)	1000
LEDS2M-450-01	.45 (11.4)	.33 (8.4)	T-1 3/4 (5mm)	1000
LEDS2M-460-01	.46 (11.7)	.33 (8.4)	T-1 3/4 (5mm)	1000
LEDS2M-500-01	.50 (12.7)	.45 (11.4)	T-1 3/4 (5mm)	1000
LEDS2M-550-01	.55 (14)	.45 (11.4)	T-1 3/4 (5mm)	1000
LEDS2M-600-01	.60 (15.2)	.45 (11.4)	T-1 3/4 (5mm)	1000
LEDS2M-650-01	.65 (16.5)	.58 (14.7)	T-1 3/4 (5mm)	1000
LEDS2M-750-01	.75 (19.1)	.70 (17.8)	T-1 3/4 (5mm)	1000
LEDS2M-850-01	.85 (21.6)	.70 (17.8)	T-1 3/4 (5mm)	1000
LEDS2M-900-01	.90 (22.9)	.70 (17.8)	T-1 3/4 (5mm)	1000


LEDM-1
Metric LED Spacers

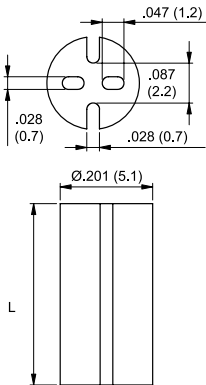

- Fits standard T-1 3/4 LEDs
- Provides height control, lead wire retention and stability
- Self-retaining feature for auto insertion and pre-assembly
- Material: PVC
- Color: Black

Item No.	L Length mm	Fits LED	Bulk Pack Qty.
LEDM-1-2	2	T-1 3/4 (5mm)	1000
LEDM-1-3	3	T-1 3/4 (5mm)	1000
LEDM-1-4	4	T-1 3/4 (5mm)	1000
LEDM-1-6	5	T-1 3/4 (5mm)	1000
LEDM-1-8	8	T-1 3/4 (5mm)	1000
LEDM-1-9	9	T-1 3/4 (5mm)	1000
LEDM-1-10	10	T-1 3/4 (5mm)	1000
LEDM-1-13	13	T-1 3/4 (5mm)	1000
LEDM-1-21	21	T-1 3/4 (5mm)	1000


LEDM-2
Metric LED Spacers

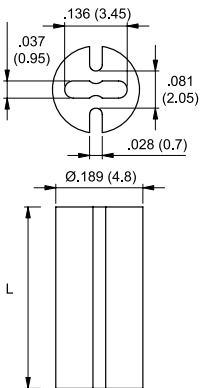

- Fits standard T-1 LEDs
- Provides height control, lead wire retention and stability
- Self-retaining feature for auto insertion and pre-assembly
- Material: PVC
- Color: Black

Item No.	L Length mm	Fits LED	Bulk Pack Qty.
LEDM-2-2	2	T-1 (3mm)	1000
LEDM-2-3	3	T-1 (3mm)	1000
LEDM-2-4	4	T-1 (3mm)	1000
LEDM-2-6	5	T-1 (3mm)	1000
LEDM-2-8	8	T-1 (3mm)	1000
LEDM-2-9	9	T-1 (3mm)	1000
LEDM-2-10	10	T-1 (3mm)	1000
LEDM-2-13	13	T-1 (3mm)	1000
LEDM-2-21	21	T-1 (3mm)	1000

LEDM-3
Metric LED Spacers

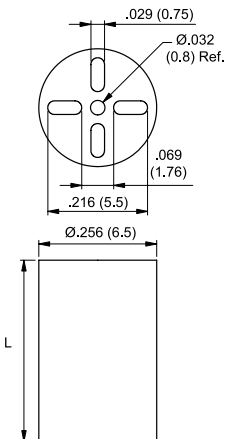

- Fits standard T-1 3/4 LEDs
- Provides height control, lead wire retention and stability
- Self-retaining feature for auto insertion and pre-assembly
- Material: PVC
- Color: Black

Item No.	L Length mm	Fits LED	Bulk Pack Qty.
LEDM-3-2	2	T-1 3/4 (5mm)	1000
LEDM-3-3	3	T-1 3/4 (5mm)	1000
LEDM-3-4	4	T-1 3/4 (5mm)	1000
LEDM-3-6	5	T-1 3/4 (5mm)	1000
LEDM-3-8	8	T-1 3/4 (5mm)	1000
LEDM-3-9	9	T-1 3/4 (5mm)	1000
LEDM-3-10	10	T-1 3/4 (5mm)	1000
LEDM-3-13	13	T-1 3/4 (5mm)	1000
LEDM-3-21	21	T-1 3/4 (5mm)	1000