




DUCT

RX
Flexible Duct

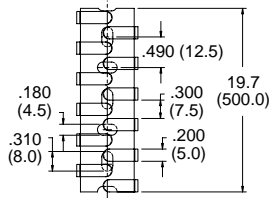

Specifications:



- Material: UL94 V-2 Polypropylene
- Color: Grey

Features:

- Flexible ribs allow the cables to be easily pushed and pulled into and out of channel
- Flexible base makes routing cables from the back and sides of control panels to components mounted on panel doors easy

Item No.		External A x A		Internal A x A		Length		Pack Qty.	Bulk Pack Qty.
Screw Mount	Adhesive Mount	In	mm	In	mm	In	mm		
RX1313-0	RX1313-4	0.492 x 0.492	12.5 x 12.5	0.171	110.0	19.700	500.0	1	112
RX1616-0	RX1616-4	0.630 x 0.630	16.0 x 16.0	0.287	185.0	19.700	500.0	1	84
RX2020-0	RX2020-4	0.787 x 0.787	20.0 x 20.0	0.496	320.0	19.700	500.0	1	112
RX2525-0	RX2525-4	0.984 x 0.984	25.0 x 25.0	0.775	500.0	19.700	500.0	1	70
RX3030-0	RX3030-4	1.181 x 1.181	30.0 x 30.0	1.116	720.0	19.700	500.0	1	50
RX4040-0	RX4040-4	1.575 x 1.575	40.0 x 40.0	2.046	1320.0	19.700	500.0	1	50
RX5050-0	RX5050-4	1.969 x 1.969	50.0 x 50.0	3.162	2040.0	19.700	500.0	1	32

SRWD
Slotted Wire Duct

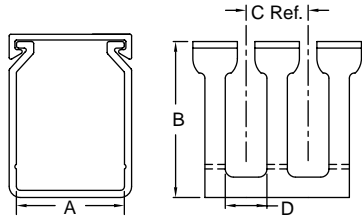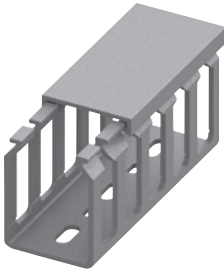


Specifications:


- Material: PVC
- Color: Grey

Features:

- Lid is supplied with the base
- Fingers are scored for easy break off
- Used for general purpose control panel wiring and to route and protect wiring in communication closets
- Holds breakout wires while providing flexibility for adding or removing wires
- Sold in 6-1/2 foot lengths

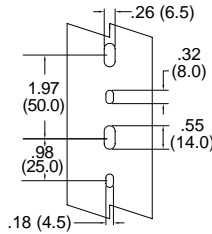



Mounting Style 1

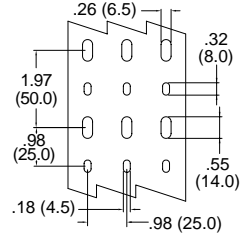

Mounting Style 2

Item No.	Approval	A		B		C		D		Mounting Style	Length		Pack Qty.	Bulk Pack Qty.
		In	mm	In	mm	In	mm	In	mm		ft	m		
SRWD-1015	UL	1.000	25.4	1.500	38.1	0.790	20.0	0.310	8.0	1	6.5	2.0	6.5 ft	78 ft
SRWD-1515	UL	1.500	38.1	1.500	38.1	0.790	20.0	0.310	8.0	1	6.5	2.0	6.5 ft	78 ft
SRWD-1520	UL	1.500	38.1	2.000	50.8	0.790	20.0	0.310	8.0	1	6.5	2.0	6.5 ft	52 ft
SRWDN1-1530	UL	1.500	38.1	3.000	76.2	0.390	10.0	0.160	4.0	1	6.5	2.0	6.5 ft	78 ft
SRWD-2020	UL	2.000	50.8	2.000	50.8	0.790	20.0	0.310	8.0	1	6.5	2.0	6.5 ft	52 ft
SRWDN1-2030	UL	2.000	50.8	3.000	76.2	0.390	10.0	0.160	4.0	1	6.5	2.0	6.5 ft	78 ft
SRWD-4020	UL	4.000	101.6	2.000	50.8	0.790	20.0	0.310	8.0	2	6.5	2.0	6.5 ft	26 ft

SCD
Single Cable Duct

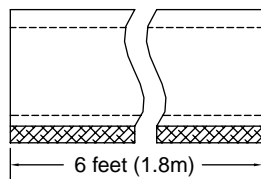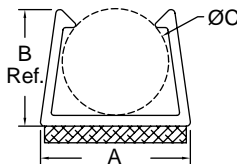

Specifications:

- Material: UL94 V-0 PVC
- Color: Tan

Features:

- Designed to route single coax or computer cable
- Supplied in 6 foot lengths
- Adhesive base for easy mounting



Item No.	C Holding Ø		A		B Ref.		Cable Recommendations	Length		Pack Qty.	Bulk Pack Qty.
	In	mm	In	mm	In	mm		ft	m		
SCD-1521	0.156 - 0.218	4.0 - 5.5	0.300	7.6	0.250	6.4	RG58	6	1.8	6 ft	60 ft
SCD-2228	0.218 - 0.280	5.5 - 7.1	0.360	9.1	0.290	6.6	RG59, RG62, RG6, 9 Line	6	1.8	6 ft	60 ft