




GASK Series
Gasketing

Specifications:


- Material: EPDM or PVC

Features:


- Internal wire inserts allow for a firm clip, except types 22-24
- Can be used as a protective edge of the sheet metal
- PVC is best if enclosure will be sealed for long periods

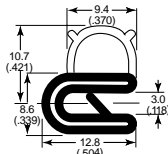


GASK100A

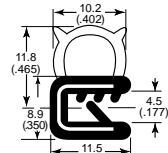


GASK200A

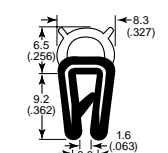


GASK300A

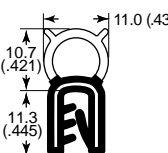


GASK350A

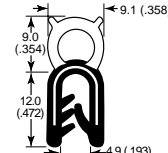


GASK400A

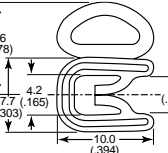


GASK500A

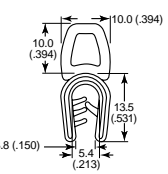


GASK600A

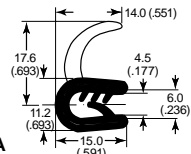


GASK800A

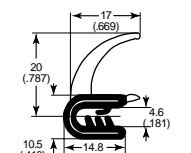


GASK850A

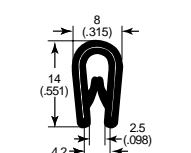


GASK900A

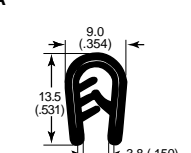


GASK930A

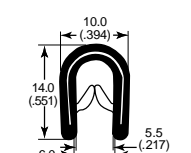

GASK960A

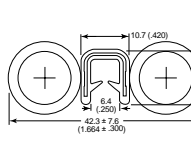

GASK1050A

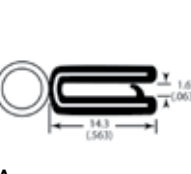

GASK2100A

Item No.	Material	Grip Range mm	Roll Length	
			Ft	m
GASK100A	EPDM	1.0 - 2.5	328	100.0
GASK200A	EPDM	1.0 - 3.0	328	100.0
GASK300A	EPDM	1.0 - 2.0	328	100.0
GASK350A	EPDM	1.0 - 3.5	328	100.0
GASK400A	EPDM	1.0 - 3.5	328	100.0
GASK500A	EPDM with PVC	1.0 - 2.0	328	100.0
GASK600A	EPDM with PVC	1.5 - 4.0	328	100.0

Item No.	Material	Grip Range mm	Roll Length	
			Ft	m
GASK800A	EPDM	2.0 - 4.0	164	50.0
GASK850A	EPDM	1.0 - 3.5	164	50.0
GASK900A	PVC	1.0 - 3.0	492	150.0
GASK930A	PVC	1.5 - 4.0	492	150.0
GASK960A	PVC	1.0 - 4.0	492	150.0
GASK1050A	EPDM with PVC	6.3	200	60.9
GASK2100A	EPDM & PVC over Metal	1.6	250	76.2