




RBS/STF Series
Bumpers/Stick-On Feet

- Specifications:
- Material: Polyurethane
 - Adhesive: Rubber
 - Color: Clear or Black
 - Application Temperature: 65°F to 150°F

Cylindrical
On A Pad




- Features:
- Will not tarnish, scratch, or discolor any surface
 - Easy to use - simply peel & stick
 - Adhesion works best on a smooth, clean & dry surface
 - Commonly used as rubber feet, cabinet stoppers, door stops & surface protectors

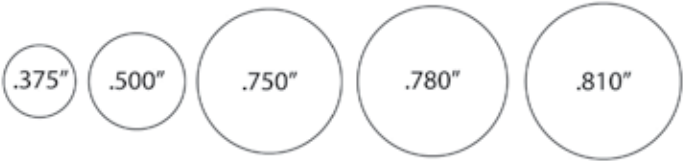

Actual Size (Diameter)

Item No.		Dia.		Height		Pieces/Pad	Pack Qty
Clear	Black	In	mm	In	mm		
RBS-34	RBS-34BK	0.375	9.5	0.125	3.2	300	300
RBS-35	RBS-35BK	0.375	9.5	0.190	4.8	50	200
RBS-5	RBS-5BK	0.500	12.7	0.060	1.5	200	200
RBS-1	RBS-1BK	0.500	12.7	0.140	3.6	200	200
RBS-6	RBS-6BK	0.500	12.7	0.250	6.4	50	200
RBS-11	RBS-11BK	0.620	15.7	0.400	10.2	128	128
RBS-44	RBS-44BK	0.750	19.1	0.160	4.1	98	98
RBS-41	RBS-41BK	0.780	19.8	0.200	5.1	84	84
RBS-24	RBS-24BK	0.810	20.6	0.120	3	72	72
RBS-72	RBS-72BK	1.240	31.5	0.100	2.5	32	32


Hemisphere
On A Pad

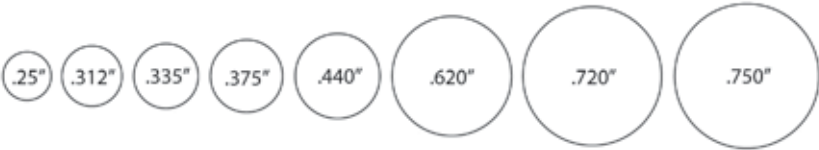

Actual Size (Diameter)

Item No.	Pack Qty.	Item No.	Pack Qty.	Dia.		Height		Pieces/Pad
Clear	Black	Clear	Black	In	mm	In	mm	
RBS-40	RBS-40BK	578	578	0.250	6.4	0.062	1.6	578
STFH250087A	STFH250087B	450	450	0.250	6.4	0.087	2.2	450
RBS-27	RBS-27BK	450	450	0.312	7.9	0.085	2.2	450
RBS-7	RBS-7BK	450	450	0.335	8.5	0.085	2.2	450
RBS-12	RBS-12BK	72	72	0.375	9.5	0.150	3.8	72
RBS-22	RBS-22BK	300	300	0.375	9.5	0.221	5.6	300
RBS-10		288		0.390	9.9	0.120	3.0	288
RBS-2	RBS-2BK	242	242	0.440	11.2	0.200	5.1	242
RBS-15	RBS-15BK	128	128	0.620	15.7	0.310	7.9	128
RBS-8	RBS-8BK	98	98	0.720	18.3	0.380	9.7	98
RBS-37	RBS-37BK	100	100	0.720	18.3	0.560	14.2	100
RBS-39	RBS-39BK	84	84	0.750	19.1	0.075	1.9	98

Square
On A Pad

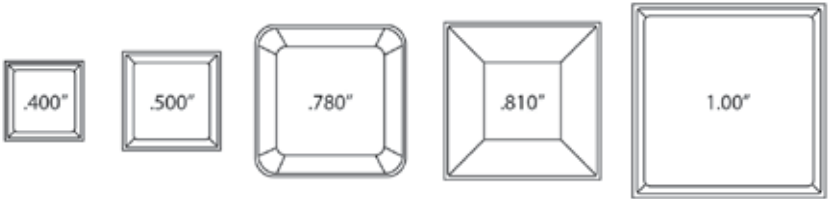

Actual Size (Width / Length)

Item No.	Pack Qty.	Item No.	Pack Qty.	Dia.		Height		Pieces/Pad
Clear	Black	Clear	Black	In	mm	In	mm	
RBS-20	RBS-20BK	242	242	0.400	10.2	0.100	2.5	242
RBS-32R	RBS-32RBK	200	200	0.500	12.7	0.120	3.0	200
RBS-3R	RBS-3RBK	200	200	0.500	12.7	0.230	5.8	200
RBS-4	RBS-4BK	100	100	0.750	19.1	0.340	8.6	100
RBS-29	RBS-29BK	98	98	0.780	19.8	0.250	6.4	98
RBS-19	RBS-19BK	98	98	0.810	20.6	0.300	7.6	98
RBS-36	RBS-36BK	55	55	1.000	25.4	0.180	4.6	55