


Dual Locking Circuit Board Support

DLCBSAT

Natural

Part Number		"A" Standoff Height	Std Pack Qty
UL94 V-2 Nylon 6/6, RMS-01	UL94 V-0 Nylon 6/6, RMS-19		
DLCBSAT-2-01	DLCBSAT-2-19	3.2	1000
DLCBSAT-3-01	DLCBSAT-3-19	4.8	1000
DLCBSAT-4-01	DLCBSAT-4-19	6.4	1000
DLCBSAT-5-01	DLCBSAT-5-19	7.9	1000
DLCBSAT-6-01	DLCBSAT-6-19	9.5	1000
DLCBSAT-7-01	DLCBSAT-7-19	11.1	1000
DLCBSAT-8-01	DLCBSAT-8-19	12.7	1000
DLCBSAT-9-01	DLCBSAT-9-19	14.3	1000
DLCBSAT-10-01	DLCBSAT-10-19	15.9	1000

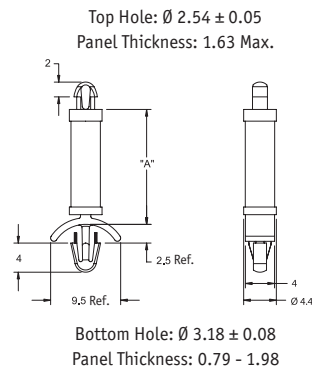

Snap Rivet Locking Circuit Board Support




SRLAHS

Natural

Rivet table	
Use Rivet Number	For Panel Thickness
SR-4050B /SR-4050W	0.7-1.6
SR-4060B /SR-4060W	1.5-2.7
SR-4070B /SR-4070W	2.7-3.7
SR-4080B /SR-4080W	3.7-4.7
SR-4090B /SR-4090W	4.7-5.7
SR-4100B /SR-4100W	5.7-6.7
SR-4120B /SR-4120W	7.2-8.7

Part Number		"A" Standoff Height	Std Pack Qty
UL94 V-2 Nylon 6/6, RMS-01	UL94 V-0 Nylon 6/6, RMS-19		
SRLAHS-7-01	SRLAHS-7-19	11.1	1000
SRLAHS-8-01	SRLAHS-8-19	12.7	1000
SRLAHS-10-01	SRLAHS-10-19	15.9	1000
SRLAHS-12-01	SRLAHS-12-19	19.1	1000
SRLAHS-14-01	SRLAHS-14-19	22.2	1000
SRLAHS-16-01	SRLAHS-16-19	25.4	1000

Top Hole: Snap-lock: Ø 4.75 ± 0.08
Panel Thickness: 0.79- 1.98

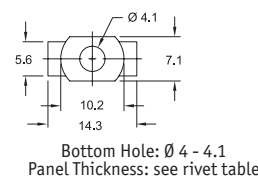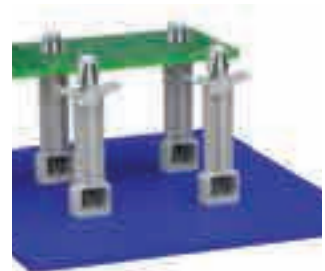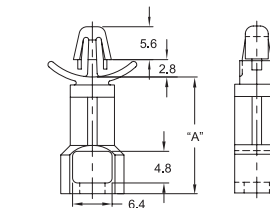

Snap Rivet Locking Circuit Board Support

SRLCBS

Natural Nylon 6/6, RMS-01

Part Number	"A" Standoff Height	Std Pack Qty
SRLCBS-6-01	9.5	1000
SRLCBS-7-01	11.1	1000
SRLCBS-8-01	12.7	1000
SRLCBS-10-01	15.9	1000
SRLCBS-12-01	19.1	1000
SRLCBS-14-01	22.2	1000
SRLCBS-16-01	25.4	1000

Rivet table	
Use Rivets Part Number	For Panel Thickness
SR-4050B /SR-4050W	0.7-1.6
SR-4060B /SR-4060W	1.5-2.7
SR-4070B /SR-4070W	2.7-3.7
SR-4080B /SR-4080W	3.7-4.7
SR-4090B /SR-4090W	4.7-5.7
SR-4100B /SR-4100W	5.7-6.7
SR-4120B /SR-4120W	7.2-8.7

Top Hole: Snap-lock: 4 ± 0.08
Panel Thickness: 1.57

