

"Stay Connected" with



Liquid Tight Cordgrips

a PennEngineering® Company

Consult Heyco
for Colors Other
Than Black



HEYCo-molded™ Liquid Tight Break-Thru Plugs

Mounting Hole Diameter Range: .500" (12,7 mm) to 1.500" (38,1 mm)*

PANEL DIMENSIONS				CABLE DIAMETER RANGE		PART NO. Black	PACKAGING		DESCRIPTION	PART DIMENSIONS			
Thickness at Locking Finger Steps		Mounting Hole Diameter*					BULK (Standard)	SMALL PACK ** <div>NEW</div>		A Head Diameter		B Overall Height	
in.	mm.	in.	mm.	in.	mm.					in.	mm.	in.	mm.

With Five Locking Finger Steps – For Panels up to .063" (1,6 mm) Thick

.02	0,5	.500	12,7	.08 - .20	2,0 - 5,1	C2008	1000	10	LTBP 500-063	.92	23,4	.32	8,1
		.625	15,9	.13 - .38	3,3 - 9,5	C2012	1000	10	LTBP 625-063	1.03	26,2		
.03	0,8	.750	19,1	.18 - .40	4,4 - 10,2	C2016	1000	10	LTBP 750-063	1.15	29,2		
		.875	22,2	.13 - .45	3,3 - 11,4	C2020	1000	10	LTBP 875-063	1.28	32,5		
.04	1,0	1.000	25,4	.20 - .72	5,1 - 18,2	C2022	1000	10	LTBP 1000-063	1.43	36,3		
		1.093	27,8	.25 - .77	6,4 - 19,4	C2024	1000	10	LTBP 1093-063	1.53	38,9		


With Seven Locking Finger Steps – For Panels from .063" (1,6 mm) to .250" (6,4 mm) Thick

.06	1,6	.500	12,7	.08 - .20	2,0 - 5,1	C2058	1000	10	LTBP 500-250	.92	23,4	.63	15,9
		.625	15,9	.13 - .38	3,3 - 9,5	C2062	1000	10	LTBP 625-250	1.03	26,2		
.08	2,0	.750	19,1	.18 - .40	4,4 - 10,2	C2066	1000	10	LTBP 750-250	1.15	29,2		
		.875	22,2	.13 - .45	3,3 - 11,4	C2070	1000	10	LTBP 875-250	1.28	32,5		
.13	3,2	1.000	25,4	.20 - .72	5,1 - 18,2	C2072	1000	10	LTBP 1000-250	1.43	36,3		
		1.093	27,8	.25 - .77	6,4 - 19,4	C2074	1000	10	LTBP 1093-250	1.53	38,9		
.20	5,1	1.375	34,9	.30 - .95	7,6 - 24,1	C2080	1000	10	LTBP 1375-250	1.80	45,7	.67	17,0
		1.500	38,1	.38 - 1.0	69,5 - 26,9	C2082	1000	10	LTBP 1500-250	1.93	49,0		

Standard color black. Consult Heyco for other colors.

*Consult Heyco for other Mounting Hole Diameters. Our Axcell Rapid Response Team is ready to meet your requirements.

**To order Small Packs, please add the suffix -P to Part No.; e.g., C2008-P

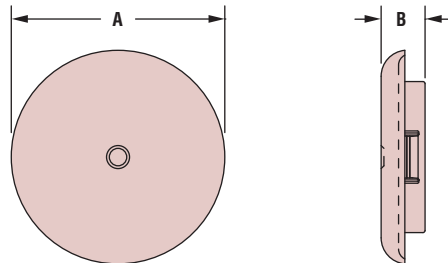

Materials
Certifications

Nylon 6/6 and TPE
Recognized under the Component Program of Underwriters' Laboratories
File E15331

Flammability Rating
Temperature Range
IP Rating

HB
-40°F (-40°C) to 212°F (100°C)
IP 67/68

*Quick
Specs*

“Stay Connected” with

HEYCO®

Bushings, Grommets, HEYcaps & Plugs

a PennEngineering® Company

Consult Heyco
for Colors Other
Than Black



HEYCo-molded™ Liquid Tight Break-Thru Plugs

Mounting Hole Diameter Range: .500" (12,7 mm) to 1.500" (38,1 mm)

Small Packs Available

PANEL DIMENSIONS				CABLE DIAMETER RANGE		PART NO. Black	PACKAGING		DESCRIPTION	PART DIMENSIONS			
Thickness at Locking Finger Steps		Mounting Hole Diameter*					BULK (Std)	SMALL PACK**		A Head Diameter		B Overall Height	
in.	mm.	in.	mm.	in.	mm.			NEW		in.	mm.	in.	mm.
With Five Locking Finger Steps for Panels up to .063" (1,6 mm) Thick													
.020	0,5	.500	12,7	.080 - .200	2,0 - 5,1	C2008	1000	10	LTBP 500-063	.92	23,4		
.032	0,8	.625	15,9	.130 - .375	3,3 - 9,5	C2012	1000	10	LTBP 625-063	1.03	26,2		
.040	1,0	.750	19,1	.175 - .400	4,4 - 10,2	C2016	1000	10	LTBP 750-063	1.15	29,2		
.048	1,2	.875	22,2	.130 - .450	3,3 - 11,4	C2020	1000	10	LTBP 875-063	1.28	32,5	.32	8,1
.063	1,6	1.000	25,4	.200 - .715	5,1 - 18,2	C2022	1000	10	LTBP 1000-063	1.43	36,3		
		1.093	27,8	.250 - .765	6,4 - 19,4	C2024	1000	10	LTBP 1093-063	1.53	38,9		



With Seven Locking Finger Steps for Panels from .063" (1,6 mm) to .250" (6,4 mm) Thick													
.063	1,6	.500	12,7	.080 - .200	2,0 - 5,1	C2058	1000	10	LTBP 500-250	.92	23,4		
.080	2,0	.625	15,9	.130 - .375	3,3 - 9,5	C2062	1000	10	LTBP 625-250	1.03	26,2		
.094	2,4	.750	19,1	.175 - .400	4,4 - 10,2	C2066	1000	10	LTBP 750-250	1.15	29,2		
.125	3,2	.875	22,2	.130 - .450	3,3 - 11,4	C2070	1000	10	LTBP 875-250	1.28	32,5	.63	15,9
.157	4,0	1.000	25,4	.200 - .715	5,1 - 18,2	C2072	1000	10	LTBP 1000-250	1.43	36,3		
.200	5,1	1.093	27,8	.250 - .765	6,4 - 19,4	C2074	1000	10	LTBP 1093-250	1.53	38,9		
.250	6,4	1.375	34,9	.300 - .950	7,6 - 24,1	C2080	1000	10	LTBP 1375-250	1.80	45,7	.67	17,0
		1.500	38,1	.375 - 1.060	9,5 - 26,9	C2082	1000	10	LTBP 1500-250	1.93	49,0		

Standard color black. Consult Heyco for other colors.

*Consult Heyco for other Mounting Hole Diameters. Our Axcell Rapid Response Team is ready to meet your requirements.

**To order Small Packs, please add the suffix -P to Part No., e.g., C2008-P

 - These **co-molded** nylon and elastomer parts function as **Liquid Tight Plugs** with an IP 67/68 rating, yet can be pierced by **round wire, cable or tubing** to function as **Liquid Tight Bushings** with the same resulting IP 67/68 rating.
- **Certified by UL under UL 635**
- For use in panels as thin as .020" (0,5 mm) and as thick as .250" (6,4 mm).
- Provide liquid tight closure when used as a plug. When pierced, function as a liquid tight bushing that convert raw edged holes to smooth, neat, insulated holes.
- Used as a liquid tight bushing, HEYCo-molded Liquid Tight Break-Thru Plugs insulate and mechanically protect electrical and telecommunications cable, tubing, hose, rope, and utility lines.
- Locking fingers snap into holes with fingertip pressure.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Withstand a push back force of greater than 35 pounds.
- Available in multiple sizes for use in .500" (12,7 mm) to 1.500" (38,1 mm) diameter holes.

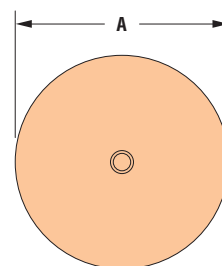

Materials
Certifications

Flammability Rating
Temperature Range
IP Rating



Nylon 6/6 and TPE
Recognized under the Component Program of Underwriters' Laboratories
File E15331
HB
-40°F (-40°C) to 212°F (100°C)
IP 67/68

"Stay Connected" with



Bushings, Grommets, HEYcaps & Plugs

a PennEngineering® Company

HEYCo-molded™ Liquid Tight Break-Thru Plugs

Mounting Hole Diameter Range: .500" (12,7 mm) to 1.500" (38,1 mm)

Small Packs Available



PANEL DIMENSIONS				CABLE DIAMETER RANGE		PART NO. Black	PACKAGING		DESCRIPTION	PART DIMENSIONS			
Thickness at Locking Finger Steps		Mounting Hole Diameter*			BULK (Std)		SMALL PACK**	A Head Diameter		B Overall Height			
in.	mm.	in.	mm.	in.	mm.						in.	mm.	in.
With Five Locking Finger Steps for Panels up to .063" (1,6 mm) Thick													
.020	0,5	.500	12,7	.080 - .200	2,0 - 5,1	C2008	1000	10	LTBP 500-063	.92	23,4	.32	8,1
.032	0,8	.625	15,9	.130 - .375	3,3 - 9,5	C2012	1000	10	LTBP 625-063	1.03	26,2		
.040	1,0	.750	19,1	.175 - .400	4,4 - 10,2	C2016	1000	10	LTBP 750-063	1.15	29,2		
.048	1,2	.875	22,2	.130 - .450	3,3 - 11,4	C2020	1000	10	LTBP 875-063	1.28	32,5		
.063	1,6	1.000	25,4	.200 - .715	5,1 - 18,2	C2022	1000	10	LTBP 1000-063	1.43	36,3		
		1.093	27,8	.250 - .765	6,4 - 19,4	C2024	1000	10	LTBP 1093-063	1.53	38,9		



With Seven Locking Finger Steps for Panels from .063" (1,6 mm) to .250" (6,4 mm) Thick

.063	1,6	.500	12,7	.080 - .200	2,0 - 5,1	C2058	1000	10	LTBP 500-250	.92	23,4	.63	15,9
.080	2,0	.625	15,9	.130 - .375	3,3 - 9,5	C2062	1000	10	LTBP 625-250	1.03	26,2		
.094	2,4	.750	19,1	.175 - .400	4,4 - 10,2	C2066	1000	10	LTBP 750-250	1.15	29,2		
.125	3,2	.875	22,2	.130 - .450	3,3 - 11,4	C2070	1000	10	LTBP 875-250	1.28	32,5		
.157	4,0	1.000	25,4	.200 - .715	5,1 - 18,2	C2072	1000	10	LTBP 1000-250	1.43	36,3		
.200	5,1	1.093	27,8	.250 - .765	6,4 - 19,4	C2074	1000	10	LTBP 1093-250	1.53	38,9	.67	17,0
.250	6,4	1.375	34,9	.300 - .950	7,6 - 24,1	C2080	1000	10	LTBP 1375-250	1.80	45,7		
		1.500	38,1	.375 - 1.060	9,5 - 26,9	C2082	1000	10	LTBP 1500-250	1.93	49,0		

Standard color black. Consult Heyco for other colors.

*Consult Heyco for other Mounting Hole Diameters. Our Axcell Rapid Response Team is ready to meet your requirements.

 **To order Small Packs, please add the suffix -P to Part No., e.g., C2008-P

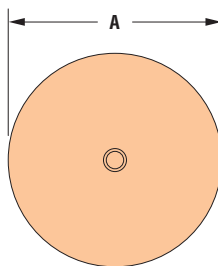

- These **co-molded** nylon and elastomer parts function as **Liquid Tight Plugs** with an IP 67/68 rating, yet can be pierced by **round wire, cable or tubing** to function as **Liquid Tight Bushings** with the same resulting IP 67/68 rating.
- **Certified by UL under UL 635**
- For use in panels as thin as .020" (0,5 mm) and as thick as .250" (6,4 mm).
- Provide liquid tight closure when used as a plug. When pierced, function as a liquid tight bushing that convert raw edged holes to smooth, neat, insulated holes.
- Used as a liquid tight bushing, HEYCo-molded Liquid Tight Break-Thru Plugs insulate and mechanically protect electrical and telecommunications cable, tubing, hose, rope, and utility lines.
- Locking fingers snap into holes with fingertip pressure.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Withstand a push back force of greater than 35 pounds.
- Available in multiple sizes for use in .500" (12,7 mm) to 1.500" (38,1 mm) diameter holes.

Materials

Nylon 6/6 and TPE

Certifications

Recognized under the Component Program of Underwriters' Laboratories File E15331

Flammability Rating

HB

Temperature Range

-40°F (-40°C) to 212°F (100°C)

IP Rating

67/68