





- **Molded from a nylon material which, in the event of a fire, will not burn and will not produce toxic gases.** Also formulated for sunlight resistance. Other Heyco products are available in this material—please consult Heyco.
- Close unneeded panel holes.
- Quick and easy installation.
- Convex, matte finish head tapers to a thin edge (Except HFP-187 glossy finish).
- Lock firmly into panel up to .125" (3,2 mm) thick.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Approximate Head Thickness: .062" (1,6 mm). Thickness may vary.
- Multiple sizes for use in .187" (4,7 mm) to 2.000" (50,8 mm) diameter holes. Consult Heyco for larger sizes.

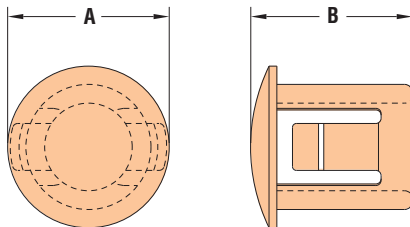

SINGLE PANEL THICKNESS DESIGN

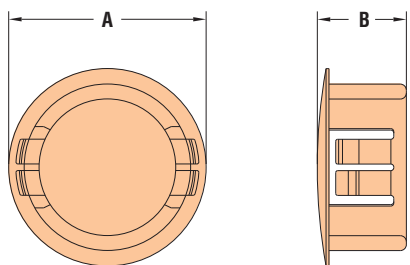

MULTIPLE PANEL THICKNESS DESIGN

Heyco® Halogen and Phosphorus-Free 94V-0 Hole Plugs

Heat Stabilized • Self Extinguishing • Nontoxic • UV Resistant

Mounting Hole Diameter Range: .187" (4,7 mm) to 2.000" (50,8 mm)

MOUNTING HOLE DIAMETER		PART NO. Black	DESCRIPTION	PART DIMENSIONS			
in.	mm.			A Head Diameter		B Overall Height	
				in.	mm.	in.	mm.

Single Locking Step for Panel Thickness up to .062" (1,6 mm)

.187	4,7	2593	HFP 187*	.25	6,4	.24	6,1
.250	6,4	2606	HFP 250	.31	7,9	.31	7,9
.312	7,9	2616	HFP 312	.38	9,5		

Multiple Locking Steps for Panel Thickness up to .125" (3,2 mm)

.375	9,5	2623	HFP 375	.47	11,9	.41	10,3
.437	11,1	2636	HFP 437	.53	13,5		
.500	12,7	2646	HFP 500	.58	14,7		
.625	15,9	2666	HFP 625	.72	18,2		
.750	19,1	2686	HFP 750	.92	23,4		
.875	22,2	2706	HFP 875	1.02	25,8	.45	11,5
1.000	25,4	2716	HFP 1000	1.20	30,6		
1.093 - 1.125	27,8 - 28,6	2729	HFP 1093	1.22	30,9		
1.250	31,7	2749	HFP 1250	1.38	34,9		
1.375	34,9	2759	HFP 1375	1.50	38,1		
1.500	38,1	2769	HFP 1500	1.69	42,8		
1.750	44,5	2779	HFP 1750	1.92	48,7		
2.000	50,8	2789	HFP 2000	2.17	55,1		

Multiple Locking Steps for Panel Thickness up to .250" (6,4 mm)

ALL NEW PRODUCTS

.500	12,7	3004F	HFPT 500	.58	14,7	.56	14,3
.625	15,9	3006F	HFPT 625 *	.73	18,5	.52	13,2
.750	19,1	3008F	HFPT 750 *	.91	23,1	.56	14,3
.875	22,2	3044F	HFPT 875	1.02	25,8		
1.000	25,4	3046F	HFPT 1000	1.20	30,6		
1.093-1.125	27,8-28,6	3018F	HFPT 1093	1.22	30,9		
1.250	31,7	3102F	HFPT 1250	1.38	34,9		
1.375	34,9	3106F	HFPT 1375	1.50	38,1		
1.500	38,1	3048F	HFPT 1500	1.67	42,4		
1.750	44,5	3027F	HFPT 1750	1.91	48,4		
2.000	50,8	3050F	HFPT 2000	2.17	55,1		
						.58	14,7

Standard color black.

*Convex, glossy finish head.

*Quick
Specs*

Material
Certifications

Nylon 6/6
Recognized under the Component Program of Underwriters' Laboratories File E51579

Flammability Rating
Temperature Range

Certified by the Canadian Standards Association File 8919
94V-0
-40°F (-40°C) to 221°F (105°C)



Heyco® Nylon Knock Out Seals and Thick Panel Knock Out Seals

Consult Heyco
for our Complete Line
of Dome Plugs

Mounting Hole Diameter Range: 1/2" to 2" Electrical Knock-outs
(.875" to 2.500" nominal)

- **Plug electrical knock-outs.**
- Molded in silver gray color to resemble galvanized steel.
- Install quickly with fingertip pressure (no tool required).
- Economical.
- Multiple trade sizes fit 1/2" to 2" knock-out holes.
- Lock firmly in boxes up to 1/8" thick, except for Part Number 4002 (KOS 2) and Thick Panel Knock-Out Seals (KOST's) which lock firmly in boxes up to 1/4" thick.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Approximate Head Thickness: .06" (1,6 mm). Thickness may vary.
- To adapt a Knock-Out to accept a Heyco Strain Relief, see page 4-37 for Knock-Out Adapters in the Heyco Catalog.

MOUNTING HOLE DIAMETER		TRADE SIZE	PART NO. Silver Gray	DESCRIPTION	PART DIMENSIONS			
in.	mm.				A Head Diameter		B Overall Height	
					in.	mm.	in.	mm.


Multiple Locking Steps for Panel Thickness up to .125" (3,2 mm)

.875	22,2	1/2	3997	KOS 1/2	1.02	25,8		
1.093	27,8	3/4	3998	KOS 3/4	1.22	31,0	.45	11,5
1.375	34,9	1	3999	KOS 1	1.50	38,1		
1.750	44,5	1-1/4	4000	KOS 1-1/4	1.91	48,4	.47	12,0
2.000	50,8	1-1/2	4001	KOS 1-1/2	2.16	54,9	.45	11,5

Multiple Locking Steps for Panel Thickness up to .250" (6,4 mm)

.875	22,2	1/2	3991	KOST 1/2	1.02	25,8		
1.093	27,8	3/4	3992	KOST 3/4	1.22	31,0		
1.375	34,9	1	3993	KOST 1	1.50	38,1	.56	14,3
1.750	44,5	1-1/4	3994	KOST 1-1/4	1.91	48,4		
2.000	50,8	1-1/2	3995	KOST 1-1/2	2.16	54,9	.58	14,7
2.500	63,5	2	4002	KOS 2	2.73	69,3	.75	19,1

Standard color silver gray.

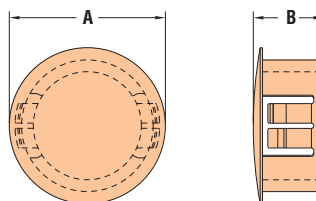

Heyco® Nylon V-0 Knock Out Seals

Multiple Locking Steps for Panel Thickness up to .13" (3,2 mm)

Mounting Hole Diameter Range: 1/2" to 1-1/2" Electrical Knock-outs
(.875" to 2.000" nominal)

- **Molded from a nylon material which, in the event of a fire, will not burn and will not produce toxic gases.** Also formulated for sunlight resistance.

MOUNTING HOLE DIAMETER		TRADE SIZE	PART NO. Black	DESCRIPTION	PART DIMENSIONS			
in.	mm.				A Head Diameter		B Overall Height	
					in.	mm.	in.	mm.

.875	22,2	1/2	2706	HFP 875	1.02	25,8		
1.093	27,8	3/4	2729	HFP 1093	1.22	31,0		
1.375	34,9	1	2759	HFP 1375	1.50	38,1	.45	11,5
1.750	44,5	1-1/4	2779	HFP 1750	1.91	48,4		
2.000	50,8	1-1/2	2789	HFP 2000	2.16	54,9		

Standard color black.

*Quick
Specs*

Material
Certifications



Nylon 6/6

Recognized under the Component Program of Underwriters' Laboratories, File E51579



Certified by Canadian Standards Association, File 8919

Flammability Rating
Temperature Range

KOS: 94V-2, HFP 94V-0

-40°F (-40°C) to 221°F (105°C)