



Heyco® Snap Bushings

Mounting Hole Diameter Range: 1.000" (25,4 mm) to 2.500" (63,5 mm)

MOUNTING HOLE DIAMETER		PART NO.		DESCRIPTION	PART DIMENSIONS					
		Black	White		A Inside Diameter		B Head Diameter		C Overall Height	
in.	mm.				in.	mm.	in.	mm.	in.	mm.
Multiple Locking Steps for Panel Thickness up to .125" (3,2 mm)										
1.000	25,4	2140	2141	SB 1000-12	.77	19,4	1.13	28,6	.45	11,5
1.093 - 1.125	27,8 - 28,6	2160	2161	SB 1093-13	.81	20,6	1.22	30,9		
		2163	2164	SB 1093-14	.88	22,2				
		2166	2167	SB 1093-15	.94	23,8				
1.187	30,2	2182	2183	SB 1187-15	.94	23,8	1.31	33,3		
1.250	31,8	2198	2199	SB 1250-15	.94	23,8	1.36	34,5		
		2201	2202	SB 1250-16	1.00	25,4	1.31	33,3		
1.375	34,9	2207	2208	SB 1375-14	.88	22,2	1.49	37,9		
		2210	2211	SB 1375-16	1.01	25,8				
1.500	38,1	2233	2234	SB 1500-17	1.06	27,0	1.61	40,9		
		2236	2237	SB 1500-18	1.13	28,6				
		2240	2241	SB 1500-21	1.31	33,3				
1.625	41,3	2273	2274	SB 1625-21	1.31	33,3	1.74	44,2		
1.750	44,5	2300	2301	SB 1750-22	1.38	34,9	1.88	47,6		
1.875	47,6	2287	2288	SB 1875-24	1.50	38,1	2.00	50,8		
2.000	50,8	2400	2401	SB 2000-26	1.64	41,6	2.13	54,0		
		2406	2414	SB 2000-28	1.75	44,5				
Multiple Locking Steps for Panel Thickness up to .250" (6,4 mm)										
2.093	53,1	2415	2416	SB 2.093-29	1.81	46,0	2.35	59,7	.72	18,3
2.250	57,2	2417	2418	SB 2.250-29	1.86	47,1	2.48	63,1		
2.500	63,5	2420	2421	SB 2.500-31	1.97	50,0	2.66	67,5		

Standard colors black and white. Consult Heyco for other colors.

Larger 3.000" (76,2 mm) to 6.000" (152,4 mm) Diameter Parts

Small Packs Available

MOUNTING HOLE DIAMETER		PART NO.		DESCRIPTION	PACKAGING		PART DIMENSIONS					
		Black	White		BULK (Std)	SMALL PACK* NEW	A Inside Diameter		B Head Diameter		C Overall Height	
in.	mm.						in.	mm.	in.	mm.	in.	mm.
Multiple Locking Steps for Panel Thickness up to .250" (6,4 mm)												
3.000	76,2	2461	2462	SB 3.000-39	300	10	2.47	62,7	3.15	80,0	.75	19,1
		2424	2425	SB 3.000-44	300	5	2.75	69,9	3.16	80,2	.72	18,3
3.375	85,7	2407	2408	SB 3.375-45	400	5	2.81	71,4	3.66	93,0	.72	18,3
3.500	88,9	2470	2471	SB 3.500-47	200	5	2.94	74,7				
4.000	101,6	2479	2480	SB 4.000-55	300	5	3.47	88,1	4.15	105,4	.74	18,8
5.000	127,0	2409	2410	SB 5.000-70	150	1	4.38	113,8	5.22	132,6		
6.000	152,4	2484	2485	SB 6.000-86	130	1	5.38	139,2	6.22	157,9		

Standard colors black and white. Consult Heyco for other colors.

*Small Pack available in Black color only. To order, please add the suffix -P to Part No., e.g., 2461-P

Material
Certifications

Nylon 6/6



Recognized under the Component Program of Underwriters' Laboratories, File E15331



Certified by Canadian Standards Association, File 8919

Flammability Rating
Temperature Range


94V-2

-.4°F (-18°C) to 221°F (105°C)

- Convert raw-edged holes to smooth, neat, insulated holes.
- Insulate and mechanically protect electrical and telecommunications cables, tubing, hose, rope, and utility lines.
- Locking fingers snap into holes with fingertip pressure.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Withstand a push back force of 35 pounds.
- Available in multiple sizes for use in .250" (6,4 mm) to 6.00" (152,4 mm) diameter holes.
- We offer the following brass-colored parts for lamp and lighting applications:
 - Part No. 2012, SB 312-3 Brass
 - Part No. 2033, SB 375-4 Brass
 - Part No. 2041, SB 437-4 Brass

NEW!

NEW!

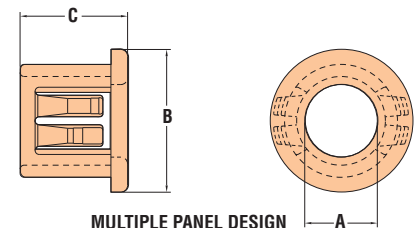

MULTIPLE PANEL DESIGN

*Quick
Specs*



Heyco® Thick Panel Snap Bushings

Mounting Hole Diameter Range: .375" (9,5 mm) to 2.0" (50,8 mm)


MOUNTING HOLE DIAMETER		PART NO.		DESCRIPTION	PART DIMENSIONS					
		Black	White		A Inside Diameter		B Head Diameter		C Overall Height	
in.	mm.				in.	mm.	in.	mm.	in.	mm.
Single Locking Step for Panel Thickness up to .170" (4,3 mm)										
.375	9,5	2017	2018	SB 375-281	.28	7,1	.47	11,9	.41	10,3
1.000	25,4	3085	3088	SBT 1000-790*	.80	20,3	1.13	28,8	.45	11,4
Multiple Locking Steps for Panel Thickness up to .250" (6,4 mm)										
.500	12,7	3126	3127	SBT 500-6	.39	9,9	.58	14,7	.56	14,3
.625	15,9	2830	2831	SB 625-500**	.50	12,7	.70	17,9	.53	13,5
.750	19,1	2840	2841	SB 750-625**	.63	15,9	.83	21,0		
.875	22,2	3104	3105	SBT 875-11	.69	17,5	.95	24,2	.56	14,3
1.000	25,4	3108	3109	SBT 1000-12	.77	19,4	1.13	28,6		
1.093-1.125	27,8-28,6	3128	3129	SBT 1093-15	.94	23,8	1.22	30,9		
1.187	30,2	3130	3131	SBT 1187-15	.94	23,8	1.31	33,3		
1.250	31,8	3132	3133	SBT 1250-16	1.00	25,4	1.31	33,2		
1.375	34,9	3110	3111	SBT 1375-16	1.00	25,4	1.50	38,1		
1.500	38,1	3112	3113	SBT 1500-21	1.31	33,3	1.62	41,2		
1.750	44,5	3114	3115	SBT 1750-22	1.38	34,9	1.88	47,6		
2.000	50,8	3116	3117	SBT 2000-26	1.63	41,3	2.13	54,0		

Standard colors black and white. Consult Heyco for other colors.

*Notched head, triple locking finger design.

**Single Locking Step for Panel Thickness up to .250" (6,4 mm).

- For use in mounting panels up to 1/4" thick.
- Convert raw-edged holes to smooth, neat, insulated holes.
- Insulate and mechanically protect electrical and telecommunications cables, tubing, hose, rope, and utility lines.
- Locking fingers snap into holes with fingertip pressure.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Withstand a push back force of >35 pounds.
- Available in multiple sizes for use in .375" (9,5 mm) to 2.000" (50,8 mm) diameter holes.

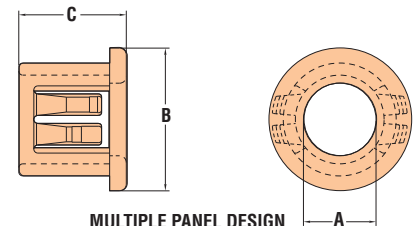

MULTIPLE PANEL DESIGN

Heyco® Knock-Out Snap Bushings

For use in electrical boxes and enclosures up to thicknesses shown.

BOX HOLE DIAMETER		TRADE SIZE	PART NO. Black	DESCRIPTION	A		PART DIMENSIONS		C	
					Inside Diameter	B		Overall Height		
in.	mm.				in.	mm.	in.	mm.	in.	mm.
Multiple Locking Steps for Box Thickness up to .125" (3,2 mm)										
.875	22,2	1/2	2126	SB 875-11	.69	17,5	.95	24,2	.45	11,5
1.093-1.125	27,8-28,6	3/4	2166	SB 1093-15	.94	23,8	1.22	30,9		
1.375	34,9	1	2210	SB 1375-16	1.01	25,8	1.49	37,3		
1.750	44,5	1-1/4	2300	SB 1750-22	1.38	34,9	1.88	47,6		
2.000	50,8	1-1/2	2406	SB 2000-28	1.75	44,5	2.13	54,0		
Multiple Locking Steps for Box Thickness up to .250" (6,4 mm)										
2.500	63,5	2	2420	SB 2.500-31	1.97	50.0	2.66	67,5	.72	8,3

Standard color black. Consult Heyco for white and other colors. For thicker boxes, see below.

Material

Nylon 6/6

Certifications

Recognized under the Component Program of Underwriters' Laboratories, File E15331

Certified by Canadian Standards Association, File 8919

Flammability Rating

94V-2

Temperature Range

-4°F (-18°C) to 221°F (105°C)

Quick
Specs