



Heyco® Thin Panel Bushings

Multiple Locking Steps for Panels as Thin as .020" (0,5 mm)

Mounting Hole Diameter Range: .218" (5,5 mm) to .875" (22,2 mm)*

- For use in panels as thin as .020" (0,5 mm).
- Convert raw-edged holes to smooth, neat, insulated holes.
- Insulate and mechanically protect electrical and telecommunications cables, tubing, hose, rope, and utility lines.
- Locking fingers snap into holes with fingertip pressure.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Withstand a push back force of greater than 35 pounds.
- Available in multiple sizes for use in .218" (5,5 mm) to .875" (22,2 mm) diameter holes.

PANEL DIMENSIONS				PART NO.		DESCRIPTION	PART DIMENSIONS					
Thickness at Locking Finger Steps		Mounting Hole Diameter*		Black	White		A Inside Diameter		B Head Diameter		C Overall Height	
in.	mm.	in.	mm.				in.	mm.	in.	mm.	in.	mm.

Three Steps to .048" (1,2 mm) Thick

.020	0,5	.218	5,5	2859N	2860N	B 218-125N	.13	3,2	.28	7,1	.24	6,0
		.250	6,4	2003N	2004N	B 250-187N	.19	4,7	.31	7,9		
		.281	7,1	2853N	2854N	B 281-218N	.22	5,6	.34	8,7		
		.312	7,9	2810N	2811N	B 312-250N	.25	6,3	.38	9,5		
.032	0,8	.343	8,7	2856N	2857N	B 343-218N	.22	5,6	.41	10,3	.25	6,4
		.375	9,5	2803N	2804N	B 375-250N	.25	6,3	.44	11,1		

Five Steps to .064" (1,6 mm) Thick


.020	0,5	.500	12,7	2820N	2821N	B 500-375N	.38	9,5	.56	14,3	.25	6,4
		.625	15,9	2827N	2828N	B 625-500N	.50	12,7	.70	17,9		
		.750	19,1	2836N	2837N	B 750-625N	.63	15,9	.94	23,8		
		.875	22,2	2850N	2851N	B 875-750N	.75	19,0	.95	24,0		

Standard colors black and white. Consult Heyco for other colors.

*Consult Heyco for other mounting hole diameters. Our Axcell Rapid Response Team is ready to meet your requirements.

Heyco® Thin Panel versus Shorty Bushings

Choose from Multiple Locking Steps, for the Fit and Finish Your Application Requires

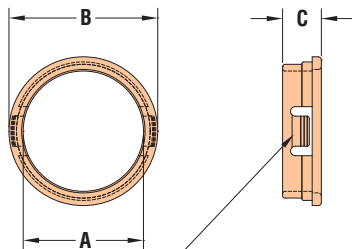

MULTIPLE FINGER STEPS FOR TIGHT, FINISHED PANEL FIT.

Mounting Hole Diameter		PANEL DIMENSIONS					PART NO.		DESCRIPTION
		Maximum Thickness Locking Steps					Black	White	
		inches/millimeters							
in.	mm.	.020 0,5	.032 0,8	.040 1,0	.048 1,2	.064 1,6			
.218	5,5	x	x		x		2859N	2860N	B 218-125N
						x	2859	2860	B 218-125
.250	6,4	x	x		x		2003N	2004N	B 250-187N
		x	x		x		2853N	2854N	B 281-218N
.281	7,1					x	2853	2854	B 281-218
		x	x		x		2810N	2811N	B 312-250N
.312	7,9					x	2810	2811	B 312-250
		x	x		x		2856N	2857N	B 343-218N
.343	8,7					x	2856	2857	B 343-218
		x	x		x		2803N	2804N	B 375-250N
.375	9,5					x	2803	2804	B 375-250
		x	x	x	x	x	2820N	2821N	B 500-375N
.500	12,7					x	2820	2821	B 500-375
		x	x	x	x	x	2827N	2828N	B 625-500N
.625	12,7					x	2827	2828	B 625-500
		x	x	x	x	x	2836N	2837N	B 750-625N
.750	19,1					x	2836	2837	B 750-625
		x	x	x	x	x	2850N	2851N	B 875-750N
.875	22,2					x	2850	2851	B 875-750

Quick
Specs

Material
Certifications

Nylon 6/6

Recognized under the Component Program of Underwriters' Laboratories, File E15331

Certified by Canadian Standards Association, File 8919

Flammability Rating
Temperature Range

94V-2

-4°F (-18°C) to 221°F (105°C)




Heyco® Shorty Bushings

Single Locking Step for Panel Thickness up to .062" (1,6 mm)

Mounting Hole Diameter Range: .187" (4,7 mm) to 1.093" (27,8 mm)

	MOUNTING HOLE DIAMETER		PART NO.		DESCRIPTION	PART DIMENSIONS							
			Black	White		A Inside Diameter		B Head Diameter		C Overall Height			
	in.	mm.				in.	mm.	in.	mm.	in.	mm.		
NEW!	.187	4,7	2800	2801	B 187-125	.13	3,2	.25	6,4	.24	6,0		
	.218	5,5	2859	2860	B 218-125	.13	3,2	.28	7,1				
	.281	7,1	2853	2854	B 281-218	.22	5,5	.34	8,7				
	.307	7,8	2808	2809	B 307-244	.24	6,2	.38	9,7				
	.312	7,9	2810	2811	B 312-250	.25	6,3	.38	9,7				
NEW!	.343	8,7	2856	2857	B 343-218	.22	5,5	.41	10,3	.25	6,4		
	.375	9,5	2803	2804	B 375-250	.25	6,3	.44	11,1				
	.390	9,9	2815	2816	B 390-265	.27	6,7	.43	10,9				
	.406	10,3	2806	2807	B 406-281	.28	7,1	.47	11,9				
	.437	11,1	2813	2814	B 437-312	.31	7,9	.50	12,7				
NEW!	.468	11,9	2817	2818	B 468-343	.34	8,6	.53	13,5			.26	6,5
	.500	12,7	2820	2821	B 500-375	.38	9,5	.56	14,3				
	.512	13,0	2822	2823	B 512-375								
NEW!	.531	13,5	2824	2825	B 531-406	.41	10,3	.59	15,1				
	.593	15,1	2833	2834	B 593-468	.47	11,9	.66	16,7				
	.625	15,9	2827	2828	B 625-500	.50	12,7	.70	17,9				
	.687	17,4	2832	2835	B 687-562	.57	14,4	.76	19,3				
	.750	19,1	2836	2837	B 750-625	.63	15,9	.83	21,0				
	.781	19,8	2844	2845	B 781-625	.63	15,9	.86	21,8				
	.875	22,2	2850	2851	B 875-750	.75	19,0	.95	24,0				
1.000	25,4	2847	2848	B 1000-875	.88	22,3	1.06	27,0					
	1.093	27,8	2838	2839	B 1093-969	.97	24,6	1.16	29,4	.26	6,5		

Standard colors black and white. Consult Heyco for other colors.

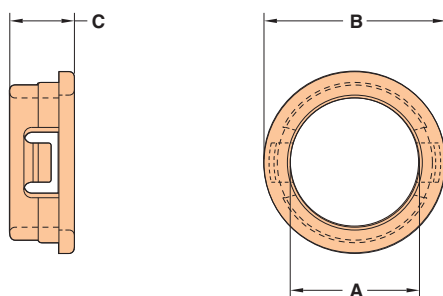

SINGLE PANEL DESIGN
(PANEL MAY BE THINNER)

Material
Certifications

Nylon 6/6



Recognized under the Component Program of Underwriters' Laboratories, File E15331



Certified by Canadian Standards Association, File 8919

Flammability Rating
Temperature Range

94V-2

-4°F (-18°C) to 221°F (105°C)

*Quick
Specs*