


Cable Ties

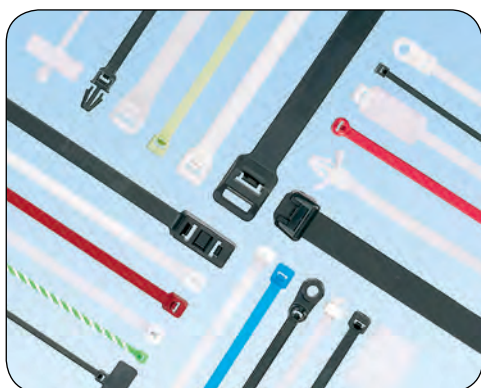

Panduit® offers the most complete selection of cable tie styles, sizes, materials and colors to meet our customers' needs. Panduit cable ties bundle, mount, and identify in countless indoor, outdoor, and harsh environment applications. Panduit cable ties, wiring accessories, and installation tools allow our customers to achieve the lowest total installed cost of managing wire and cable.



- Panduit continues to provide innovative new cable tie designs to meet our customers' application challenges
- Panduit cable ties and wiring accessories can be used in a variety of applications and environments, providing the optimal wire management solution
- Panduit offers a large selection of ergonomic cable tie installation tools – all with consistent, and reliable performance

Panduit leads the industry in the breadth and depth of available cable tie designs created from customer feedback on their application requirements. As with all Panduit products, quality in design and production along with customer service excellence are assured.

Cable Accessories Products Overview – Used with Cable Ties

Adhesive Backed Cable Tie Mounts

Pages B2.4 – B2.8



- Uses premium Panduit adhesive for a long-term, reliable bond
- Adhesive backing allows routing of wires and cables where mounting holes cannot be drilled
- Mounts should be used with Panduit cable ties for a complete wire routing solution

Screw Applied Cable Tie Mounts

Pages B2.9 – B2.15



- Screw/rivet applied cable tie mounts offer a countersunk or through hole in the mount through which a screw or rivet can be secured
- Offered in a wide selection of specialty materials for resistance to severe conditions such as heat, radiation, chemicals, and outdoor environments
- Available in styles ranging from low profile mounts with integral push-rivet to high stability cradle mounts for Extra-Heavy strength cable ties

Other Cable Tie Mounts

Pages B2.16 – B2.26










- Push mount designs lock into a hole in a metallic panel or in a blind masonry hole
- Edge clip mounts secure to a panel edge using metal barbs that dig into panel surface
- Stud mounts secure onto threaded bolts by screwing or hammering on the bolt
- Connector rings can be used to attach adjacent bundles to provide spacing and prevent vibration damage

4-Way Adhesive Backed Cable Tie Mounts

- Allow cable tie entry from all four sides
- Available in multiple sizes to match application load requirements
- Produced 2-up or 4-up for fast and easy liner removal to speed installation

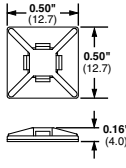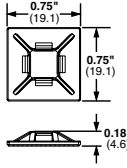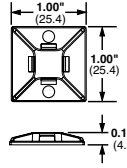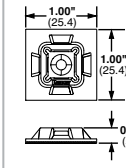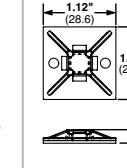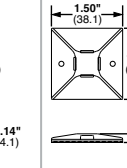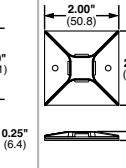

						
ABM1M 0.50" x 0.50"	ABMM 0.75" x 0.75"	ABM2S 1.00" x 1.00"	ABM100 1.00" x 1.00"	ABM112 1.12" x 1.12"	ABM3H 1.50" x 1.50"	ABM4H 2.00" x 2.00"
Accepts M Cable Ties	Accepts M, I Cable Ties	Accepts M, I, S Cable Ties	Accepts M, I, S Cable Ties	Accepts M, I, S Cable Ties	Accepts M, I, S, HS, LH, H, HLM Cable Ties	Accepts M, I, S, HS, LH, H, HLM Cable Ties

White Nylon 6.6; Rubber Adhesive; Indoor Environment	ABM1M-A-C 100 pc/pkg	-	-	ABM200-A-C** 100 pc/pkg	ABM112-A-C 100 pc/pkg	ABM3H-A-L 100 pc/pkg	ABM4H-A-L 100 pc/pkg
White Nylon 6.6; Acrylic Adhesive; Indoor/High Temp Environment	ABM1M-AT-C 100 pc/pkg	-	-	ABM100-AT-C 100 pc/pkg	ABM112-AT-C 100 pc/pkg	ABM3H-AT-L 100 pc/pkg	ABM4H-AT-L 100 pc/pkg
Black Weather Resistant Nylon 6.6; Acrylic Adhesive; Outdoor/High Temp Environment	-	-	-	ABM100-AT-C0 100 pc/pkg	ABM112-AT-C0 100 pc/pkg	-	-
White ABS; Rubber Adhesive; Indoor Environment	-	ABMM-A-C	ABM2S-A-C*^ 100 pc/pkg	-	-	-	-
White ABS; Acrylic Adhesive; Indoor/High Temp Environment	-	ABMM-AT-C 100 pc/pkg	ABM2S-AT-C 100 pc/pkg	-	-	-	-
Black Weather Resistant ABS; Acrylic Adhesive; Outdoor/High Temp Environment	-	ABMM-AT-C0 100 pc/pkg	ABM2S-AT-C0 100 pc/pkg	-	-	-	-
White ABS; Indoor Environment; User Supplied Adhesive	-	ABMM-D 500 pc/pkg	-	-	-	-	-
White ABS; Indoor Environment; User Supplied Adhesive or #6 screw(s)	-	-	ABM2S-S6-D 500 pc/pkg	-	-	-	-
White Nylon 6.6; Indoor Environment; User Supplied Adhesive or #6 (M3) screw(s)	-	-	-	ABM100-S6-C 100 pc/pkg	ABM112-S6-C 100 pc/pkg	ABM3H-S6-T 200 pc/pkg	ABM4H-S6-T 200 pc/pkg
Natural Flame Retardant Nylon 6.6; Indoor Environment; User Supplied Adhesive or #6 (M3) screw(s)	-	-	-	ABM100-S6-C69 100 pc/pkg	ABM112-S6-C69 100 pc/pkg	-	-

*Also available in Gray ABS material with Rubber Adhesive for Indoor environments. Part number ABM2S-A-C14

^Also available in Ivory ABS material with Rubber Adhesive for Indoor environments. Part number ABM2S-A-C15

**Also available in Ivory Nylon 6.6 material with Rubber Adhesive for Indoor environments. Part number ABM100-A-C15