


Cable Accessories



Panduit® provides a comprehensive offering of cable accessories. These accessories are engineered to speed installation and lower installed costs for routing and managing cable. Panduit cable accessories are designed and manufactured to meet applicable quality standards including International, UL, Military, ISO and Aerospace.

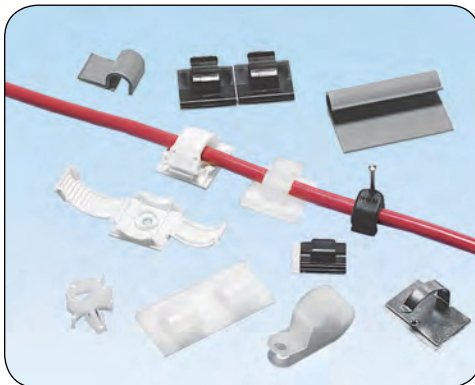


- **Largest selection of mounts, clips, and clamps for cable management**
- **Panduit cable ties and accessories can be used in a variety of applications and environments, providing the optimal cable management solution**
- **Installation methods include adhesive backed, user applied adhesive, screws, rivets or push barb**



Panduit mounts, clips, and clamps are manufactured in an environment committed to design innovation, high quality, and knowledgeable service to our customers. Adhesive backed mounts provide a strong adhesive bond for long-term reliability. Cable clips offer a one-piece solution to save time and reduce inventory. Harness board accessories speed the routing and forming of cable bundles in the fabrication of a harness. They hold bundles at a uniform height above the board and are ideal for use with Panduit manual and automatic cable tie tooling.

Adhesive Backed Cord Clips

- Cables are easily snapped into or out of the clips

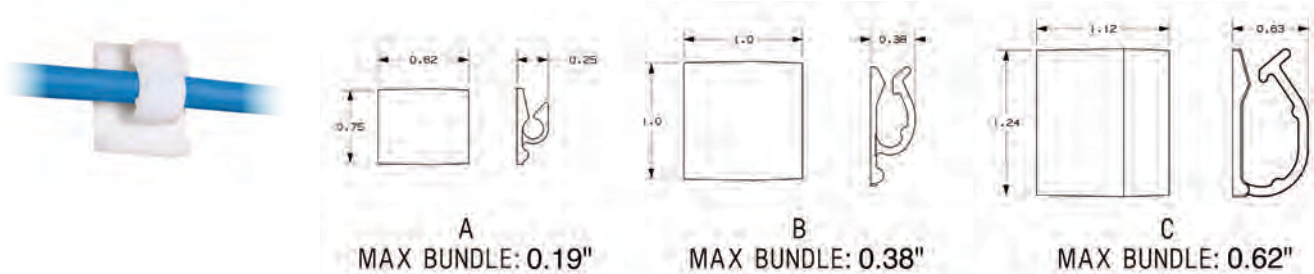


	Max. Bundle Dia.: 0.19"	Max. Bundle Dia.: 0.38"	Max. Bundle Dia.: 0.62"
Natural Nylon 6.6; Rubber Adhesive; 100 pc/pkg	ACC19-A-C	ACC38-A-C	ACC62-A-C
Natural Nylon 6.6; Acrylic Adhesive; 100 pc/pkg	ACC19-AT-C	ACC38-AT-C	ACC62-AT-C
Black Nylon 6.6; Rubber Adhesive; 100 pc/pkg	ACC19-A-C0	ACC38-A-C0	ACC62-A-C0
Black Weather Resistant Nylon 6.6; Acrylic Adhesive; 100 pc/pkg	ACC19-AT-C0	ACC38-AT-C0	ACC62-AT-C0
Black Heat Stabilized Weather Resistant Nylon; High Bond Acrylic Adhesive, 1,000 pc/pkg	ACC19-AV-M300*	ACC38-AV-M300*	ACC62-AV-M300*

*Not UL recognized

Push Mount Cord Clip

- Cables are easily snapped into or out of clips
- Winged design holds mount in place even in applications where vibration is present
- Design of wing provides added stability

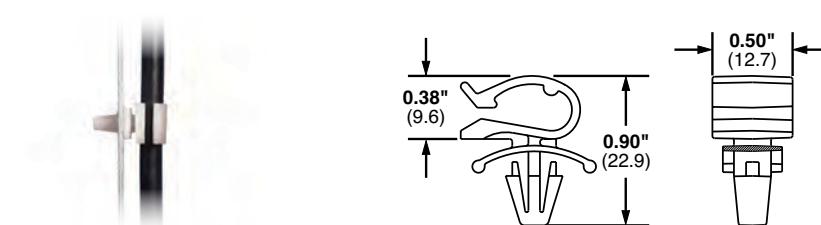

Part Number	Max. Bundle Diameter		Max. Panel Thickness		Panel Hole Diameter		Material	Color	Environment	Mounting Method	Std. Pkg. Qty.	Std. Ctn. Qty.
	In.	mm	In.	mm	In.	mm						
PMCC38H25-C	0.38	9.6	0.105	2.7	0.250	6.4	Nylon 6.6	Natural	Indoors	Push Barb	100	1000
PMCC38H25-M0	0.38	9.6	0.105	2.7	0.250	6.4	Weather Resistant Nylon 6.6	Black	Outdoors		1000	5000