


## Cable Accessories



Panduit® provides a comprehensive offering of cable accessories. These accessories are engineered to speed installation and lower installed costs for routing and managing cable. Panduit cable accessories are designed and manufactured to meet applicable quality standards including International, UL, Military, ISO and Aerospace.

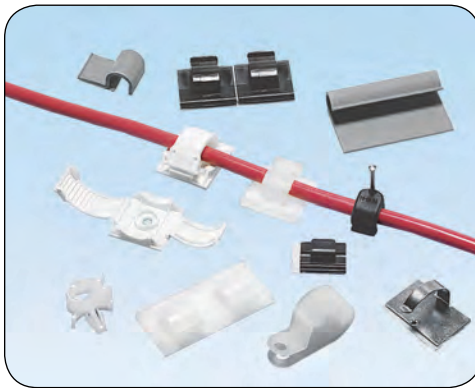


- **Largest selection of mounts, clips, and clamps for cable management**
- **Panduit cable ties and accessories can be used in a variety of applications and environments, providing the optimal cable management solution**
- **Installation methods include adhesive backed, user applied adhesive, screws, rivets or push barb**



Panduit mounts, clips, and clamps are manufactured in an environment committed to design innovation, high quality, and knowledgeable service to our customers. Adhesive backed mounts provide a strong adhesive bond for long-term reliability. Cable clips offer a one-piece solution to save time and reduce inventory. Harness board accessories speed the routing and forming of cable bundles in the fabrication of a harness. They hold bundles at a uniform height above the board and are ideal for use with Panduit manual and automatic cable tie tooling.

# Flat Cable Clips


- Use with any width flat cable for a maximum stack height of 0.17 inches (4.3mm)
- Low profile design holds wires, cables, and tubing
- For indoor use only
- Material: PVC

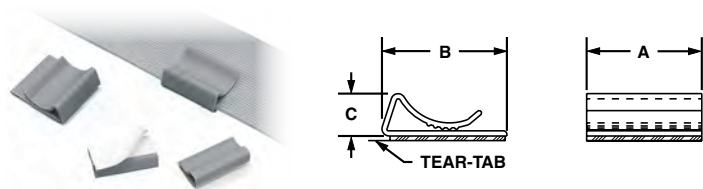

Part Number	Cable Width	Length A		Width B		Height C		Color	Mounting Method	Std. Pkg. Qty.	Std. Ctn. Qty.
		In.	mm	In.	mm	In.	mm				
FCC5-A-C8	Any width flat cable	1.00	25.4	0.56	14.2	0.29	7.4	Gray	Rubber	100	1000
FCC-A-C8		1.00	25.4	1.09	27.7	0.38	9.7			100	1000

# Pan-Clamp™ Heavy Duty Fixed Diameter Clamps

- One-piece design significantly reduces installation time
- Integrated ribs prevent rotation of cable bundles and ensures secure grip on hoses
- Material: Impact modified Weather Resistant Nylon 6.6

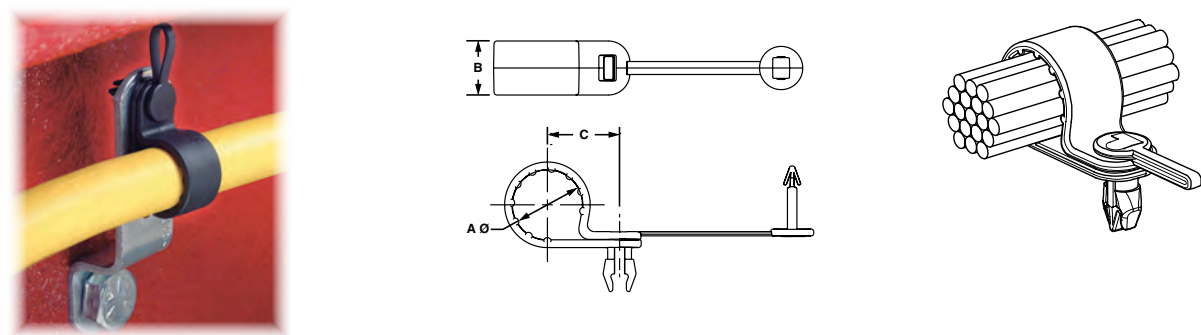

Part Number	Max. Bundle Diameter A		Width B		Bundle Offset C		Max. Panel Thickness		Panel Hole Diameter		Color	Std. Pkg. Qty.	Std. Ctn. Qty.
	In.	mm	In.	mm	In.	mm	In.	mm	In.	mm			
PC038-H25D-C0	0.38	9.5	0.62	15.7	0.64	16.3	0.13	3.2	0.28	7.1	Black	100	500
PC050-H25D-C0	0.50	12.7	0.62	15.7	0.71	17.9	0.13	3.2	0.28	7.1		100	500
PC062-H25D-C0	0.63	15.8	0.62	15.7	0.77	19.5	0.13	3.2	0.28	7.1		100	500
PC075-H25D-C0	0.75	19.1	0.62	15.7	0.83	21.1	0.13	3.2	0.28	7.1		100	1000
PC087-H25D-C0	0.88	22.1	0.62	15.7	0.89	22.7	0.13	3.2	0.28	7.1		100	1000
PC100-H25D-C0	1.00	25.4	0.62	15.7	0.96	24.3	0.13	3.2	0.28	7.1		100	1000
PC112-H25D-C0	1.13	28.5	0.62	15.7	1.02	25.8	0.13	3.2	0.28	7.1		100	1000
PC125-H25D-C0	1.25	31.8	0.62	15.7	1.08	27.4	0.13	3.2	0.28	7.1		100	1000