

Cable Accessories



Panduit® provides a comprehensive offering of cable accessories. These accessories are engineered to speed installation and lower installed costs for routing and managing cable. Panduit cable accessories are designed and manufactured to meet applicable quality standards including International, UL, Military, ISO and Aerospace.




- **Largest selection of mounts, clips, and clamps for cable management**
- **Panduit cable ties and accessories can be used in a variety of applications and environments, providing the optimal cable management solution**
- **Installation methods include adhesive backed, user applied adhesive, screws, rivets or push barb**



Panduit mounts, clips, and clamps are manufactured in an environment committed to design innovation, high quality, and knowledgeable service to our customers. Adhesive backed mounts provide a strong adhesive bond for long-term reliability. Cable clips offer a one-piece solution to save time and reduce inventory. Harness board accessories speed the routing and forming of cable bundles in the fabrication of a harness. They hold bundles at a uniform height above the board and are ideal for use with Panduit manual and automatic cable tie tooling.

Fixed Diameter Cable Clamps

- Durable Nylon 6.6 cable clamps

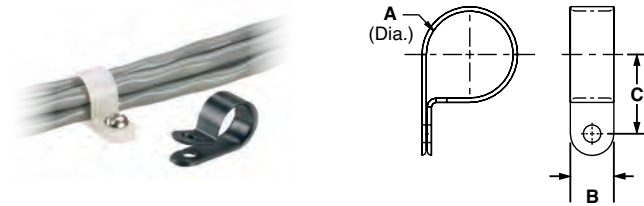

Part Number	Max. Bundle Diameter A		Width B		Bundle Offset C		Mounting Method	Std. Pkg. Qty.	Std. Ctn. Qty.
	In.	mm	In.	mm	In.	mm			
CCS12-S8-C	0.12	3.1	0.37	9.4	0.33	8.4	#8 (M4) Screw	100	500
CCS19-S8-C	0.19	4.8	0.37	9.4	0.43	10.9	#8 (M4) Screw	100	500
CCS25-S8-C	0.25	6.3	0.37	9.4	0.41	10.4	#8 (M4) Screw	100	500
CCS25-S10-C	0.25	6.3	0.37	9.4	0.41	10.4	#10 (M5) Screw	100	500
CCS31-S8-C	0.31	7.9	0.37	9.4	0.49	12.4	#8 (M4) Screw	100	500
CCS38-S8-C	0.38	9.5	0.37	9.4	0.59	15.0		100	500
CCS44-S8-C	0.44	11.1	0.37	9.4	0.57	14.5		100	500
CCS50-S8-C	0.50	12.7	0.37	9.4	0.60	15.2		100	500
CCH12-S10-C	0.12	3.1	0.50	12.7	0.36	9.1	#10 (M5) Screw	100	500
CCH19-S10-C	0.19	4.8	0.50	12.7	0.42	10.7		100	500
CCH25-S10-C	0.25	6.3	0.50	12.7	0.46	11.7		100	500
CCH31-S10-C	0.31	7.9	0.50	12.7	0.50	12.7		100	500
CCH38-S10-C	0.38	9.5	0.50	12.7	0.53	13.5		100	500
CCH44-S10-C	0.44	11.1	0.50	12.7	0.56	14.2		100	500
CCH50-S10-C	0.50	12.7	0.50	12.7	0.59	15.0		100	500
CCH56-S10-C	0.56	14.2	0.50	12.7	0.61	15.5		100	500
CCH62-S10-C	0.62	15.7	0.50	12.7	0.65	16.5		100	500
CCH69-S10-C	0.69	17.5	0.50	12.7	0.75	19.1		100	500
CCH75-S10-C	0.75	19.1	0.50	12.7	0.78	19.8		100	500
CCH81-S10-C	0.81	20.6	0.50	12.7	0.81	20.6		100	500
CCH87-S10-C	0.87	22.1	0.50	12.7	0.84	21.3		100	500
CCH100-S10-C	1.00	25.4	0.50	12.7	0.91	23.1		100	500
CCH112-S10-C	1.12	28.4	0.50	12.7	0.97	24.6		100	500
CCH119-S10-C	1.19	30.2	0.50	12.7	1.00	25.4		100	500
CCH125-S10-C	1.25	31.8	0.50	12.7	1.06	26.9		100	500
CCH138-S10-C	1.37	34.8	0.50	12.7	1.12	28.4		100	500
CCH150-S10-C	1.50	38.1	0.50	12.7	1.19	30.2		100	500

All parts listed are also available in black weather resistant material (add suffix 0). Bulk package only.