


SHAFT EXTENSIONS

1/4", 3/8" Bores

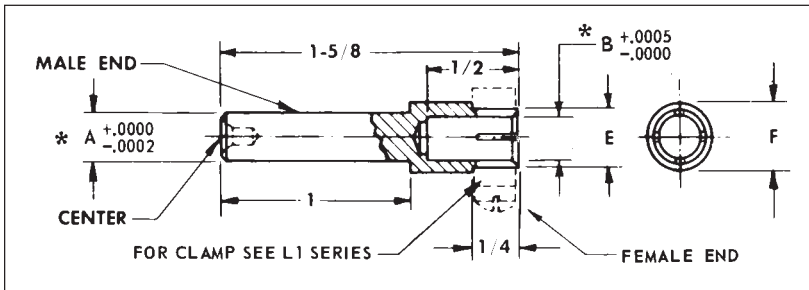

Material: 303 Stainless Steel


Shaft Size	A*	B**	E	F	Part No.
Male to Female					
1/4 to 1/4	.2497	.2498	.312	.375	AU-3
3/16 to 1/4	.1872	.2498	.312	.375	AU-6
1/4 to 1/8	.2497	.1248	.188	.250	AU-8
1/4 to 3/8	.2497	.3748	.437	.500	AU-11
3/8 to 1/4	.3747	.2498	.312	.375	AU-12

*Inch Shaft Dia. Toler. $\begin{smallmatrix} +.0000 \\ -.0002 \end{smallmatrix}$

**Inch Bores Toler. $\begin{smallmatrix} +.0005 \\ -.0000 \end{smallmatrix}$

*Diameters Concentric Within .0005 T.I.R.

STAINLESS THREADED STOCK — #2-56 To 3/8 -16

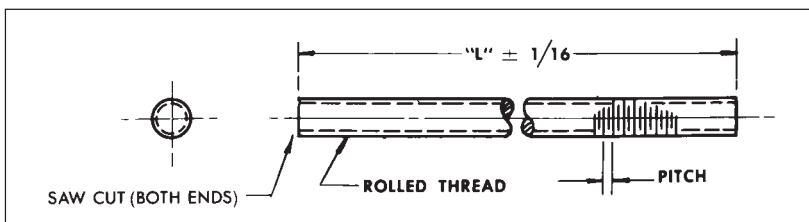


Material: 300 Series Stainless Steel

Thread	D	Pitch	L	Part No.
# 2-56	.086	.018	12	A9-10
# 4-40	.112	.025		A9-11
# 6-32	.138	.031		A9-1
# 8-32	.164	.031		A9-2
#10-32	.190	.031	16	A9-4
1/4 -20	1/4	.050	24	A9-5
1/4 -28	1/4	.036		A9-6
5/16-18	5/16	.055		A9-7
3/8 -16	3/8	.062		A9-8

Other Lengths, Diameters and Modifications Available,
Consult Factory.

STAINLESS THREADED STUDS — #6-32 To 1/4 -20

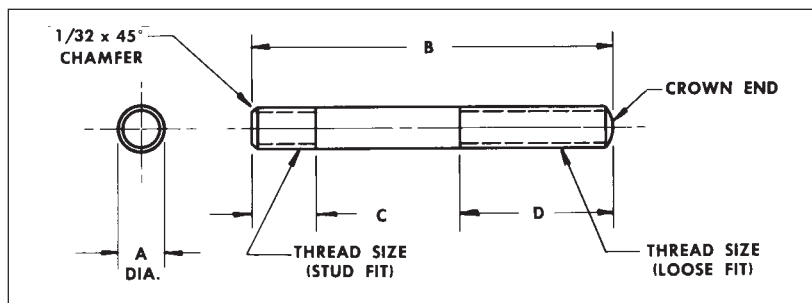

Material: 303 Stainless Steel

Thread Size	A	B	C	D	Part No.
#6-32	.138	1	7/32	1/2	2040
		1-1/4		5/8	2041
		1-1/2		3/4	2042
		1-3/4		3/4	2043
		2		3/4	2044
#8-32	.164	1	7/32	1/2	2045
		1-1/4		5/8	2046
		1-1/2		3/4	2047
		1-3/4		3/4	2048
		2		3/4	2049

Thread Size	A	B	C	D	Part No.
#10-32	.190	1	7/32	1/2	2055
		1-1/4		5/8	2056
		1-1/2		3/4	2057
		1-3/4		3/4	2058
		2		3/4	2059
1/4-20	.250	1-1/4	9/32	5/8	2060
		1-1/2		5/8	2061
		1-3/4		3/4	2062
		2		3/4	2063
		2-1/2		3/4	2064
		3		1	2065