

Aluminum Fan Filters - 06 Series


These tested and proven filters provide maximum airflow with effective filtering. Mill and stainless steel finishes are offered to enhance EMI/RFI shielding as well as an anodized finish for aesthetic purposes. The tightly woven corrugated mesh screen is encased in a formed aluminum frame built for ruggedness and durability. The filters are designed to fit any standard 60mm - 2 1/2", 80mm - 3 1/8", 92mm - 3 5/8" and 120mm - 4 1/2" tubeaxial fan. The units are easily washed in a solvent or degreaser and can be mounted directly to the fan or to a panel.



Part Number	Use With Fan Size		Finish	Size (in)		Mounting Hole Diameter	Mounting Hole Center
	mm	in.		Height (sq.)	Thickness		
60 mm - 2 1/2"							
06250-B	60	2 1/2	Anodized (Black)	2.36	.138	.170 (4 Places)	1.97
06250-M	60	2 1/2	Mill (No Finish)	2.36	.138	.170 (4 Places)	1.97
06250-SS	60	2 1/2	Stainless Steel	2.36	.138	.170 (4 Places)	1.97
80 mm - 3 1/8"							
06325-B	80	3 1/8	Anodized (Black)	3.30	.138	.170 (4 Places)	2.81
06325-M	80	3 1/8	Mill (No Finish)	3.30	.138	.170 (4 Places)	2.81
06325-SS	80	3 1/8	Stainless Steel	3.30	.138	.170 (4 Places)	2.81
92 mm - 3 5/8"							
06362-B	92	3 5/8	Anodized (Black)	3.62	.138	.170 (4 Places)	3.25
06362-M	92	3 5/8	Mill (No Finish)	3.62	.138	.170 (4 Places)	3.25
06362-SS	92	3 5/8	Stainless Steel	3.62	.138	.170 (4 Places)	3.25
120 mm - 4 1/2"							
06450-B	120	4 1/2	Anodized (Black)	4.67	.138	.170 (4 Places)	4.13
06450-M	120	4 1/2	Mill (No Finish)	4.67	.138	.170 (4 Places)	4.13
06450-SS	120	4 1/2	Stainless Steel	4.67	.138	.170 (4 Places)	4.13

Fan Power Cords - 07 Series

Fan-S offers four configurations of high quality fan power cords designed to be used with tubeaxial fans with a strain relief for added safety. UL and cUL rated 10 Amps/125 Volt with special configurations such as daisy chain, special length and color are available.

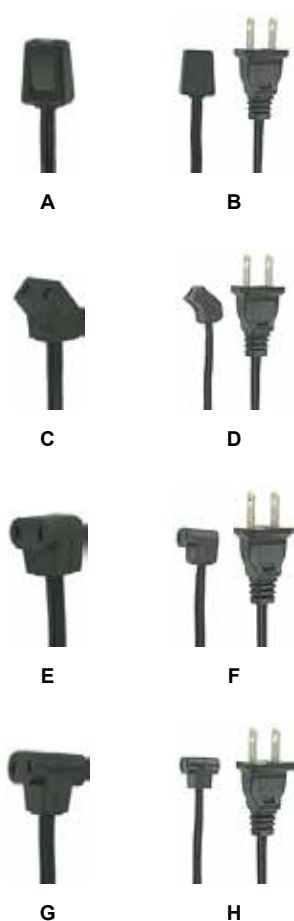

Part Number	Cord Length		Style	Figure	Cordage
	mm	in.			
07100-12	305	12	Straight	A	SPT-1(18/2)
07100-24	610	24	Straight	A	SPT-1(18/2)
07100-36	915	36	Straight	A	SPT-1(18/2)
07100-40	1016	40	Straight	A	SPT-1(18/2)
07100-50	1270	50	Straight	A	SPT-1(18/2)
07100-60	1524	60	Straight	A	SPT-1(18/2)
07100-80	2034	80	Straight	A	SPT-1(18/2)
07100-SP024	610	24	Straight	B	SPT-1(18/2)
07100-SP036	915	36	Straight	B	SPT-1(18/2)
07100-SP072	1829	72	Straight	B	SPT-1(18/2)
07145-12	305	12	45°	C	SPT-1(18/2)
07145-24	610	24	45°	C	SPT-1(18/2)
07145-36	915	36	45°	C	SPT-1(18/2)
07145-40	1016	40	45°	C	SPT-1(18/2)
07145-50	1270	50	45°	C	SPT-1(18/2)
07145-60	1524	60	45°	C	SPT-1(18/2)
07145-80	2034	80	45°	C	SPT-1(18/2)
07145-SP024	610	24	45°	D	SPT-1(18/2)
07145-SP036	915	36	45°	D	SPT-1(18/2)
07145-SP072	1829	72	45°	D	SPT-1(18/2)
07190-12	305	12	90°	E	SPT-1(18/2)
07190-24	610	24	90°	E	SPT-1(18/2)
07190-36	915	36	90°	E	SPT-1(18/2)
07190-40	1016	40	90°	E	SPT-1(18/2)
07190-50	1270	50	90°	E	SPT-1(18/2)
07190-60	1524	60	90°	E	SPT-1(18/2)
07190-80	2034	80	90°	E	SPT-1(18/2)
07190-SP024	610	24	90°	F	SPT-1(18/2)
07190-SP036	915	36	90°	F	SPT-1(18/2)
07190-SP072	1829	72	90°	F	SPT-1(18/2)
07199-12	305	12	T-Type	G	SPT-1(18/2)
07199-24	610	24	T-Type	G	SPT-1(18/2)
07199-36	915	36	T-Type	G	SPT-1(18/2)
07199-40	1016	40	T-Type	G	SPT-1(18/2)
07199-50	1270	50	T-Type	G	SPT-1(18/2)
07199-60	1524	60	T-Type	G	SPT-1(18/2)
07199-80	2034	80	T-Type	G	SPT-1(18/2)
07199-SP024	610	24	T-Type	H	SPT-1(18/2)
07199-SP036	915	36	T-Type	H	SPT-1(18/2)
07199-SP072	1829	72	T-Type	H	SPT-1(18/2)

Fan Accessories Guide – AC Fans

Fan Series	Wire Form Fan Guard	Aluminum Fan Filters	Plastic Fan Guards	Plastic Fan Filter Assemblies	QLM Vibration Sleeve	Fan Cords
FAA1-08025	08132, 08172	06325-B, 06325-M, 06325-SS	09252-G, 09080-G, 09081-G, 09325-G	09325-F/**		07100, 07145, 07190, 07199
FAA1-08038	08132, 08172	06325-B, 06325-M, 06325-SS	09252-G, 09080-G, 09081-G, 09325-G	09325-F/**		07100, 07145, 07190, 07199
FAA1-09225	08134, 08174, 08189	06362-B, 06362-M, 06362-SS	09362-G, 09363-G	09362-F/**		07100, 07145, 07190, 07199
FAA1-12025	08129, 08130, 08141, 08170, 08213	06450-B, 06450-M, 06450-SS	09120-G, 09121-G, 09122-G, 09123-G, 09450-G	09450-F/**		07100, 07145, 07190, 07199
FAA1-12038-A	08129, 08130, 08141, 08170, 08213	06450-B, 06450-M, 06450-SS	09120-G, 09121-G, 09122-G, 09123-G, 09450-G	09450-F/**	QLM-119-40-10, QLM-119-40-20	07100, 07145, 07190, 07199
FKA1-17251	08125		09651-G			07100, 07145, 07190, 07199
FKA2-17251	08125		09651-G			07100, 07145, 07190, 07199
FKA2-17689	08190					07100, 07145, 07190, 07199
FKA2-18065	08717					07100, 07145, 07190, 07199
FKA2-20572						07100, 07145, 07190, 07199
FKA2-25489	08127, 08155, 08243-SS					07100, 07145, 07190, 07199
FKA2-28089	08719					07100, 07145, 07190, 07199
FKA2-28089-A	08719					07100, 07145, 07190, 07199
FDA2-17238	08125		09651-G			07100, 07145, 07190, 07199
FDA2-17238 IP56M	08125		09651-G			07100, 07145, 07190, 07199
FDA2-17251	08125		09651-G			07100, 07145, 07190, 07199
FDA2-17251 IP56M	08125		09651-G			07100, 07145, 07190, 07199
FDA2-R17251	08126		09650-G	09650-F/**		07100, 07145, 07190, 07199
FDA2-R17251 IP56M	08126		09650-G	09650-F/**		07100, 07145, 07190, 07199
FDA2-17255	08126		09650-G	09650-F/**		07100, 07145, 07190, 07199
FDA2-17255 IP56M	08126		09650-G	09650-F/**		07100, 07145, 07190, 07199
FDA2-22580	08718					
FDA2-22580 IP56M	08718					
FDA2-25489	08127, 08155, 08243-SS					07100, 07145, 07190, 07199
FDA2-25489 IP56M	08127, 08155, 08243-SS					07100, 07145, 07190, 07199
FDA2-28080	08719					
FDA2-28080 IP56M	08719					

Fan Accessories Guide - DC Fans

Fan Series	Wire Form Fan Guard	Aluminum Fan Filters	Plastic Fan Guards	Plastic Fan Filter Assemblies	QLM Vibration Sleeve
FAD1-02510	08245				
FAD1-03010	08346				
FAD1-04010	08149		09150-G	09150-F/**	
FAD1-04020	08149		09150-G	09150-F/**	
FAD1-05010	08148				
FAD1-06020	08147	06250-B, 06250-M, 06250-SS	09250-G	09250-F/**	
FAD1-06025	08147	06250-B, 06250-M, 06250-SS	09250-G	09250-F/**	
FAD1-08015	08132, 08172	06325-B, 06325-M, 06325-SS	09252-G, 09080-G, 09081-G, 09325-G	09325-F/**	
FAD1-08015 IC	08132, 08172	06325-B, 06325-M, 06325-SS	09252-G, 09080-G, 09081-G, 09325-G	09325-F/**	
FAD1-08025	08132, 08172	06325-B, 06325-M, 06325-SS	09252-G, 09080-G, 09081-G, 09325-G	09325-F/**	QLM-80-40-10, QLM-80-40-20
FAD1-08025 IC	08132, 08172	06325-B, 06325-M, 06325-SS	09252-G, 09080-G, 09081-G, 09325-G	09325-F/**	QLM-80-40-10, QLM-80-40-20
FAD1-08032	08132, 08172	06325-B, 06325-M, 06325-SS	09252-G, 09080-G, 09081-G, 09325-G	09325-F/**	QLM-80-40-10, QLM-80-40-20
FAD1-08038	08132, 08172	06325-B, 06325-M, 06325-SS	09252-G, 09080-G, 09081-G, 09325-G	09325-F/**	QLM-80-40-10, QLM-80-40-20
FAD1-09225	08134, 08174, 08189	06362-B, 06362-M, 06362-SS	09362-G, 09363-G	09362-F/**	QLM-92-40-10, QLM-92-40-20
FAD1-09225 IC	08134, 08174, 08189	06362-B, 06362-M, 06362-SS	09362-G, 09363-G	09362-F/**	QLM-92-40-10, QLM-92-40-20
FAD1-12025	08129, 08130, 08141, 08170, 08213	06450-B, 06450-M, 06450-SS	09120-G, 09121-G, 09122-G, 09123-G, 09450-G	09450-F/**	QLM-119-50-10, QLM-119-50-20
FAD1-12032	08129, 08130, 08141, 08170, 08213	06450-B, 06450-M, 06450-SS	09120-G, 09121-G, 09122-G, 09123-G, 09450-G	09450-F/**	QLM-119-50-10, QLM-119-50-20
FAD1-12038	08129, 08130, 08141, 08170, 08213	06450-B, 06450-M, 06450-SS	09120-G, 09121-G, 09122-G, 09123-G, 09450-G	09450-F/**	QLM-119-40-10, QLM-119-40-20
FAD1-12738	08135				
FDD1-17238	08125		09651-G		
FDD1-17251	08125		09651-G		
FDD1-17251 IP56M	08125		09651-G		