

POP® Point Of Purchase Displays

POP point-of-purchase displays offer a complete and effective way to organize and simplify your sheet material fastener inventory. They contain only the most popular and fastest moving items so you get faster turns. With five different displays and four product lines to choose from, you can tailor your inventory to your customer's requirements.

All packaging contains application information so the customer can select the right fastener.



POP® Thrift Pack Display P/N 5835

Part No.	Code No.	Grip Ranges	Rivet Dia.	Qty./ Display	Qty./ Pkg.
Steel Rivet/Steel Mandrel					
57438	SD42	1/16-1/8	1/8	5	25
57442	SD44	3/16-1/4	1/8	5	20
57446	SD46	5/16-3/8	1/8	5	15
Aluminum Rivet/Aluminum Mandrel					
57473	AD42-A	1/16-1/8	1/8	5	25
57477	AD44-A	3/16-1/4	1/8	5	20
57480	AD46-A	5/16-3/8	1/8	5	15
57487	AD62-A	Up to 1/8	3/16	5	15
57488	AD64-A	1/8-1/4	3/16	5	15
57490	AD66-A	1/4-3/8	3/16	5	15
Back-Up Plates					
57660	SBUP-4	1/8 Hole	Steel	3	40
57661	ABUP-4	1/8 Hole	Alum	3	30
57662	ABUP-6	3/16 Hole	Alum	3	30
Tools					
PS15-CS				4	



POP® Plastic Rivet Display P/N 5870

Part No.	Grip Ranges	Rivet Dia.	Qty./ Display	Qty./ Pkg.
57712	.059-.177	5.0mm	2	25
57714	.118-.177	5.0mm	2	25
57715	.118-.236	5.0mm	2	25
57720	.236-.394	5.0mm	2	25
57721	.157-.335	6.0mm	2	25
57732	.157-.236	6.3mm	2	25
57735	.157-.236	6.3mm	2	25
57736	.157-.394	6.3mm	2	25
57737	.157-.394	6.3mm	2	25
57741	.315-.472	6.3mm	2	25
57747	.098-.197	6.6mm	2	25
57748	.098-.197	6.6mm	2	25
57752	.098-.236	7.0mm	2	25
Tools				
60930	Pouched Rivet tool		4	



POP® SHOP RACK DISPLAY P/N 5856

Part No.	Code No.	Grip Ranges	Rivet Dia.	Qty./ Display
Steel Rivet/Steel Mandrel				
59438	SD42	1/16-1/8	1/8	3
59439	SK42	1/16-1/8	1/8	2
59442	SD44	3/16-1/4	1/8	6
59443	SK44	3/16-1/4	1/8	3
59446	SD46	5/16-3/8	1/8	4
59447	SD48	3/8-1/2	1/8	3
Aluminum Rivet/Aluminum Mandrel				
59473	AD42-A	1/16-1/8	1/8	2
59477	AD44-A	3/16-1/4	1/8	4
59480	AD46-A	5/16-3/8	1/8	2
59488	AD64-A	1/8-1/4	3/16	3
59490	AD66-A	1/4-3/8	3/16	2
Tools				
PS15-CS				2

Note: Shop pack boxes contain 100 rivets

60930-KIT

POPSet[®] Plastic Rivet Tool

- One stroke setting tool (60930)
- Designed to set POP plastic rivets up to 5/16"
- Never need to change nosepiece
- Supplied as a kit with 100 of the most popular plastic rivets



PS15-KIT

POPSet[®] Rivet Tool Kit

- Professional plier style hand tool (PS15-CS)
- Designed to set Aluminum rivets up to 3/16" and Steel up to 5/32"
- Supplied with nosepieces and nosepiece wrench
- Supplied as a 265 piece kit with wide assortment of 8 rivet types



PS10-BL

POPSet[®] DIY Hand Plier Rivet Tool


- Sets Aluminum rivets up to 3/16" (4.8mm)
- Contoured handle grips
- Robust construction
- Supplied with 4 nosepieces and wrench



PS15-CS

POPSet[®] Professional Hand Plier

- Sets Aluminum rivets up to 3/16" (4.8mm)
- Professional grade
- Contoured handle grips
- Rivet retaining handle
- Robust construction
- Supplied with 4 nosepieces and wrench

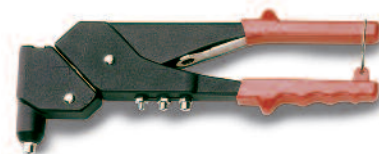

61946

Swivelhead Rivet Tool

- Rotates full 360° for easy access to any application
- Includes 3/32, 1/8, 5/32 and 3/16 nosepieces and wrench
- All steel construction for durability



PS25

POPSet[®] Heavy Duty Lazy Tong Rivet Tool

- Heavy duty grade
- Sets all rivets up to 1/4" (6.4mm) including high strength
- Supplied with 5 nosepieces and wrench
- Linkage system for improved mechanical advantage

PS45

POPSet[®] Heavy Duty Lever Rivet Tool

- Telescopic levered high capacity tool
- Compact non-extended position
- Heavy duty grade
- Sets all rivets up to 1/4" (6.4mm) including high strength
- Integral removable mandrel collector
- Supplied with 5 nosepieces and wrench



MANUAL TOOL & RIVET GUIDE

TOOL	RIVET MATERIAL		RIVET DIAMETER				TOOL	RIVET MATERIAL		RIVET DIAMETER			
	Rivet	Mandrel	3/32	1/8	5/32	3/16		Rivet	Mandrel	1/8	5/32	3/16	1/4
PS10-BL & PS15-CS	Alum.	Alum.	●	● ●	● ●	● ●	PS25 & PS45	Alum.	Alum.	● ●	● ●	● ●	● ●
	Alum.	Steel	●	● ●	● ●	●		Alum.	Steel	● ●	● ●	● ●	● ●
	Steel	Steel	●	● ●	● ●			Steel	Steel	● ●	● ●	● ●	● ●
	St'less	St'less		● ●	● ●			St'less	St'less	● ●	● ●	● ●	● ●
	St'less	Steel		●				St'less	Steel	●	●	●	
	T-Rivets							T-Rivets				●	●

POP RIVET TOOL INTERCHANGEABLE NOSEPIECES

POP Rivet Tools are furnished with nosepieces to set the most frequently used range of rivet sizes (see tool descriptions on page 22). To order additional nosepieces for other requirements — rivet sizes and types — use the chart below.



Nosepieces

TOOL	RIVET DIAMETER					
	3/32	1/8	5/32	3/16	1/4	1/4 T-Rivet
PS15-CS	DPM400-A08	DPM400-B08	DPM400-C08	DPM400-D08	—	—
PS25 & PS45	—	DPM400-B10	DPM400-C10	DPM400-D10	DPM400-F10	DPM400-FT0

REPLACEMENT JAWS

REPLACEMENT JAWS PART NO.	FOR USE WITH TOOL MODEL NO.	RIVET DIAMETER
DPM400-084	PS15-CS	Up to 3/16"
FAN400-020	PS25 & PS45	All



Countersunk Drill
(P/N 60928)

Jaws