


For installation information please refer to the tooling overview and manuals on our website www.avdel-global.com.
 Pour les conditions de pose, merci de vous référer à la description de l'outil et aux manuels disponibles sur notre site Web.
 Angaben zur Verarbeitung entnehmen Sie bitte der Geräteübersicht und den Betriebsanleitungen auf unserer Website.
 Per informazioni sull'installazione preghiamo consultare i manuali e la panoramica degli attrezzi sul nostro sito web.
 Para ver información sobre máquinas de colocación, consulte nuestra página web, apartados visión general de máquinas y manuales.



English	Français	Deutsch	Italiano	Español
Protruding head	Tête bombée	Flachrundkopf	Testa tonda	Cabeza alomada
Body: Steel* Zinc plated	Corps: Acier* Revêtement zingué	Hülse: Stahl* verzinkt	Corpo: Acciaio* Zincati	Cuerpo: Acero* Zincado
Stem: Steel* Zinc plated Clear trivalent chromated	Tige: Acier* Revêtement zingué Passivation claire trivalente	Dorn: Stahl* verzinkt Klar chromatiert, Cr6-frei	Gambo: Acciaio* Zincati Passivazione chiara trivalente	Vástago: Acero* Zincado Passivado claro trivalente

*: BS 3111 Type 1 SAE 1038

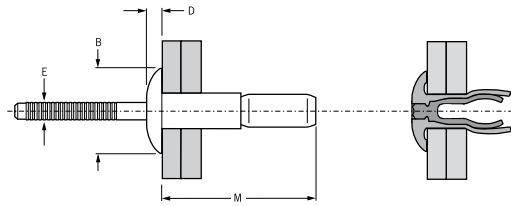

Ø					M	B	D	E			Part No/ref
nom.	min.	max.	min.	max.	max.	max.	max.	max.	lbf min. ¹⁾	lbf min. ¹⁾	
3/16" (4.8 mm)	.062	.250	.194	.204	.716	.400	.090	.122	1300	1000	SSPI-06-04
	.214	.437			1.003						SSPI-06-07
	.375	.625			1.090						SSPI-06-10
	.062	.437			1.003						SSPI-E06-07
1/4" (6.4 mm)	.080	.375	.261	.276	1.181	.530	.117	.162	2400	1850	SSPI-08-06 ²⁾
	.350	.625			1.431						SSPI-08-10
	.080	.625			1.431						SSPI-E08-10

all dimensions in inches / en pouces / alle Maße in Zoll / in pollici / en pulgadas

1) typical values / valeurs moyennes / typische Werte / Valori tipici / resistencias máximas recomendadas

2) Deutsches Institut für Bautechnik (DIBt) Zulassung Nr. Z-14.1-4 Anlage 2-23