


Monobolt® 2771 (SSPV)

For installation information please refer to the tooling overview and manuals on our website www.avdel-global.com.
 Pour les conditions de pose, merci de vous référer à la description de l'outil et aux manuels disponibles sur notre site Web.
 Angaben zur Verarbeitung entnehmen Sie bitte der Geräteübersicht und den Betriebsanleitungen auf unserer Website.
 Per informazioni sull'installazione preghiamo consultare i manuali e la panoramica degli attrezzi sul nostro sito web.
 Para ver información sobre máquinas de colocación, consulte nuestra página web, apartados visión general de máquinas y manuales.



English	Français	Deutsch	Italiano	Español
Protruding head	Tête bombée	Flachrundkopf	Testa tonda	Cabeza alomada
Body: carbon steel* Zinc plated Clear trivalent passivated with top seal	Corps: Acier au carbone* Revêtement zingué Passivation claire trivalente avec top seal	Hülse: Stahl* Verzinkt Klar passiviert, Cr6-frei mit Versiegelung	Corpo: Acciaio carbonio* Zincato Passivazione chiara triva- lente con sigillante	Cuerpo: Acero carbono* Zincado Pasivado claro trivalente con sellante
Stem: medium carbon steel** Zinc plated Clear trivalent passivated with top seal	Tige: Acier au carbone** Revêtement zingué Passivation claire trivalente avec top seal	Dorn: Stahl** Verzinkt Klar chromatiert, Cr6-frei mit Versiegelung	Gambo: Acciaio carbonio** Zincato Passivazione chiara triva- lente con sigillante	Vástago: Acero medio en carbono** Zincado Pasivado claro trivalente con sellante
*: BS 3111 Type 9 SAE 10B21 DIN 1654 22B2				
**: BS 3111 Type 10 SAE 10B35 DIN 1654 35B2				

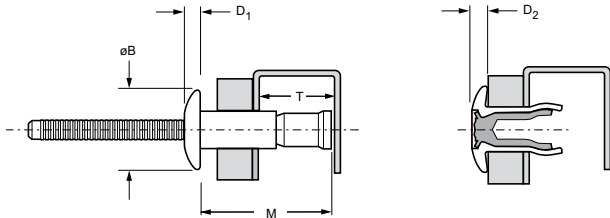

Ø					M	Ø B	D ₁	T	D ₂			Part No/ref
nom.	min.	max.	min.	max.	max.	max.	max.	min.	max.	lb ^{f1}	lb ^{f1}	
3/16" (4.8 mm)	.064	.270	.193	.201	.716	.395	.083	.410	.073	1450	1150	02771-00613 (SSPV-06-04)
	.064	.437			.962			.530				02771-00617 (SSPV-E06-07)
1/4" (6.4 mm)	.080	.375	.260	.275	.933	.525	.114	.480	.104	2650	2350	02771-00817 (SSPV-08-06)
	.080	.625			1.296			.645				02771-00824 (SSPV-E08-10)
3/8" (10 mm)	.120	.625	.392	.409	1.425	.798	.160	.875	.156	5940	3953	02771-01228

all dimensions in inches / en pouces / alle Maße in Zoll / in pollici / en pulgadas

1) typical values / valeurs moyennes / typische Werte / Valori tipici / resistencias máximas recomendadas



An Acument™ Global Technologies Company

www.avdel-global.com

© 2008 Acument Intellectual Properties, LLC

Monobolt® is a trademark of Avdel UK Limited

10.2009

Data shown is subject to change without prior notice as a result of continuous product development and improvement policy.
 Your local Avdel representative is at your disposal should you need to confirm latest information.