

Stavex® BS01


For installation information please refer to the tooling overview and manuals on our website www.avdel-global.com.
 Pour les conditions de pose, merci de vous référer à la description de l'outil et aux manuels disponibles sur notre site Web.
 Angaben zur Verarbeitung entnehmen Sie bitte der Geräteübersicht und den Betriebsanleitungen auf unserer Website.
 Per informazioni sull'installazione preghiamo consultare i manuali e la panoramica degli attrezzi sul nostro sito web.
 Para ver información sobre máquinas de colocación, consulte nuestra página web, apartados visión general de máquinas y manuales.



English	Français	Deutsch	Italiano	Español
Dome head	Tête plate	Flachrundkopf	Testa tonda	Cabeza alomada
Body: Low carbon steel*	Corps: Acier bas carbone*	Hülse: Stahl*	Corpo: Acciaio a basso tenore di carbonio*	Cuerpo: Acero bajo en carbono*
Zinc plated	Revêtement zingué	Verzinkt	Zincato	Zincado
Stem: Low carbon steel**	Tige: Acier bas carbone**	Dorn: Stahl**	Gambo: Acciaio a basso tenore di carbonio**	Vástago: Acero bajo en carbono**
Zinc plated	Revêtement zingué	Verzinkt	Zincato	Zincado

*: BS3111 Type 0, SAE 1008, DIN 1654, QSt 34-3

** : BS3111 Type 0, SAE 1010/1015/1018/1022, DIN 17210, Cq10 / DIN 1654 Cq10/Cq15/Cq22

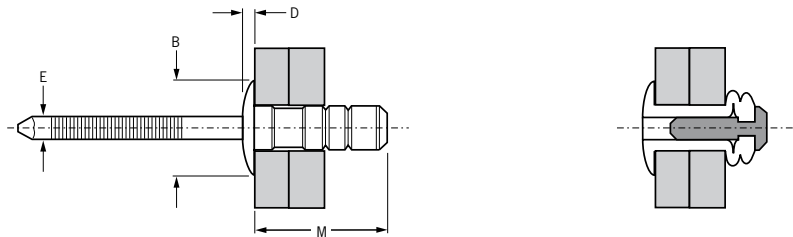

Ø					M	B	D	E			Part No/ref
nom.	min.	max.	min.	max.	max.	max.	max.	max.	lbf min.	lbf min.	
1/8" (3.2 mm)	.039	.236	.129	.134	.57	.287	.037	.087	202	263	OBS01-00414
5/32" (4.0 mm)	.079	.315	.161	.166	.63	.322	.052	.112	344	405	OBS01-00516
3/16" (4.8 mm)	.060	.200	.192	.196	.48	.397	.061	.120	585	647	OBS01-00612
	.060	.250			.54						OBS01-00614
	.059	.354			.67						OBS01-00618
	.250	.500			.79						OBS01-00622
1/4" (6.4 mm)	.060	.300	.261	.275	.66	.530	.105	.158	700	800	01610-04844 ¹⁾

all dimensions in inches / en pouces / alle Maße in Zoll / in pollici / en pulgadas

1) zinc plated, clear trivalent passivated / revêtement zingué, passivation claire trivalente / verzinkt, klar chromatiert Cr6-frei/
 zincato, passivazione chiara trivalente / zincado, pasivado claro trivalente