


Hemlok® 2221

For installation information please refer to the tooling overview and manuals on our website www.avdel-global.com.
 Pour les conditions de pose, merci de vous référer à la description de l'outil et aux manuels disponibles sur notre site Web.
 Angaben zur Verarbeitung entnehmen Sie bitte der Geräteübersicht und den Betriebsanleitungen auf unserer Website.
 Per informazioni sull'installazione preghiamo consultare i manuali e la panoramica degli attrezzi sul nostro sito web.
 Para ver información sobre máquinas de colocación, consulte nuestra página web, apartados visión general de máquinas y manuales.



| English | Français | Deutsch | Italiano | Español |
|--|--|---|--|---|
| Protruding head | Tête bombée | Flachrundkopf | Testa tonda | Cabeza alomada |
| Body: medium carbon steel Zinc plated Clear trivalent passivated | Corps: Acier moyen carbone Revêtement zingué Passivation claire trivalente | Hülse: Stahl Verzinkt Klar passiviert, Cr6-frei | Corpo: Acciaio a medio tenore di carbonio Zincato Passivazione chiara trivalente | Cuerpo: Acero medio en carbono Zincado Pasivado claro trivalente |
| Stem: medium carbon steel Zinc plated Clear trivalent passivated | Tige: Acier moyen carbone Revêtement zingué Passivation claire trivalente | Dorn: Stahl Verzinkt Klar chromatiert, Cr6-frei | Gambo: Acciaio a medio tenore di carbonio Zincato Passivazione chiara trivalente | Vástago: Acero medio en carbono Zincado Pasivado claro trivalente |

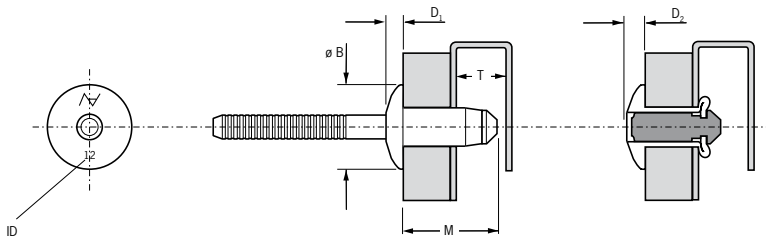

| Ø | | | | | ID | M | Ø B | D ₁ | T | D ₂ | | | Part No/ref |
|------------------|------|------|------|------|----|------|------|----------------|------|----------------|----------|----------|-------------|
| nom. | min. | max. | min. | max. | | max. | max. | max. | min. | max. | lbf min. | lbf min. | |
| 1/4" (6.4 mm) | .060 | .138 | .264 | .272 | 12 | .539 | .525 | .105 | .480 | .134 | 2360 | 1978 | 02221-00812 |
| | .110 | .189 | | | 13 | .590 | | | | | 2698 | | 02221-00813 |
| | .132 | .211 | | | 14 | .612 | | | | | 2810 | | 02221-00814 |
| | .189 | .268 | | | 15 | .669 | | | | | 2810 | | 02221-00815 |
| | .268 | .346 | | | 17 | .747 | | | | | 3147 | | 02221-00817 |
| | .295 | .374 | | | 18 | .775 | | | | | 3372 | | 02221-00818 |
| | .346 | .425 | | | 19 | .826 | | | | | 3597 | | 02221-00819 |
| | .425 | .504 | | | 21 | .905 | | | | | 3597 | | 02221-00821 |

all dimensions in inches / en pouces / alle Maße in Zoll / in pollici / en pulgadas



An Acument™ Global Technologies Company

www.avdel-global.com

© 2007 Acument Intellectual Properties, LLC

Hemlok® is a trademark of Avdel UK Limited

03.2010

Data shown is subject to change without prior notice as a result of continuous product development and improvement policy.
 Your local Avdel representative is at your disposal should you need to confirm latest information.