

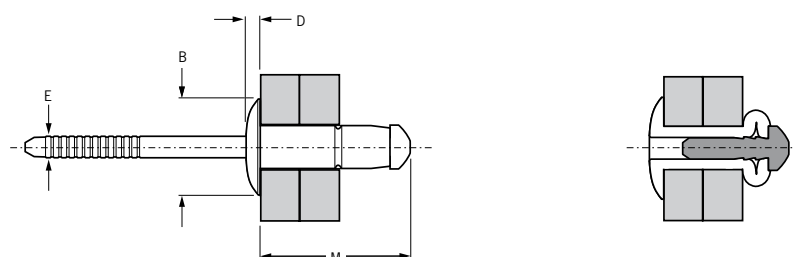
Avinox® BE61



 

For installation information please refer to the tooling overview and manuals on our website www.avdel-global.com.
 Pour les conditions de pose, merci de vous référer à la description de l'outil et aux manuels disponibles sur notre site Web.
 Angaben zur Verarbeitung entnehmen Sie bitte der Geräteübersicht und den Betriebsanleitungen auf unserer Website.
 Per informazioni sull'installazione preghiamo consultare i manuali e la panoramica degli attrezzi sul nostro sito web.
 Para ver información sobre máquinas de colocación, consulte nuestra página web, apartados visión general de máquinas y manuales.



| English | Français | Deutsch | Italiano | Español |
|------------------------------------|----------------------|----------------------------------|---|--|
| Dome head | Tête plate | Flachrundkopf | Testa tonda | Cabeza alomada |
| Body: Stainless steel* Polished | Corps: Inox* Poli | Hülse: Edelstahl* Blank | Corpo: Acciaio inox* Lucido | Cuerpo: Acero inoxidable* Pulido |
| Stem: Stainless steel** Natural | Tige: Inox** Brut | Dorn: Edelstahl** Unbehandelt | Gambo: Acciaio inox** Nessuna finitura | Vástago: Acero inoxidable** Natural |

*: BS 3111 394S17, Werkstoff 1.4567
 **: BS 3111 321S31, AISI 321, Werkstoff 1.4541 / AISI 304, Werkstoff 1.4301



| ø |  | |  | | M | B | D | E |  |  | Part No/ref |
|-------------------|---|------|---|------|------|------|------|------|---|---|-------------|
| nom. | min. | max. | min. | max. | max. | max. | max. | max. | lb ^{f1) 2)} | lb ^{f1)} | |
| 1/8" (3.2 mm) | .039 | .118 | .130 | .134 | .360 | .260 | .043 | .083 | 360 | 450 | OBE61-00408 |
| | .118 | .197 | | | .460 | | | | 382 | | OBE61-00411 |
| | .197 | .276 | | | .560 | | | | 719 | | OBE61-00414 |
| 5/32" (4.0 mm) | .039 | .118 | .161 | .169 | .410 | .315 | .059 | .102 | 629 | 899 | OBE61-00509 |
| | .118 | .197 | | | .510 | | | | 1169 | | OBE61-00512 |
| | .197 | .276 | | | .620 | | | | 1169 | | OBE61-00516 |
| 3/16" (4.8 mm) | .059 | .138 | .193 | .201 | .510 | .378 | .059 | .126 | 1236 | 1124 | OBE61-00611 |
| | .138 | .236 | | | .610 | | | | | | OBE61-00614 |
| | .236 | .335 | | | .730 | | | | | | OBE61-00618 |

all dimensions in inches / en pouces / alle Maße in Zoll / in pollici / en pulgadas

1) typical values / valeurs moyennes / typische Werte / Valori tipici / resistencias máximas recomendadas

2) includes stem in shear plane, where applicable / Avec présence de la tige dans le plan de cisaillement / mit Restdorn in Scherebene, wo zutreffend / Include il gambo nel taglio piano, dove applicabile / Cuando esté incluido el vástago en la zona de cortadura



An Acument™ Global Technologies Company

www.avdel-global.com

© 2007 Acument Intellectual Properties, LLC

Avinox® is a trademark of Avdel UK Limited

03.2010

Data shown is subject to change without prior notice as a result of continuous product development and improvement policy.
 Your local Avdel representative is at your disposal should you need to confirm latest information.