


# Stavex® BS11



English	Français	Deutsch	Italiano	Español
Dome head	Tête plate	Flachrundkopf	Testa tonda	Cabeza alomada
Body: Stainless steel* Polished	Corps: Inox* Poli	Hülse: Edelstahl* Blank	Corpo: Acciaio inox* Lucido	Cuerpo: Acero inoxidable* Pulido
Stem: Stainless steel** Natural	Tige: Inox** Brut	Dorn: Edelstahl** Unbehandelt	Gambo: Acciaio inox** Nessuna finitura	Vástago: Acero inoxidable** Natural

\*: BS3111 394S17, Werkstoff 1.4567

\*\* : BS3111 304S17, AISI 304, Werkstoff 1.4301 / BS3111 321S31, AISI 321, Werkstoff 1.4541

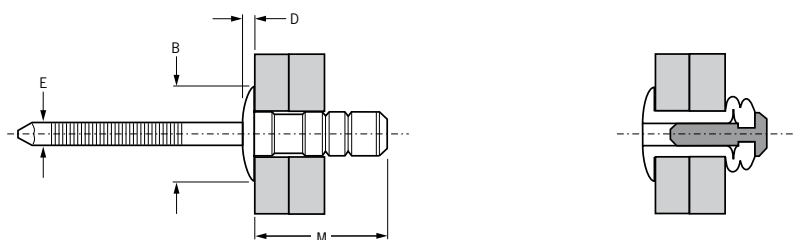

Ø					M	B	D	E			Part No/ref
nom.	min.	max.	min.	max.	max.	max.	max.	max.	lbf min. <sup>1)</sup>	lbf min. <sup>1)</sup>	
1/8" (3.2 mm)	.039	.236	.129	.134	.570	.287	.037	.087	364	445	OBS11-00414
5/32" (4.0 mm)	.079	.315	.161	.166	.630	.322	.052	.112	546	728	OBS11-00516
3/16" (4.8 mm)	.059	.354	.192	.196	.670	.397	.061	.120	931	1012	OBS11-00618

all dimensions in inches / en pouces / alle Maße in Zoll / in pollici / en pulgadas

1) typical values / valeurs moyennes / typische Werte / Valori tipici / resistencias máximas recomendadas



An Acument™ Global Technologies Company

[www.avdel-global.com](http://www.avdel-global.com)

© 2007 Acument Intellectual Properties, LLC

Stavex® is a trademark of Avdel UK Limited

05.2007

Data shown is subject to change without prior notice as a result of continuous product development and improvement policy.  
Your local Avdel representative is at your disposal should you need to confirm latest information.