

Genesis® nG2 Hydro Pneumatic Tool

71213 series with quick release stem collector bottle

71214 series with fixed stem collector bottle

Features

- Lightweight tool
- Toughened plastic body and heavy duty rubber base
- Quick release nose assembly
- Quick release stem collector bottle (71213 series)
- Fixed stem collector bottle (71214 series)
- Adjustable vacuum air flow
- Enhanced tool life
- Soft touch rubber grip on handle
- Integral cycle counter

Benefits

- Reduced operator fatigue
- High placement speed
- Robust tool
- Minimized air consumption
- Reduced setting times and change of equipment
- Reduced time to empty stem collector
- Places a wide range of fasteners
- Ergonomic

Specifications

| | |
|---------------------------|----------------------|
| Weight (min. with equip) | 2.1 kg (4.5 lbs) |
| Pull force @ 5.5 bar | 9.34 kN (2100 lbf) |
| Stroke (min.) | 17 mm (0.67 in) |
| Cycle time (approx.) | 0.8 sec |
| Air supply pressure | 5-7 bar (80-100 psi) |
| Free air volume @ 5.5 bar | 2.1 litres |
| Noise level | <75 dB(A) |
| Vibration | <2.5m/s ² |


Placing capability

Up to 4.8mm (3/16") breakstem rivets produced by Avdel. Can also place Avseal® II sealing plug up to 7 mm.

For detailed information on placing capability and nose equipment please refer to the tool manual on our website www.avdel-global.com or contact your local Avdel representative.



Dimensions (mm)

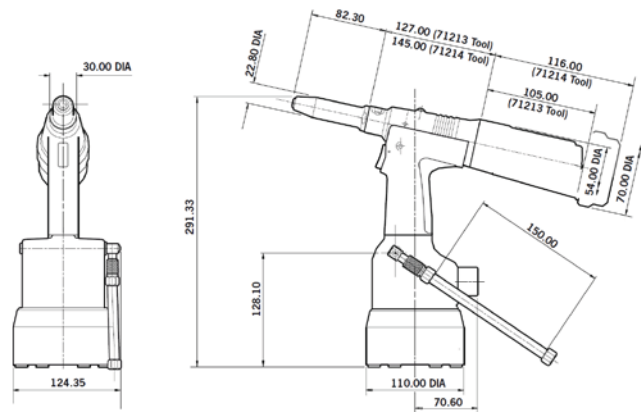

Avdel USA LLC
614 NC Highway 200 South
Stanfield, North Carolina 28163
Tel. +1 704 888-7100 · Fax -0258
infoAvdel-USA@infastech.com

www.avdel-global.com

Avdel Canada Limited
1030 Lorimar Drive
Mississauga, Ontario L5S 1R8
Tel. +1 905 364-0664 · Fax -0678
infoAvdel-Canada@infastech.com

© 2010 Infastech

Avdel Patent Protected. Avseal® and Genesis® are trademarks of Avdel UK Limited.

09.2011

Data shown is subject to change without prior notice as a result of continuous product development and improvement policy.
Your local Avdel representative is at your disposal should you need to confirm latest information.