



1-Conductor Female Connectors with Push-Buttons

Pin Spacing: 7.5 mm

MCS MIDI

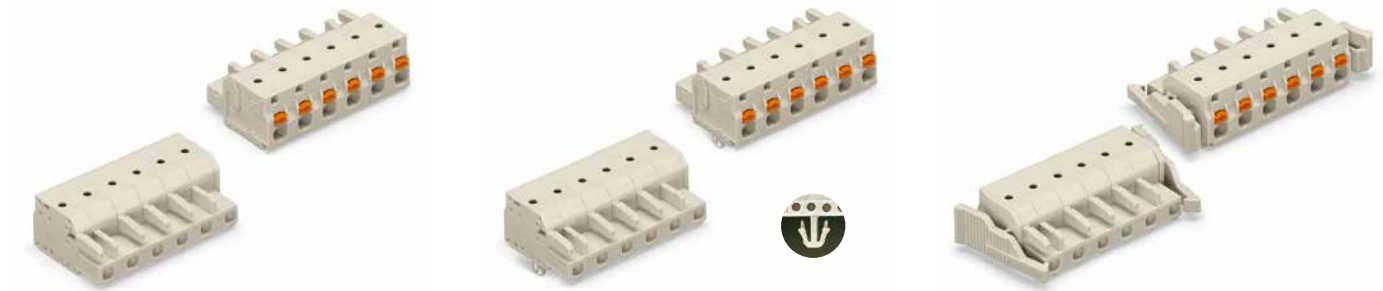


Dimensions (in mm):

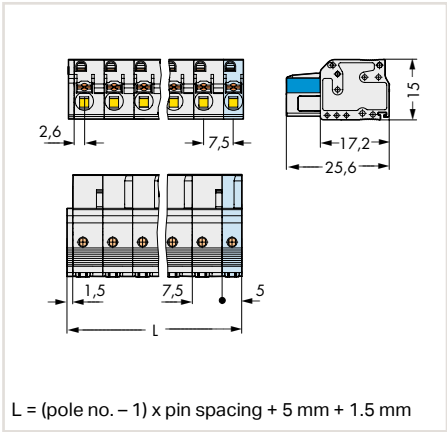

1-conductor female connector, with push-buttons, light gray, 7.5 mm (0.295 inch) pin spacing

Pole No.	Item No.	Pack. Unit
2	2721-202/026-000	100
3	2721-203/026-000	100
4	2721-204/026-000	50
5	2721-205/026-000	50
6	2721-206/026-000	50
7	2721-207/026-000	50
8	2721-208/026-000	25
9	2721-209/026-000	25
10	2721-210/026-000	25
11	2721-211/026-000	25
12	2721-212/026-000	25


Dimensions (in mm):

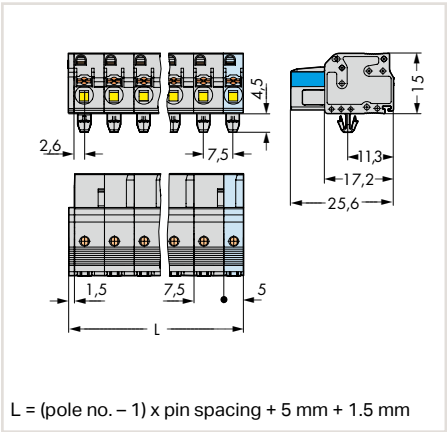

1-conductor female connector, with push-buttons and snap-in mounting feet, for 0.6 ... 1.2 mm plate thickness, 3.5 mm Ø mounting holes, light gray, 7.5 mm (0.295 inch) pin spacing

Pole No.	Item No.	Pack. Unit
2	2721-202/008-000	100
3	2721-203/008-000	100
4	2721-204/008-000	50
5	2721-205/008-000	50
6	2721-206/008-000	50
7	2721-207/008-000	50
8	2721-208/008-000	25
9	2721-209/008-000	25
10	2721-210/008-000	25
11	2721-211/008-000	25
12	2721-212/008-000	25

Dimensions (in mm):

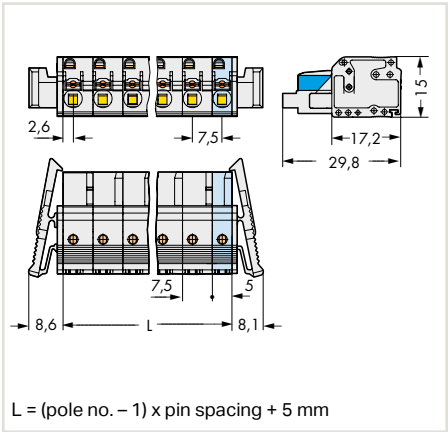

1-conductor female connector, with push-buttons and locking levers, light gray, 7.5 mm (0.295 inch) pin spacing

Pole No.	Item No.	Pack. Unit
2	2721-202/037-000	50
3	2721-203/037-000	50
4	2721-204/037-000	50
5	2721-205/037-000	50
6	2721-206/037-000	25
7	2721-207/037-000	25
8	2721-208/037-000	25
9	2721-209/037-000	25
10	2721-210/037-000	25
11	2721-211/037-000	10
12	2721-212/037-000	10

2-pole female connectors – one latch only

Available upon request (depending on quantity required):

- Other pole numbers
- Gold-plated or partially gold-plated contact surfaces

Depending on the version requested, "item no. suffix ... /010-000" is added to the "basic item no."