




Empty component plug housing			
	Description	Item No.	Pack. Unit
Type 4	2-pole, 10 mm/0.394 inch wide; Plug inside dimensions (W/H/D): 8.2/15/15 mm	280-803	50

Technical Data


Rated voltage	250 V
Rated impulse voltage	4 kV
Pollution degree	3
per contact	6 A (max.)

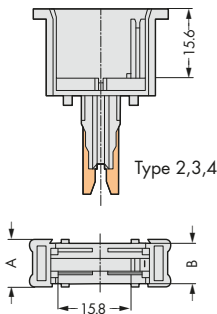

Type	1	2	3	4
A	5	10	10	10
B	3.2	8.2	8.2	8.2



2-conductor through terminal block

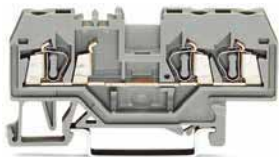

3-conductor through terminal block



4-conductor through terminal block



2-conductor through terminal block

Through terminal block			
	Description	Item No.	Pack. Unit
2-conductor, front-entry wiring	gray, terminal block width: 5 mm/0.197 inch, marking on both sides	280-601	100
2-conductor, front-entry wiring	gray, terminal block width: 5 mm/0.197 inch, marking in center position	280-901	100
3-conductor, front-entry wiring	gray, terminal block width: 5 mm/0.197 inch	280-681	100

Technical Data

Conductor range	0.08 ... 2.5 mm² / 28 ... 12 AWG (12 AWG: THHN, THWN)
Strip length	8 ... 9 mm / 0.31 ... 0.35 inch

Through terminal block			
	Description	Item No.	Pack. Unit
4-conductor, front-entry wiring	gray, terminal block width: 5 mm/0.197 inch, marking on both sides	280-621	100
4-conductor, front-entry wiring	gray, terminal block width: 5 mm/0.197 inch, marking in center position	280-833	100
2-conductor, front-entry wiring	gray, terminal block width: 5 mm/0.197 inch	280-101	100

Technical Data

Conductor range	0.08 ... 2.5 mm² / 28 ... 14 AWG
Strip length	8 ... 9 mm / 0.31 ... 0.35 inch