


TIMING BELTS

CIRCULAR PITCH	BELT WIDTH	MATERIALS	BERG'S® NAME	PULLEY
.200 (XL)	1/4"	Polyurethane (Red) 90A Duro 1/32" Stainless Steel Cable*	Flex-E-Grip®	Operates with 20TP Series

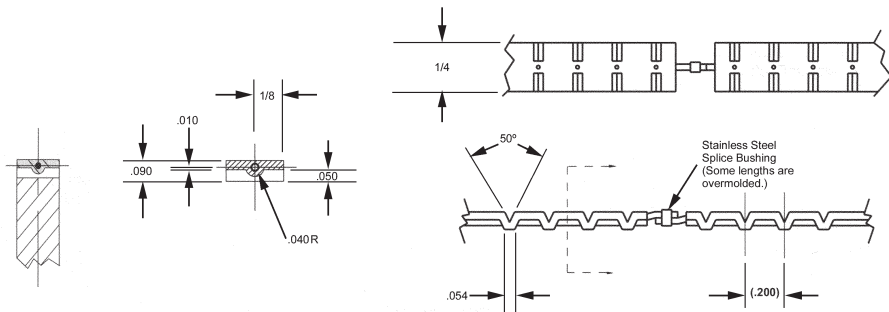

STOCK NO.	NO. OF PITCHES	LENGTH (Ref.)
20TB-10	10*	2.00
20TB-15	15*	3.00
20TB-20	20*	4.00
20TB-25	25	5.00
20TB-30	30	6.00
20TB-35	35	7.00
20TB-40	40	8.00
20TB-45	45	9.00
20TB-50	50	10.00
20TB-55	55	11.00
20TB-60	60	12.00
20TB-65	65	13.00
20TB-70	70	14.00
20TB-80	80	16.00
20TB-85	85	17.00
20TB-90	90	18.00
20TB-95	95	19.00
20TB-100	100	20.00
20TB-105	105	21.00
20TB-110	110	22.00
20TB-110	115	23.00
20TB-120	120	24.00
20TB-125	125	25.00
20TB-130	130	26.00
20TB-135	135	27.00
20TB-140	140	28.00
20TB-145	145	29.00
20TB-150	150	30.00
20TB-155	155	31.00
20TB-160	160	32.00
20TB-175	175	35.00
20TB-180	180	36.00
20TB-185	185	37.00
20TB-190	190	38.00
20TB-200	200	40.00
20TB-210	210	42.00

* Aramid Core. Alternate construction available.

- No Flanges Required
- Infinite Lengths
- Silent Drive
- No-Walk Feature
- No Lubrication
- Weight .10 oz./ft.
- Compact Design
- Positive Drive
- Light Weight
- Extra Strong
- Ultimate Tensile Strength 50 lbs.
- Temperature Range +180°F to -15°F
- Recommended Operating Load 10-12 lbs.
- Recommended Max. Operating Speed 376 ft./min.
- For Field Splice Kit Order 20TB-70

* Splices are factory overmolded

BULK FOOTAGE - NOT SPLICED	
STOCK NO.	LENGTH
20TB-5FT	5 FT
20TB-10FT	10 FT
20TB-25FT	25 FT
20TB-50FT	50 FT
20TB-100FT	100 FT

