


SPROCKET GEARS

| PITCH | CIRCULAR PITCH | BORE | STYLE | MATERIALS | BERG'S ® NAME | CHAIN |
|-------|----------------|-------|---------|---|-------------------------------------|-------------------------------|
| 32 | .0982 | 3/16" | PIN HUB | 303 Stainless Steel 2024-T4 Aluminum Anodized | Flex-E-Gear® Chain Drive | Operates with 32GCF Series |

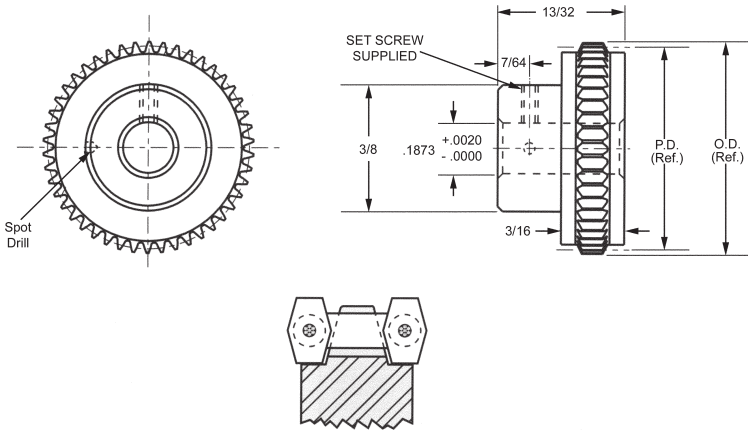

| 303 STAINLESS STEEL | 2024-T4 ALUMINUM ANODIZED | | | |
|---------------------------|---------------------------------|-----------------|------------|-----------------|
| STOCK NO. | STOCK NO. | NO. OF TEETH | PITCH DIA. | OUTSIDE DIA. |
| GG33S21-15 | GG33A21-15 | 15** | .4688 | .531 |
| GG33S21-16 | GG33A21-16 | 16** | .5000 | .563 |
| GG33S21-18 | GG33A21-18 | 18 | .5625 | .625 |
| GG33S21-20 | GG33A21-20 | 20 | .6250 | .688 |
| GG33S21-22 | GG33A21-22 | 22 | .6875 | .750 |
| GG33S21-24 | GG33A21-24 | 24 | .7500 | .813 |
| GG33S21-26 | GG33A21-26 | 26 | .8125 | .875 |
| GG33S21-28 | GG33A21-28 | 28 | .8750 | .938 |
| GG33S21-30 | GG33A21-30 | 30 | .9375 | 1.000 |
| GG33S21-32 | GG33A21-32 | 32 | 1.0000 | 1.063 |
| GG33S21-36 | GG33A21-36 | 36 | 1.1250 | 1.188 |
| GG33S21-40 | GG33A21-40 | 40 | 1.2500 | 1.313 |
| GG33S21-48 | GG33A21-48 | 48 | 1.5000 | 1.563 |
| GG33S21-56 | GG33A21-56 | 56 | 1.7500 | 1.813 |
| GG33S21-64 | GG33A21-64 | 64 | 2.0000 | 2.063 |
| GG33S21-72 | GG33A21-72 | 72 | 2.2500 | 2.313 |
| GG33S21-80 | GG33A21-80 | 80 | 2.5000 | 2.563 |
| GG33S21-88 | GG33A21-88 | 88 | 2.7500 | 2.813 |
| GG33S21-96 | GG33A21-96 | 96 | 3.0000 | 3.063 |
| GG33S21-112 | GG33A21-112 | 112 | 3.5000 | 3.563 |
| GG33S21-128 | GG33A21-128 | 128 | 4.0000 | 4.063 |



** Sprockets .500 P.D. and smaller for idler use only.
Other numbers of teeth available on request.
Teeth could be anodized.