


SPROCKET GEARS

PITCH	CIRCULAR PITCH	BORE	STYLE	MATERIALS	BERG'S ® NAME	CHAIN
32	.0982	1/4"	PIN HUB	303 Stainless Steel 2024-T4 Aluminum Anodized	Flex-E-Gear® Chain Drive	Operates with 32GCF Series

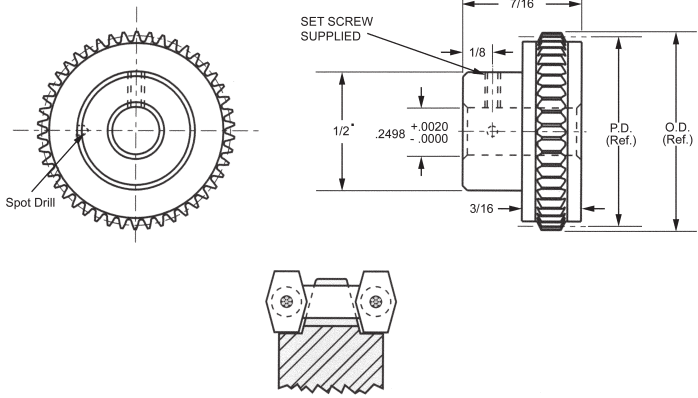

303 STAINLESS STEEL	2024-T4 ALUMINUM ANODIZED			
STOCK NO.	STOCK NO.	NO. OF TEETH	PITCH DIA.	OUTSIDE DIA.
GG33S28-18	GG33A28-18	18•	.5625	.625
GG33S28-20	GG33A28-20	20	.6250	.688
GG33S28-22	GG33A28-22	22	.6875	.750
GG33S28-24	GG33A28-24	24	.7500	.813
GG33S28-26	GG33A28-26	26	.8125	.875
GG33S28-28	GG33A28-28	28	.8750	.938
GG33S28-30	GG33A28-30	30	.9375	1.000
GG33S28-32	GG33A28-32	32	1.0000	1.063
GG33S28-36	GG33A28-36	36	1.1250	1.188
GG33S28-40	GG33A28-40	40	1.2500	1.313
GG33S28-48	GG33A28-48	48	1.5000	1.563
GG33S28-56	GG33A28-56	56	1.7500	1.813
GG33S28-64	GG33A28-64	64	2.0000	2.063
GG33S28-72	GG33A28-72	72	2.2500	2.313
GG33S28-80	GG33A28-80	80	2.5000	2.563
GG33S28-88	GG33A28-88	88	2.7500	2.813
GG33S28-96	GG33A28-96	96	3.0000	3.063
GG33S28-112	GG33A28-112	112	3.5000	3.563
GG33S28-128	GG33A28-128	128	4.0000	4.063



• For 18 teeth, hub diameter equals .47.
Other numbers of teeth available on request.
Teeth could be anodized.