


LINEAR BALL BEARINGS

SHAFT SIZE	MATERIAL
1/8" TO 1"	STAINLESS STEEL OUTER SLEEVE HARDENED & GROUND STEEL BALLS - HARDENED STEEL

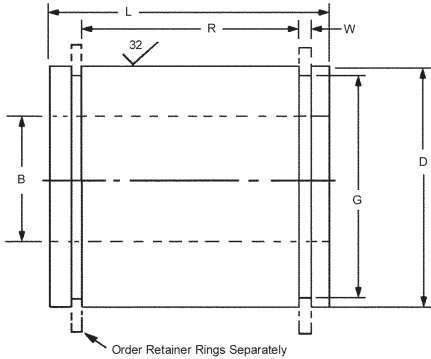

STOCK NO.	WORKING BORE B	OUTSIDE DIAMETER D	L	±.015 R	+.005 -.000 W	+.000 -.008 G	MAXIMUM SHAFT DIAMETER	USE SHAFT SERIES	REC. FITS		MAX ROLLING LOAD (lbs.)	RETAINER RING STOCK NO.
									NORM +.0005	PRESS +.0005		
LMB-125SS	.1250-.0003	.3125-.0004	1/2	.312	.029	.290	.1247	S1-8	.3125	.3115	7	Q2-31
LMB-187SS	.1875-.0003	.3750-.0004	9/16	.375	.029	.352	.1872	S1-11	.3750	.3740	9	Q2-37
LMB-1SS	.2500-.0005	.5000-.0004	3/4	.433	.039	.468	.2490	LMS-4-*	.5000	.4999	25	Q2-50
LMB-2SS	.3750-.0005	.6250-.0004	7/8	.558	.039	.588	.3740	LMS-6-*	.6250	.6240	51	Q2-62
LMB-3SS	.5000-.0005	.8750-.0004	1-1/4	.871	.046	.821	.4990	LMS-8-*	.8750	.8740	102	Q2-87
LMB-4SS	.7500-.0005	1.2500-.0004	1-5/8	1.054	.056	1.176	.7490	LMS-12-*	1.2500	1.2490	205	Q2-125
LMB-5SS	1.0000-.0005	1.5625-.0004	2-1/4	1.619	.068	1.468	.9990	LMS-16-*	1.5625	1.5615	385	Q2-156