


PINS


TYPE	MATERIALS
GROOVED HALF LENGTH TYPE B ANSI-B18.2-1978 (R1995)	303 STAINLESS STEEL

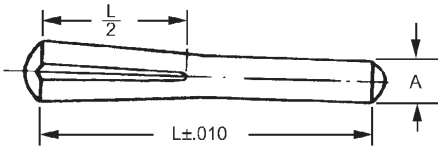

STOCK NO.	A	L	DRILL SIZE
CP4-1	.0469 +.0000 -.0010	3/8	3/64
CP4-2		1/2	
CP4-17		5/8	
CP4-3	.0625 +.0000 -.0010	3/8	1/16
CP4-4		1/2	
CP4-18		5/8	
CP4-5	.0781 +.0000 -.0010	3/8	5/64
CP4-6		1/2	
CP4-22		5/8	
CP4-7	.0938 +0.000 -.0010	3/8	3/32
CP4-8		1/2	
CP4-23	.0938 +0.000 -.0010	5/8	3/32
CP4-24		3/4	
CP4-25	.1250 +.0000 -.0020	1/2	1/8
CP4-9		5/8	
CP4-10		3/4	
CP4-26		1	
CP4-27	.1563 +.0000 -.0020	1/2	5/32
CP4-28		5/8	
CP4-11		3/4	
CP4-12		1	

Other sizes available on request.
Sold in packages of 10.

TYPE	MATERIALS
ROLL OR SPRING	420 STAINLESS STEEL

 

STOCK NO.	D	L (Inch)	DRILL SIZE	REF. SHAFT DIA.
CP5-2	.069	1/4	1/16	3/16
CP5-21		5/16		
CP5-3		3/8		
CP5-12		7/16		
CP5-10		1/2		
CP5-22		9/16		
CP5-23		5/8		
CP5-4	.086	9/16	5/64	1/4
CP5-24	.103	3/8	3/32	1/4
CP5-25		7/16		
CP5-26	.103	1/2	3/32	1/4
CP5-5		5/8		
CP5-13	.135	3/8	1/8	3/8
CP5-14		7/16		
CP5-15		1/2		
CP5-16		9/16		
CP5-17		5/8		
CP5-18		11/16		
CP5-6	.167	3/4	5/32	1/2
CP5-7		1		

Sold in packages of 10.