


RETAINER RINGS


TYPE	HOUSING BORE SIZE	MATERIALS
BEARING INTERNAL PUSH IN DESIGN	3/8 TO 3	CARBON SPRING STEEL PLATED

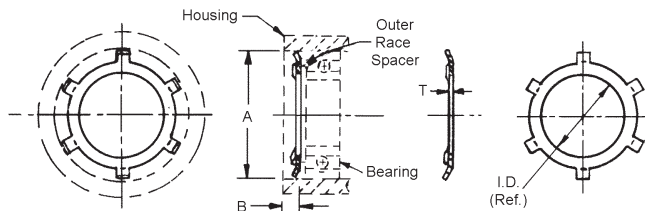

STOCK NO.	A HOUSING	B MIN. END SPACE	T±.002	I.D. (REF. ONLY)
Q6-37-CP	3/8	.040	.010	3/16
Q6-50-CP	1/2	.060	.010	1/4
Q6-61-CP	5/8	.060	.010	3/8
Q6-82-CP	7/8	.080	.015	5/8
Q6-125-CP	1-1/4	.080	.015	15/16
Q6-156-CP	1-9/16	.080	.015	1-1/8
Q6-200-CP	2	.080	.015	1-9/16
Q6-237-CP	2-3/8	.100	.015	1-7/8
Q6-300-CP	3	.100	.015	2-1/4

Sold in packages of 10.

TYPE	HOUSING BORE SIZE	MATERIALS
INTERNAL LUG DESIGN	1/4 TO 1	PH15-7 STAINLESS STEEL

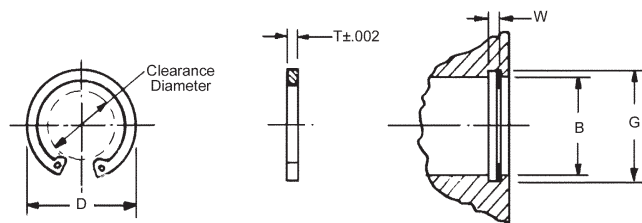

STOCK NO.	HOUSING BORE B	GROOVE DIA. G	GROOVE WIDTH W		RING THICKNESS T	FREE DIA. D	MAX. CLEAR. DIA.	PLIERS
Q4-25	1/4	.268	.020	±.002	.015	.280	.133	S13-25P
Q4-31	5/16	.330	.020		.015	.346	.191	S13-25P
Q4-37	3/8	.397	.029	±.003	.025	.415	.226	S13-37P
Q4-50	1/2	.530	.039		.035	.548	.290	S13-37P
Q4-62	5/8	.665	.039		.035	.694	.380	S13-37P
Q4-75	3/4	.796	.039		.035	.831	.490	S13-37P
Q4-87	7/8	.931	.046	±.004	.042	.971	.600	S13-37P
Q4-100	1	1.066	.046		.042	1.111	.730	S13-37P
Q4-112	1-1/8	1.197	.056		.050	1.249	.815	S13-37P