
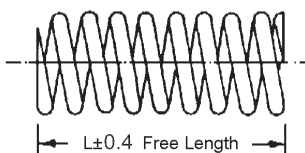


SPRINGS

TYPE	STYLE	MATERIALS
COMPRESSION	RIGHT HAND - OPEN WOUND ENDS SQUARED	302 STAINLESS STEEL SPRING TEMPERED

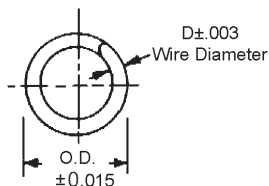

STOCK NO.	OUTSIDE DIA.	D	L	COILS	K ±10%
SPR1-1	.057	.007	3/8	18	1.58
SPR9-1		.008	1/4	13	4.41
SPR9-2		.008	1/2	24	2.08
SPR9-3	.088	.010	1/4	9	4.16
SPR1-2		.010	1/2	17	1.91
SPR9-5		.012	3/8	14	5.41
SPR9-6		.012	3/4	24	2.66
SPR9-7	.120	.016	1/4	7	14.57
SPR9-8		.016	1/2	13	6.91
SPR9-9		.018	3/8	10	14.91
SPR1-3		.018	5/8	16	8.82
SPR9-10		.018	3/4	19	7.08
SPR9-11		.020	3/8	11	23.07
SPR9-12		.020	3/4	20	10.99
SPR9-13		.022	1/2	14	25.90
SPR9-14		.022	1	27	12.24
SPR9-15	.180	.018	1/2	8	5.58
SPR9-16		.018	1	14	2.66
SPR9-17		.020	1/2	8	8.08
SPR9-18		.020	1	15	3.83
SPR1-4		.022	1/2	8	11.82
SPR9-20		.022	1	16	5.41
SPR9-21	.180	.024	1/2	9	15.74
SPR9-22		.024	1	17	7.49
SPR9-23		.026	1/2	9	22.32
SPR9-24		.026	1	17	10.16
SPR9-25		.029	3/4	14	21.49
SPR9-26		.029	1-1/2	26	10.32
SPR9-27		.032	3/4	14	34.40
SPR9-28		.032	1 1/2	27	15.66
SPR9-29	.240	.026	1/2	6	17.40
SPR1-5		.026	5/8	8	10.57
SPR9-30		.026	1	12	6.16
SPR9-31		.035	1/2	8	40.40
SPR9-32		.035	1	14	18.65
SPR9-33		.038	3/4	10	38.40
SPR9-34		.038	1-1/2	20	17.82
SPR9-35		.040	1	14	32.48
SPR9-36		.040	2	27	15.57
SPR1-6	.300	.032	5/8	6	5.16
SPR1-7	.360	.042	7/8	8	21.24
SPR1-8	.420	.045	1	7	16.66
SPR1-9	.480	.055	1-1/4	8	22.49
SPR1-10	.600	.063	1-1/2	8	19.99
SPR1-11	.720	.072	2	9	16.66

K = Average Spring Rate lbs./in.
Sold in packages of 10.

Also available

STOCK NO.	DESCRIPTION OF KIT
KIT-SPR9	COMPRESSION SPRING KIT - ASSORTED SIZES .057 TO .240 DIAMETER TO 2" LONG (141 PIECES)