


BALL BEARINGS

BORE SIZE	TYPE	MATERIAL
3/64" TO 1/2"	SINGLE ROW PRECISION ABEC-3 AND ABEC-7	440C STAINLESS STEEL

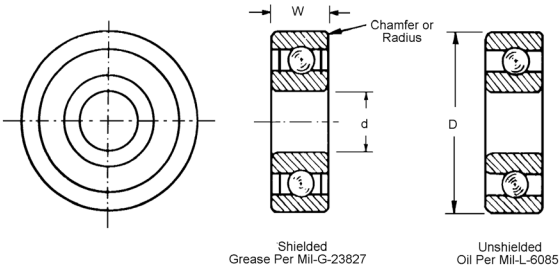

ABEC-3 STOCK NO.	ABEC-7 STOCK NO.	d	D	w	SHIELD DATA	DYNAMIC LOAD (LBS.)	STATIC LOAD (LBS.)
B1-37-Q3 B1-37-S-Q3	B1-37 B1-37-S	.0469	.1562	.0625 .0937	UNSHIELDED SHIELDED	17	6
B1-38-Q3 B1-38-S-Q3	B1-38 B1-38-S	.0550	.1875	.0781 .1094	UNSHIELDED SHIELDED	26	9
B1-33-Q3 B1-33-S-Q3	B1-33 B1-33-S	.0781	.2500	.0937 .1406	UNSHIELDED SHIELDED	36	14
B1-34-Q3 B1-34-S-Q3	B1-34 B1-34-S	.0937	.3125	.1094 .1406	UNSHIELDED SHIELDED	60	24
B1-35-Q3 B1-35-S-Q3	B1-35 B1-35-S	.1250	.2500	.0937 .1094	UNSHIELDED SHIELDED	33	13
B1-36-Q3 B1-36-S-Q3	B1-36 B1-36-S		.3125	.1094 .1406	UNSHIELDED SHIELDED	60	24
B1-24-Q3 B1-5-Q3	B1 -24 B1-5		.3750	.1562 .1562	UNSHIELDED SHIELDED	68	28
B1-42-Q3 B1-42-S-Q3	B1-42 B1-42-S		.3125	.1094 .1250	UNSHIELDED SHIELDED	33	14
B1-40-Q3 B1-40-S-Q3	B1-40 B1-40-S	.1875	.3125	.1094 .1250	UNSHIELDED SHIELDED	33	14
B1-25-Q3 B1-27-Q3	B1-25 B1-27		.3750	.1250 .1250	UNSHIELDED SHIELDED	76	33
B1-26-Q3 B1-7-Q3	B1-26 B1-7		.5000	.1562 .1960	UNSHIELDED SHIELDED	141	67
B1-29-Q3 B1-30-Q3	B1-29 B1-30		.3750	.1250 .1250	UNSHIELDED SHIELDED	37	17
B1-31-Q3 B1-32-Q3	B1-31 B1-32	.2500	.5000	.1250 .1875	UNSHIELDED SHIELDED	114	57
B1-28-Q3 B1-9-Q3	B1-28 B1-9		.6250	.1960 .1960	UNSHIELDED SHIELDED	158	78
B1-43-Q3 B1-43-S-Q3	B1-43 B1-43-S		.3125	.1562 .1562	UNSHIELDED SHIELDED	56	31
B1-39-Q3 B1-13-Q3	B1-39 B1-13	.3750	.8750	.2188 .2812	UNSHIELDED SHIELDED	356	176
B1-44-Q3 B1-44-S-Q3	B1-44 B1-44-S	.5000	.8750	.2188 .2812	UNSHIELDED SHIELDED	203	114
B1-15-Q3	B1-15		1.1250	.3125	SHIELDED	827	464

See Section K (Reference Section) for Bearing Tolerances.