


OIL-LESS BEARINGS

SHAFT SIZE	TYPE	MATERIAL
1/8" TO 1/2"	PLAIN AND FLANGED STYLE	TEFLON-MIL-P-19468

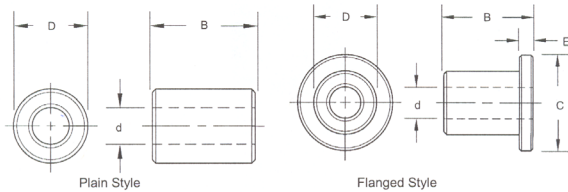

- Long Life
- Smooth Operation
- No Lubrication Required
- Minimal Breakaway Torque Resistance
- Max. PV = 10,000
- 450° F Max. Temperature Use

PLAIN STYLE	FLANGED STYLE	SHAFT SIZE	d +.005	D +.000 -.003	B ±.010	FLANGED ONLY		SHAFT STOCK NO.
						C ±.010	E ±.005	
B8-1 ---	B9-1 B9-2 B9-3 ---	1/8	.126	.254	.125 .187 .250 .375	.312	.047	S1-8
B8-5 B8-6 B8-7 ---	B9-5 B9-6 B9-7 ---	3/16	.188	.317	.125 .250 .375 .500	.375	.047	S1-11
B8-9 B8-10 B8-11 B8-12 ---	B9-9 B9-10 B9-11 ---	1/4	.251	.379	.250 .375 .500 .625	.500	.047	S1-73
B8-13 B8-14 B8-15 B8-16 ---	B9-13 B9-14 B9-15 B9-16 ---	5/16	.313	.441	.250 .375 .500 .625 .750	.562	.093	S1-16
B8-17 B8-18 B8-19 B8-20 ---	B9-17 B9-18 B9-19 B9-20 ---	3/8	.376	.504	.375 .500 .625 .750	.687	.093	S1-75
B8-21 B8-22 B8-23 B8-24 ---	B9-21 B9-22 B9-23 B9-24 ---	1/2	.501	.629	.500 .625 .750 1.000	.875	.125	S1-77